


Cable glands Progress® nickel-plated brass

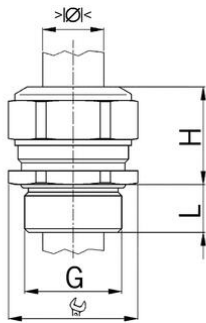

Long entry thread metric

Type approval: Progress MS

- One-piece sealing insert
- not overall length insulated

Order number:	1100.06.030
E-No:	121099018
EAN:	7611614104645
Material	Nickel-plated brass
Seal	TPE
O-ring	NBR
Operation temperature	-40°C / +100°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Entry thread	M6x1.0
Clamping range min.	2.5 mm
Clamping range max.	3.0 mm
Wrench size	8 mm
Dimension H	12 mm
Thread length L	8 mm
Note	1
UL - clamping range	3.0-3.0 mm
Dispatch	50

1 = Metric coarse-pitch thread (with VDE test report)

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.