


## Cable glands Progress® stainless steel A2 for high temperature applications

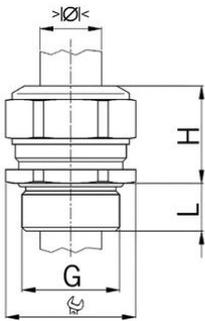

### Long entry thread Pg

- One-piece sealing insert
- not overall length insulated

<b>Order number:</b>	<b>1100.07.96.050</b>
EAN:	7611614134161
Material	CrNi stainless steel A2 (DIN EN 1.4305 / AISI 303)
Identification	1 groove
Seal	FPM
O-ring	FPM
Operation temperature	-40°C / +200°C
Protection class	IP 68 (up to 10 bar) / IP 69
Entry thread	Pg 7
Clamping range without insert min.	3.5 mm
Clamping range without insert max.	5.0 mm
Wrench size	17 mm
Dimension H	17 mm
Thread length L	10 mm
Dispatch	50