


## Synthetic cable glands Progress® GFK

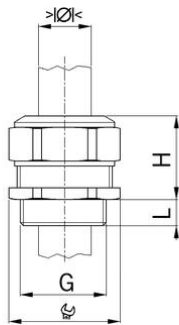

### Entry thread metric

#### Type approval: Progress GFK

- Black RAL 9005
- One-piece sealing insert

|                                    |                                  |
|------------------------------------|----------------------------------|
| <b>Order number:</b>               | <b>1540.08.050</b>               |
| E-No:                              | 121742118                        |
| EAN:                               | 7611614136967                    |
| Material                           | Polyamide glass fiber reinforced |
| Properties                         | halogen-free                     |
| Seal                               | TPE                              |
| Operation temperature              | -20°C / +100°C                   |
| Strain relief                      | Version A acc. to EN 62444       |
| Protection class                   | IP 68                            |
| Entry thread                       | M8x1.0                           |
| Clamping range without insert min. | 3.5 mm                           |
| Clamping range without insert max. | 5.0 mm                           |
| Wrench size                        | 12 mm                            |
| Dimension H                        | 15.5 mm                          |
| Thread length L                    | 10 mm                            |
| Dispatch                           | 50                               |