


## Synthetic cable glands Syntec® with lamellar technology

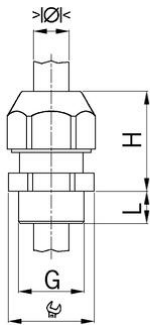

### Entry thread Pg

#### Type approval: SYNTEC

- Black RAL 9005
- One-piece sealing ring

|                       |                                                                      |
|-----------------------|----------------------------------------------------------------------|
| <b>Order number:</b>  | <b>1545.13.07</b>                                                    |
| E-No:                 | 121755329                                                            |
| EAN:                  | 7611614078144                                                        |
| Material              | Polyamide PA 6                                                       |
| Properties            | halogen-free, black UV resistant (tested according to EN ISO 4892-2) |
| Sealing ring          | CR (neoprene)                                                        |
| Operation temperature | -30°C / +100°C                                                       |
| Protection class      | IP 68                                                                |
| NEMA Type rating      | 4X                                                                   |
| Entry thread          | Pg 13                                                                |
| Clamping range min.   | 3.0 mm                                                               |
| Clamping range max.   | 7.0 mm                                                               |
| Wrench size           | 24 mm                                                                |
| Dimension H           | 26 mm                                                                |
| Thread length L       | 9 mm                                                                 |
| UL - clamping range   | 7.0-7.0 mm                                                           |
| Dispatch              | 50                                                                   |