


Synthetic cable glands Syntec® with lamellar technology

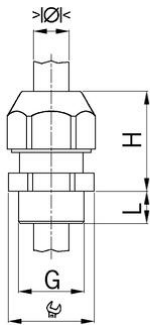

Entry thread NPT

Type approval: SYNTEC

- Black RAL 9005
- One-piece sealing ring

Order number:	1545.N0500.12
E-No:	121758329
EAN:	7611614078403
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	CR (neoprene)
Operation temperature	-30°C / +100°C
Protection class	IP 54
Entry thread	NPT 1/2 "
NEMA Type rating	4X
Clamping range min.	5.5 mm
Clamping range max.	12.0 mm
Wrench size	24 mm
Dimension H	26 mm
Thread length L	15 mm
UL - clamping range	9.5-12.0 mm
Dispatch	50