


Synthetic cable glands Syntec® with lamellar technology

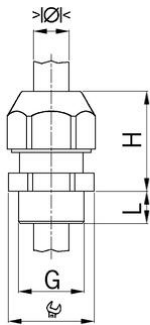

Entry thread NPT

Type approval: SYNTEC

- Light grey RAL 7035
- One-piece sealing ring

Order number:	1555.N0375.08
E-No:	121758219
EAN:	7611614078045
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	CR (neoprene)
Operation temperature	-30°C / +100°C
Protection class	IP 54
Entry thread	NPT 3/8"
NEMA Type rating	4X
Clamping range min.	3.0 mm
Clamping range max.	8.0 mm
Wrench size	19/22 mm
Dimension H	23 mm
Thread length L	15 mm
UL - clamping range	8.0-8.0 mm
Dispatch	50