


Pressure balance element nickel-plated brass and synthetic

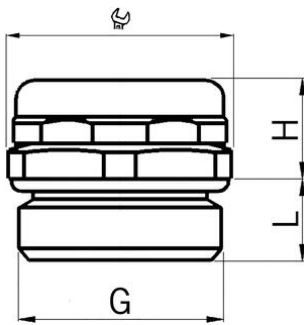

Pressure balance element nickel-plated brass with membrane

- with membrane
- with O-ring

Order number:	2450.07.34
EAN:	7611614269917
Material	Nickel-plated brass
Membrane	PES polyethersulfone
O-ring	NBR
Operation temperature	-60°C / +100°C
Protection class	IP 66 / IP 68 / IP 69
Water intrusion pressure	IP 68 = 0.2 bar / 30 min
Air flow rate	> 90 ml / min / cm ² at 10 mbar
Entry thread	Pg 7
Wrench size	18 mm
Dimension H	9.5 mm
Dimension L	8 mm
Dispatch	25

Available on request:

- Stainless steel A2 or A4