


Pressure balance element nickel-plated brass and synthetic

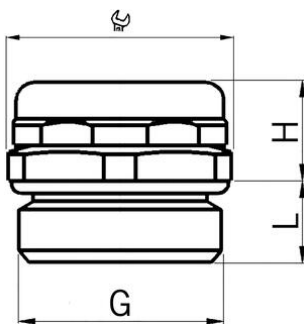

Pressure balance element nickel-plated brass with sintered filter

- Sintered filter
- with O-ring

Order number:	2450.12.32
E-No:	126244310
EAN:	7611614269948
Material	Nickel-plated brass
Filter disc	Sintered bronze
O-ring	NBR
Operation temperature	-50°C / +110°C
Protection class	IP 54 / IP x9
Degree of filter	40 µm
Entry thread	M12x1.5
Wrench size	18 mm
Dimension H	9.5 mm
Dimension L	8 mm
Dispatch	25

Available on request:

- Stainless steel A2 or A4
- For high temperature applications (+200°C)