


Synthetic adapter

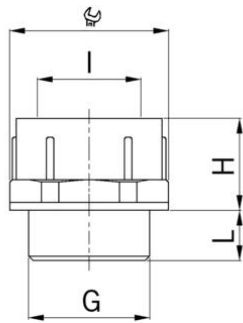

Synthetic adapter

- Outer thread metric
- Inner thread Pg
- Light grey

Order number:	3720.16
EAN:	7611614152936
Material	Polyamide glass fiber reinforced
Operation temperature	-20°C / +100°C
Protection class	IP 54
Entry thread	IP 68, if the entry thread is sealed
Thread outside	M20x1.5
Internal thread	Pg 16
Wrench size	27 mm
Dimension H	17 mm
Dimension L	11 mm
Dispatch	50