



preci-dip

RUE SAINT-HENRI 11, P.O. BOX 834 - CH-2800 DELÉMONT / SWITZERLAND

Your selected product

Screw-machined Contacts

01001


Socket contacts

For other versions than the listed available standard types, please contact PRECI-DIP

SPECIFICATIONS:

Socket contact with solder tail

- Press-in mount into dia 1.45 mm hole
- Materials: body brass, contact clip BeCu
- Electrical contact resistance max. 15 milliohms
- Mechanical life min. 500 cycles

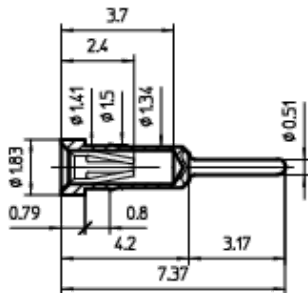

AVAILABLE STANDARD TYPES

Ordering Part Number		Plating Body	Plating Clip	Insertion	Extraction	Dia.Gauge	Max Current
01001-13-3010	RoHS	0.25µm Au	0.75µm Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-77-3010	RoHS	Flash Au	Flash Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-83-3010	RoHS	5µm Sn	0.75µm Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-87-3010	RoHS	5µm Sn	Flash Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-83-3110	RoHS	5µm Sn	0.75µm Au	0.70 N	0.40 N	0.46 mm	3.0 A
01001-87-3110	RoHS	5µm Sn	Flash Au	0.70 N	0.40 N	0.46 mm	3.0 A
01001-83-3130	RoHS	5µm Sn	0.75µm Au	0.35 N	0.20 N	0.46 mm	3.0 A
01001-93-5210		Plating on request		1.50 N	0.60 N	0.78 mm	4.5 A