




ELPRESS®

Product Datasheet

Fork terminals 0.1 - 6 mm²

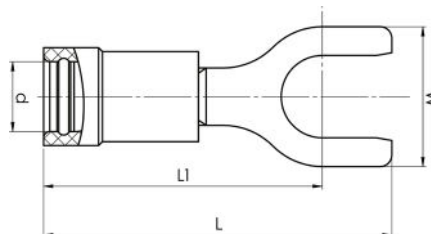

mm² (Cu)	AWG Cu	Name	Screw	W (mm)	d	L	L1	t	s	Tool	Insulation material	Easy Entry	Material	Pcs/pack	Tool
0,1-0,5	26-20	A0532G	M3	5,5	3,2	18	15	0,5	6	DSA0115	PA	No	Cu, Cu/Sn	100	DSA0115
0,25-0,75	24-20	A0832G	M3	5,5	3,2	18	15	0,5	7	DSA0115	PC	Yes	Cu, Cu/Sn	100	DSA0115
0,25-0,75	24-20	A0837G	M3,5	6,2	3,2	21	17,5	0,5	7	DSA0115	PC	Yes	Cu, Cu/Sn	100	DSA0115
0,25-0,75	24-20	A0843G	M4	6,2	3,2	21	17,5	0,5	7	DSA0115	PC	Yes	Cu, Cu/Sn	100	DSA0115
0,5-1,5	20-16	A1532G	M3	5,5	4	19	16	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
0,5-1,5	20-16	A1537G	M3,5	6,2	4	21	17,5	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
0,5-1,5	20-16	A1537GS	M3,5	5,5	4	21,2	17	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
0,5-1,5	20-16	A1543G	M4	7	4	21	17,5	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
0,5-1,5	20-16	A1553G	M5	9	4	22,5	18	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
0,5-1,5	20-16	A1565G	M6	11	4	26,5	21	0,7	7	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2532G	M3	5,5	4,5	18	15	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2537G	M3,5	6,2	4,5	21	17,5	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2537GS	M3,5	5,5	4,5	21,2	17	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2543G	M4	7	4,5	21	17,5	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2553G	M5	9	4,5	23	18	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
1,5-2,5	16-14	A2565G	M6	11	4,5	25	19,5	0,8	8	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
4-6	12-10	A4643G	M4	7,8	6,4	24	20	1	9	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
4-6	12-10	A4653G	M5	9	6,4	25	20,5	1	9	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
4-6	12-10	A4665G	M6	11	6,4	27	21,5	1	9	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
4-6	12-10	A4685G	M8	14	6,4	30	23	1	9	GSA0760	PC	Yes	Cu, Cu/Sn	100	GSA0760
4-6	12-10	A4610G	M10	18	6,4	36	27,5	1	9	GSA0760	PA	Yes	Cu, Cu/Sn	100	GSA0760

t = palm thickness, s = strip length



ELPRESS®