


Modular TOPJOB®S connector, modular; for jumper contact slot; 2-pole

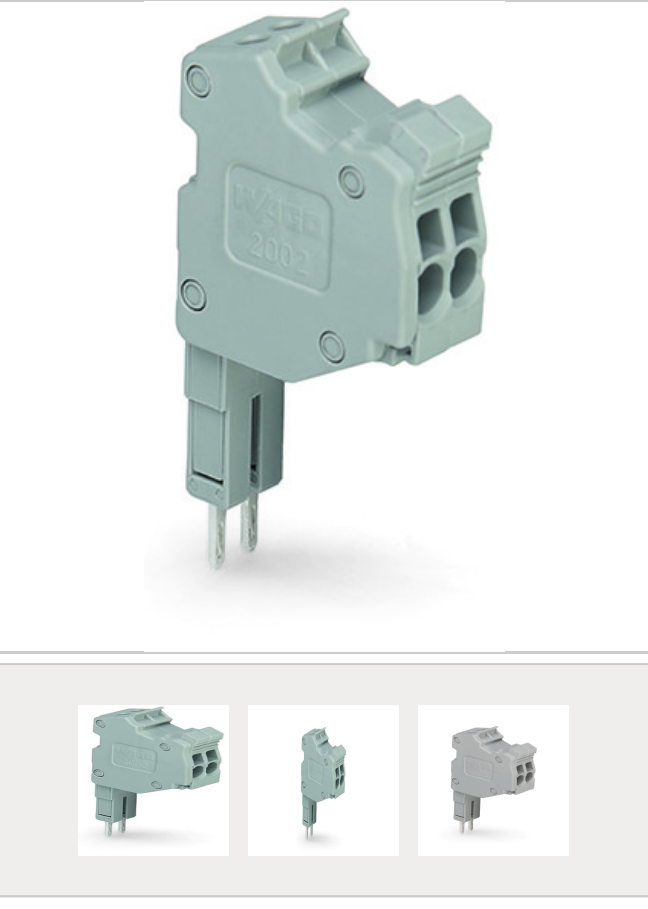

Item no.	2000-552	GTN / EAN	4959143391016
Content	1 piece	Order unit	piece
Order quantity	25 piece	Increase in order quantity	(25, 50, 75, 100, ...)
Customer item no.		Customs Tariff no.	8536690090
Customs duty for the country of origin	DE	Available	-
List price		Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS ✓
Compliant

Article details		Approvals		Downloads/Certificates		Accessories	
Description		Modular TOPJOB®S connector, modular; for jumper contact slot; 2-pole					
Remarks							
Item properties							
		Miscellaneous					
		Name		Value		Unit	
		Connection technology		Push-in CAGE CLAMP®			
		Nominal cross section		1 mm²			
		Solid conductor		0.14 ... 1.5 mm² / 24 ... 16 AWG			
		Solid conductor, push-in termination		0.5 ... 1.5 mm² / 20 ... 16 AWG			
		Fine-stranded conductor		0.14 ... 1.5 mm² / 24 ... 16 AWG			
		Fine-stranded conductor with ferrule, push-in termination, 1		0.5 mm² / 20 AWG			
		Strip length		9 ... 11 mm / 0.35 ... 0.43 inch			
		No. of poles		2			
		Total number of connection points		2			
		Total number of potentials		2			
		Type of wiring		Side-entry wiring			
		Width		8.5 mm / 0.335 in			
		Marking level		Center/side marking			
		Color		gray			
		Insulating material		Polyamide 66 (PA 66)			
		Weight [g]		4.21		g	
		Packaging type		BOX			
		[mm]		8.5		mm	
		Product Family		TOPJOB® S			
		Main product function		Testing accessories			
		Product type		Accessories			