


Modular TOPJOB®S connector, modular, for jumper contact slot, 6-pole

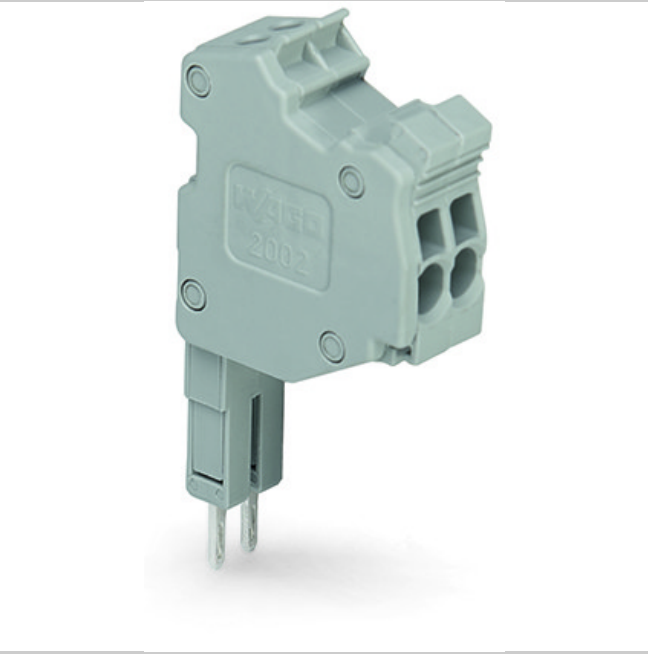

|                                        |            |                            |                       |
|----------------------------------------|------------|----------------------------|-----------------------|
| Item no.                               | 2000-556   | GTN / EAN                  | 4959143394666         |
| Content                                | 1 piece    | Order unit                 | piece                 |
| Order quantity                         | 10 piece   | Increase in order quantity | (10, 20, 30, 40, ...) |
| Customer item no.                      |            | Customs Tariff no.         | 8536690090            |
| Customs duty for the country of origin | DE         | Available                  | -                     |
| List price                             |            | Net price                  |                       |
| Availability                           | On request |                            | On request            |

Note: Some items may not be available from your local WAGO company.  
Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS ✓  
Compliant

|                                                              |                                  |                                                                      |             |
|--------------------------------------------------------------|----------------------------------|----------------------------------------------------------------------|-------------|
| Articles/details                                             | Approvals                        | Downloads/Certificates                                               | Accessories |
| Description                                                  |                                  | Modular TOPJOB®S connector, modular; for jumper contact slot, 6-pole |             |
| Remarks                                                      |                                  |                                                                      |             |
| Item properties                                              |                                  |                                                                      |             |
| Miscellaneous                                                |                                  |                                                                      |             |
| Name                                                         | Value                            | Unit                                                                 |             |
| Connection technology                                        | Push-in CAGE CLAMP®              |                                                                      |             |
| Nominal cross section                                        | 1 mm²                            |                                                                      |             |
| Solid conductor                                              | 0.14 ... 1.5 mm² / 24 ... 16 AWG |                                                                      |             |
| Solid conductor, push-in termination                         | 0.5 ... 1.5 mm² / 20 ... 16 AWG  |                                                                      |             |
| Fine-stranded conductor                                      | 0.14 ... 1.5 mm² / 24 ... 16 AWG |                                                                      |             |
| Fine-stranded conductor with ferrule, push-in termination, l | 0.5 mm² / 20 AWG                 |                                                                      |             |
| Strip length                                                 | 9 ... 11 mm / 0.35 ... 0.43 inch |                                                                      |             |
| No. of poles                                                 | 6                                |                                                                      |             |
| Total number of connection points                            | 6                                |                                                                      |             |
| Total number of potentials                                   | 6                                |                                                                      |             |
| Type of wiring                                               | Side-entry wiring                |                                                                      |             |
| Width                                                        | 22.5 mm / 0.885 in               |                                                                      |             |
| Marking level                                                | Center/side marking              |                                                                      |             |
| Color                                                        | gray                             |                                                                      |             |
| Insulating material                                          | Polyamide 66 (PA 66)             |                                                                      |             |
| Weight [g]                                                   | 11.69                            | g                                                                    |             |
| Packaging type                                               | BOX                              |                                                                      |             |
| [mm]                                                         | 22.5                             | mm                                                                   |             |
| Product Family                                               | TOPJOB® S                        |                                                                      |             |
| Main product function                                        | Testing accessories              |                                                                      |             |
| Product type                                                 | Accessories                      |                                                                      |             |

Upwards