


4-conductor ground terminal block; Notice: Terminal block cannot be commoned.

Note: Some items may not be available from your local WAGO company.
Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU)

RoHS ☒ Compliant

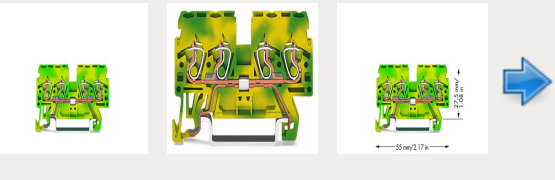

Miscellaneous		
Name	Value	Unit
Safety information 2	Max. insulation diameter: 4.4mm	
Packaging type	BOX	
Rating plate	IEC-EN 60047-7-2	
Type of wiring	Front-entry wiring	
Total number of connection points	4	
Total number of potentials	1	
Number of levels	1	
Connection technology	CAGE CLAMP®	
Actuation type	Operating tool	
Connectable conductor materials	Copper	
Solid conductor	0.08 ... 2.5 mm² / 28 ... 12 AWG	
Fine-stranded conductor	0.08 ... 4 mm² / 28 ... 12 AWG	
Strip length	6 ... 7 mm / 0.24 ... 0.28 inch	
Width	5 mm / 0.197 inch	
Height from upper-edge of DIN-35 rail	27.5 mm / 1.083 inch	
Depth	55 mm / 2.165 inch	
Design	horizontal	
Type of mounting	Carrier rail 35 x 15	
Marking level	Side marking	
Color	green/yellow	
Insulating material	Polyamide 66 (PA 66)	
Fire load [MJ]	0.11	MJ
Weight [g]	8.667	g
Main product function	QAD cond. term. block	
Product type	Through rail-mount term. blocks	