


Within Series Adaptor 46_SMB-50-0-2/111_N

Description

T-adaptor, 3 jacks
SMB jack (female) / SMB jack (female)

Interface standard
Series SMB - IEC 60169-10_MIL-STD-348A/311_CECC 22130

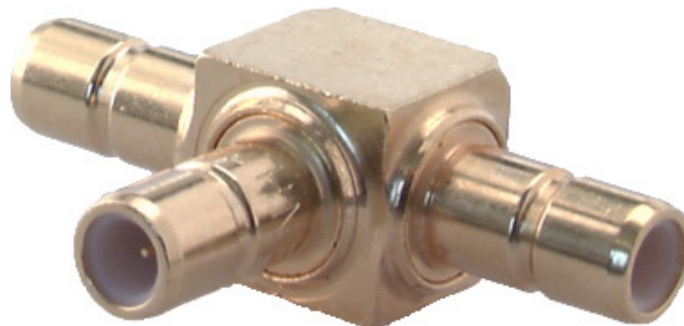

Technical Data

Electrical Data

Impedance 50 Ω
Interface frequency max. 4 GHz

Mechanical Data

Number of matings 500
Weight 0.0029 kg

Environmental Data

Operating temperature -65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102) not compliant

Material Data

Interface - SMB jack (female)

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Interface - SMB jack (female)

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Related Documents

Catalogue drawing DCA-00013519

Ordering Information

Single package 46_SMB-50-0-2/111_NE