


## EPIC® H-B 32 TG

Housing design H-B for 2 inserts.

Two connector inserts in single housing with two levers ensure a high level of safety and are suitable for use in control systems.

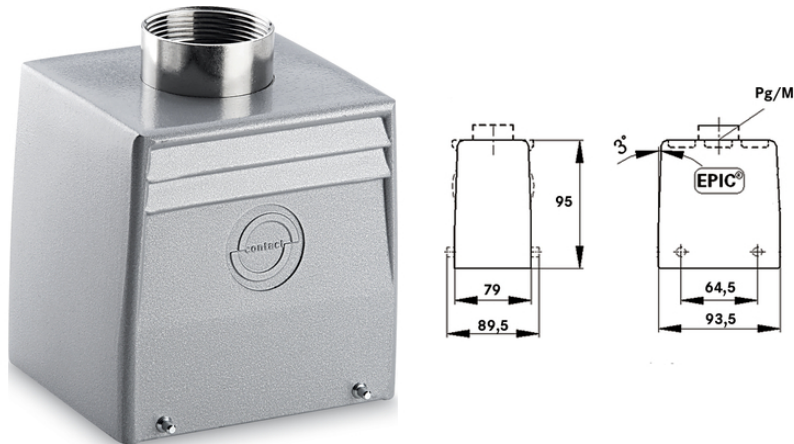

### Benefits

Two inserts in one housing. With two levers for high safety

### Application range

Plant engineering  
Control engineering  
Plastics industry

### Product features

Hood  
Bolts for double lever  
Straight cable entry  
Versions with / without neck

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40°C to +100°C, short-term up to +125°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® H-B 32 TG**

Article number	Article description	M	PG	Neck	Pieces / PU
H-B housing: hood (straight cable entry, bolts for double lever)					
10133000	H-B 32 TG 21	-	21	yes	5
10134000	H-B 32 TG 29	-	29	yes	5
19134000	H-B 32 TG M32	32	-	-	5
19134400	H-B 32 TG M40	40	-	-	5