



| *Trusted Solutions,
Improving Lives™*



GBH 10D1125-101-1053 Vs 10D1126-401-7048B

GBH 10D1125-101-1053



ITS 10D1126-401-7048B




The only difference is motor :


GBH Version : Brushed motor

ITS Version : Local BLDC Motor

GBH 10D1125-101-1053

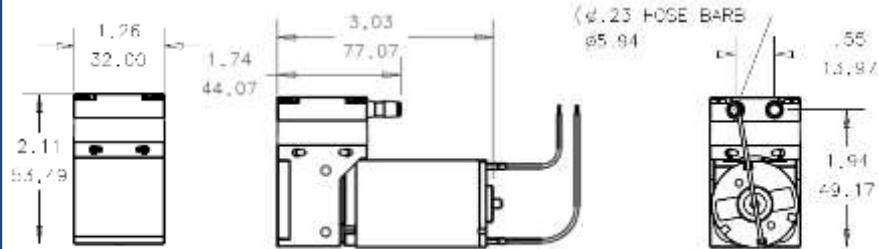

ITS 10D1126-401-7048B

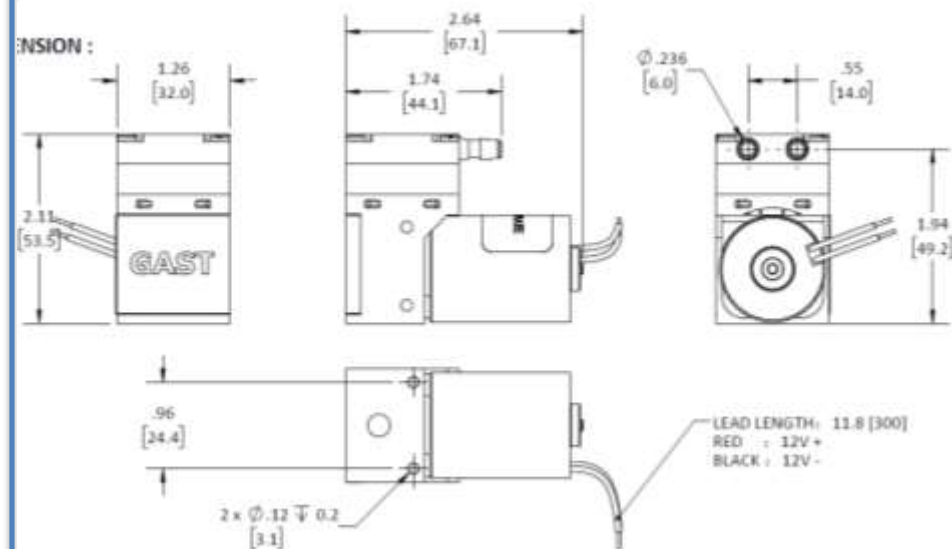


ITS version is smaller than GBH version:


GBH Version : 77.07 x 32 x 53.5 mm

ITS Version : 67.1 x 32 x 53.5 mm

GBH 10D1125-101-1053

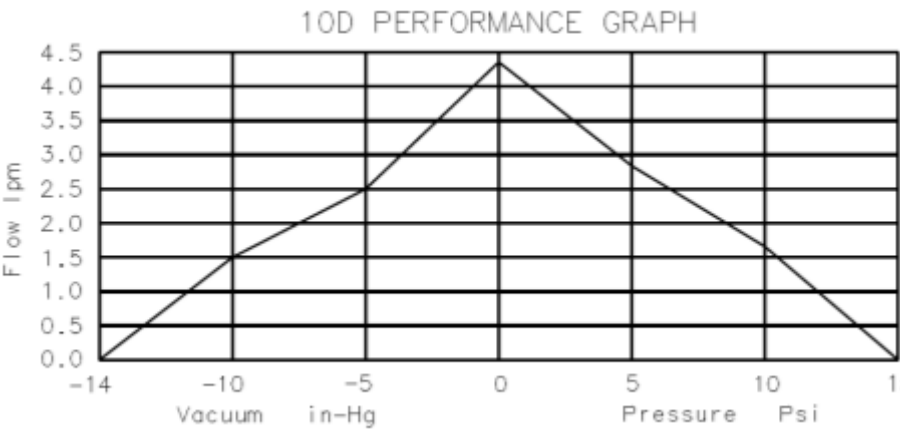

ITS 10D1126-401-7048B

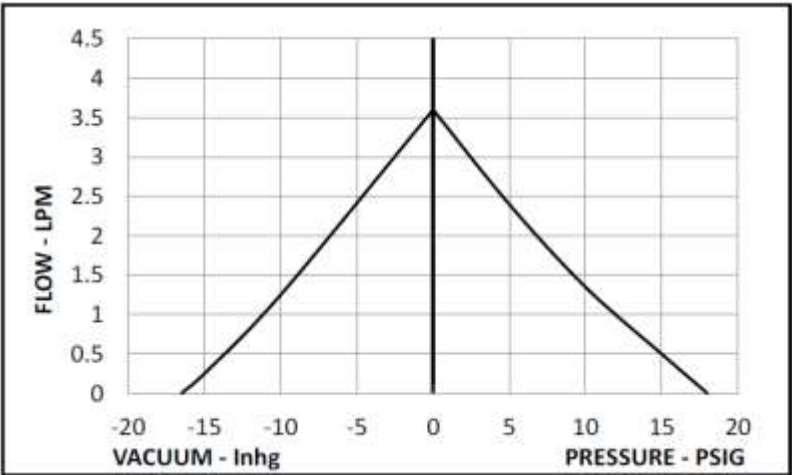

ITS flow is a little lower than GBH version