



| *Trusted Solutions,  
Improving Lives™*



**GBH 10D1125-101-1052 Vs 10D1126-401-7049B**

GBH 10D1125-101-1052




ITS 10D1126-401-7049B




**The only difference is motor :**  
GBH Version : Brushed motor  
ITS Version : Local BLDC Motor

## GBH 10D1125-101-1052

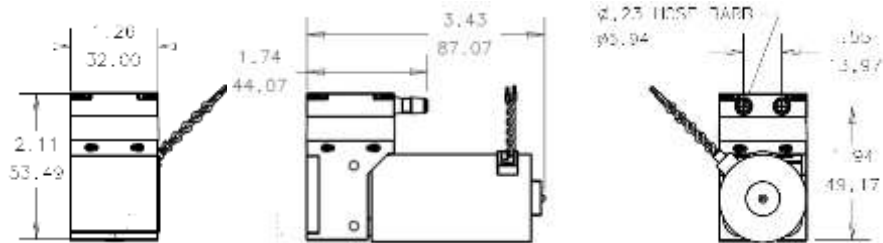

## ITS 10D1126-401-7049B

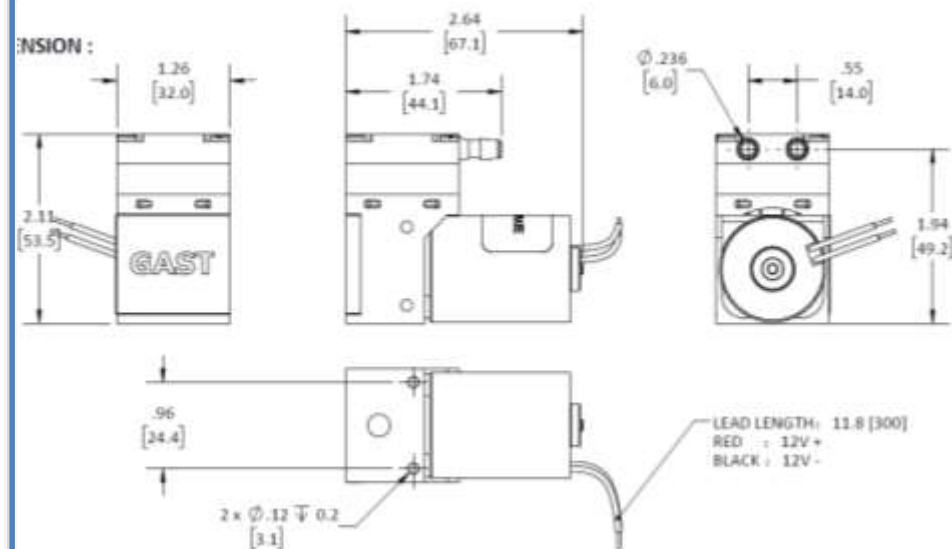


**ITS version is smaller than GBH version:**


GBH Version : 87.07 x 32 x 53.5 mm

ITS Version : 67.1 x 32 x 53.5 mm

GBH 10D1125-101-1052

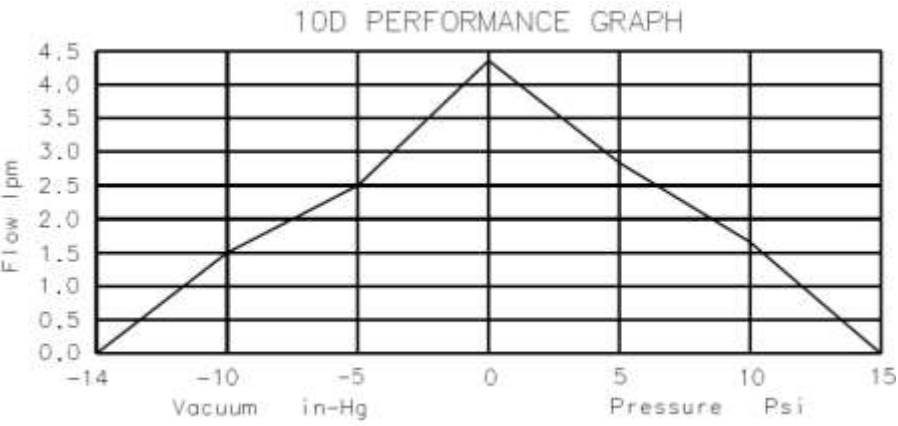

ITS 10D1126-401-7049B

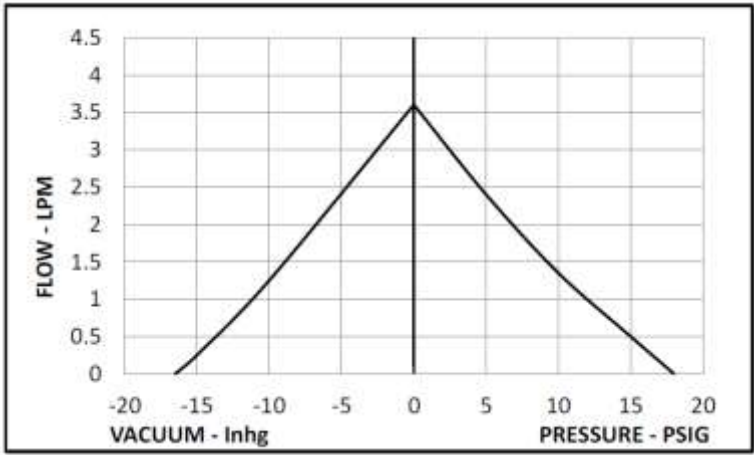

ITS flow is a little lower than GBH version