


Small Mushroom Head WiFi Dualband Antenna Bluetooth Wimax Zigbee

AN_W003



Mechanical Dimension

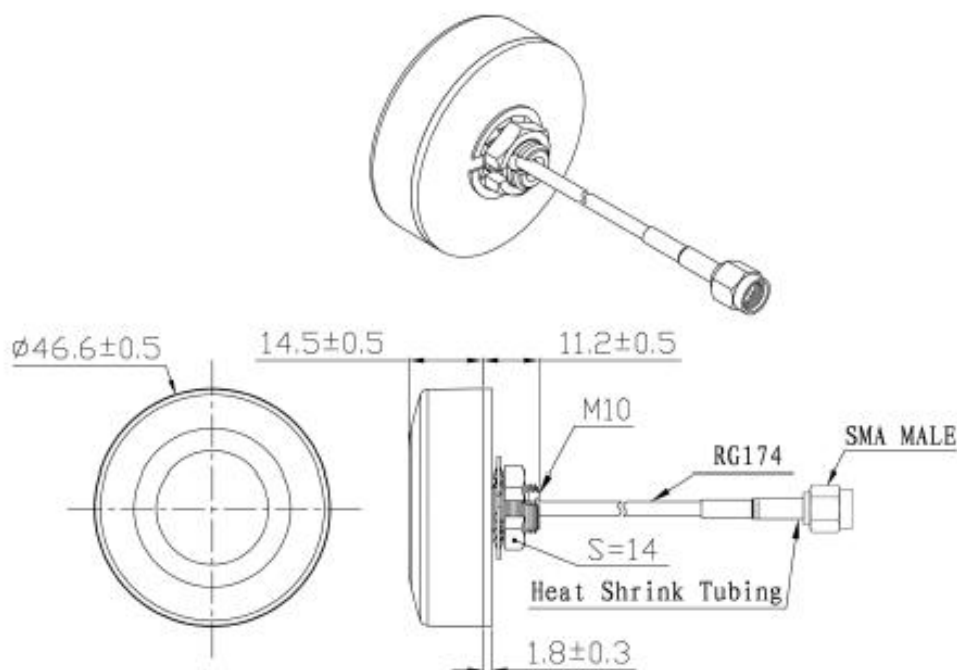

Unit: mm

Small Mushroom Head WiFi Dualband Antenna Bluetooth Wimax Zigbee AN_W003

Specifications

Item		Specifications
WIFI Antenna	Frequency Range	2400 ~ 2483.5/4800~5825MHz
	Polarization	Linear
	Gain	2dBi (Zenith)
	V.S.W.R (min)	< 2.5
	Impedance	50Ω
Mechanical	Cable	RG174
	Connector	SMA/MCX/FAKRA or others
	Radome Material	ABS
	Mounting Method	Screw
Environmental	Operating Temperature	-40°C~+85°C
	Relative Humidity	Up to 95%
	Ingress Protection	IP65~IP66 (exclude cable outlef)
	Vibration	10 to 55Hz with 1.5mm amplitude 2hours
	Environmentally Friendly	ROHS Compliant

Small Mushroom Head WiFi Dualband Antenna Bluetooth Wimax Zigbee AN_W003

Radiation Patterns

