
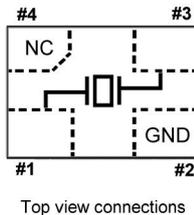
 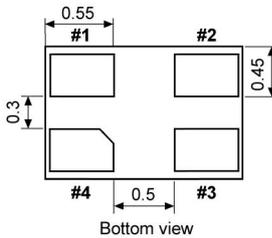



Quartz Crystal


SMD-version

part no.	12.84853
model	KX – 4T
frequency	24.0 MHz
mode	fundamental
operating temperature	-30° ~ +85°C
frequency tolerance at +25°C	±10 ppm
temperature tolerance -30° ~ +85°C	±15 ppm
load capacitance C_L	12 pF
series resistance R1 (ESR) max.	120 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C_0 max.	3.0 pF
drive level max.	100 µW
contents of reel	1000 pcs.


Dimensions (mm):

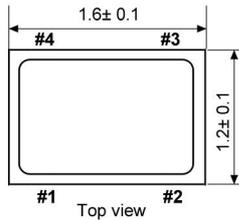

Suggested soldering pad:

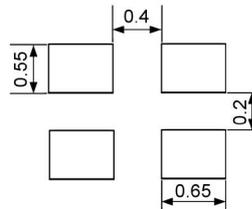

Reflow soldering condition:

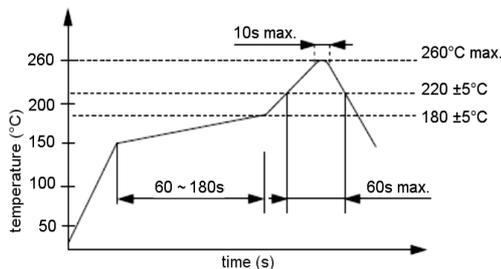

Tape specification:

