


Type K Glassfibre Insulated Flat Pair thermocouple Cable / Wire (IEC)

XE-2520-010

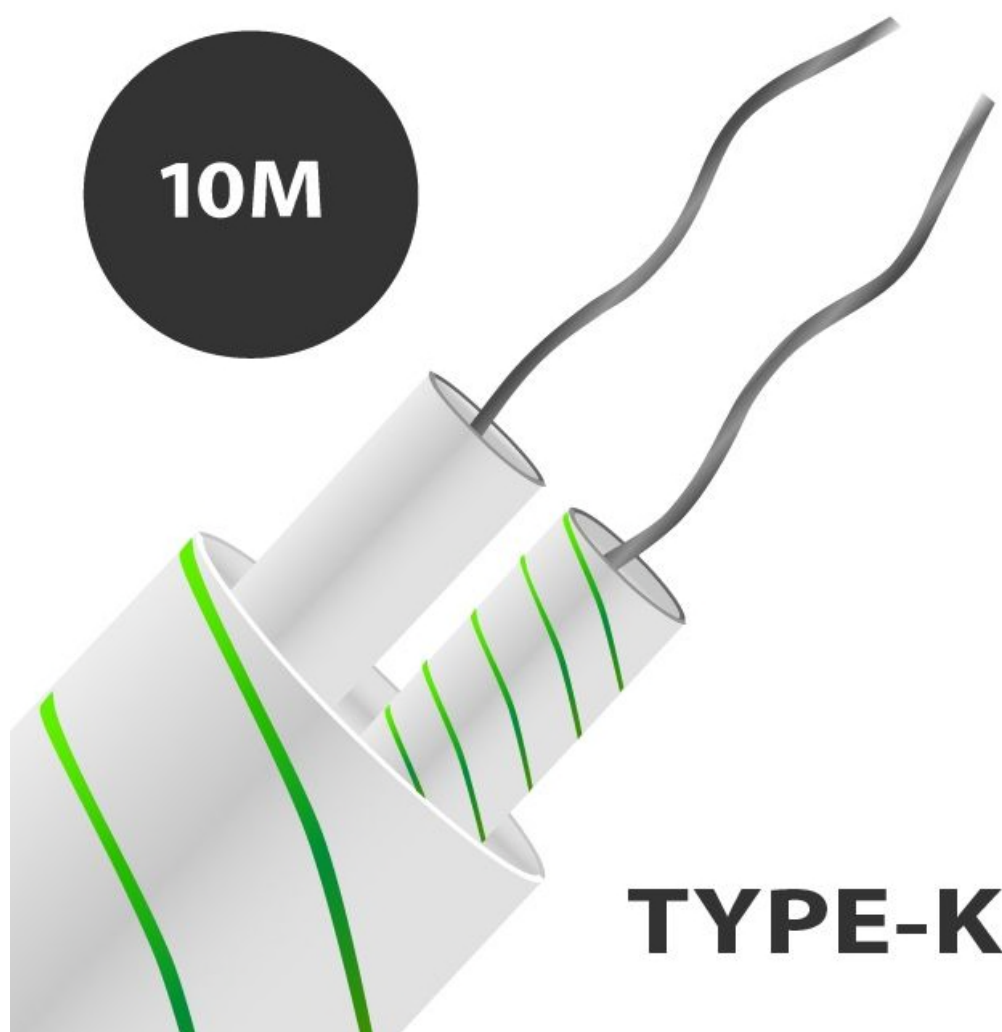

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Specifications

General Description	Good temperature range but will not prevent ingress of fluids. Fairly flexible but does not provide good mechanical protection.
Cable Length	10m
Cable Type	Flat pair cable
Core / Strands	1/0.508mm
Conductor Cross Section 1/0.508 (mm²)	0.203
Outer Colour	Green & White
+ Colour	Green
- Colour	White
Drain Wire	No
Insulation Material	Glassfibre insulated
Loop Resistance 1/0.508 (Ohms per combined metre)	4.9
Max. Temperature	+350°C (short periods up to 400°C)
Min. Temperature	-60°C
+ Conductor	Nickel Chromium
- Conductor	Nickel Aluminium
Screen	No
Standards Met	Colour code (cores & jacket) to IEC-584-3
Thermocouple Type	K
Tolerance	Class 2

Ordering Information

Type	Style	Material	Core/Strands	Length	Manufacturers Number
K	Flat Pair	Glassfibre	1/0.508mm	10m (32 ft)	XE-2520-010