


Thermocouple Cable / Wire (IEC) Type E PVC Insulated Flat Pair

XE-2554-010

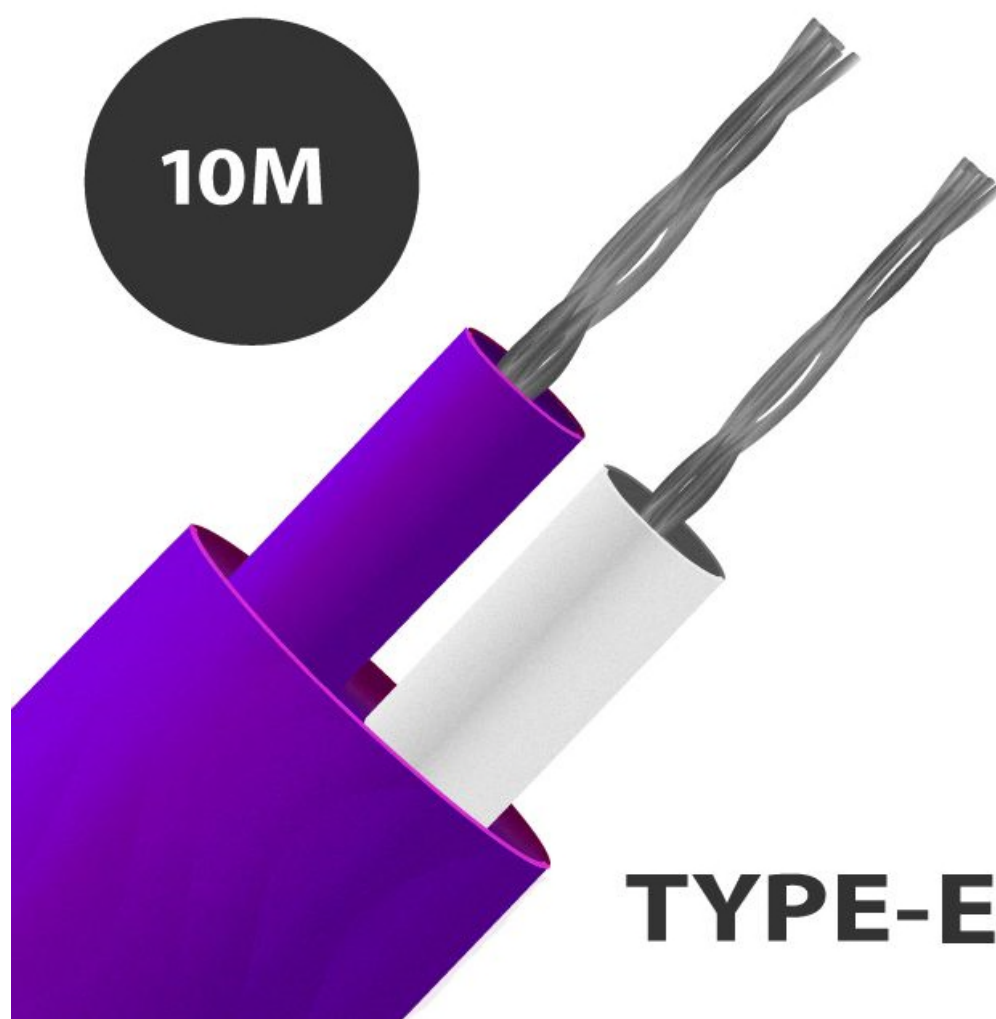

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Specifications

Cable Length	10m
Cable Type	Flat pair construction
Core / Strands	Stranded conductors available, 7/0.2mm
Insulation Material	PVC Insulated
Max. Temperature	+105°C
Min. Temperature	-10°C
Standards Met	Colour code (cores & jacket) to IEC-584-3
Thermocouple Type	E
Tolerance	Class 2

Ordering Information

Type	Style	Material	Core/Strands	Length	Manufacturers Number
E	Flat Pair	PVC	7/0.2mm	10m (32 ft)	XE-2554-010