



TYPE B4F

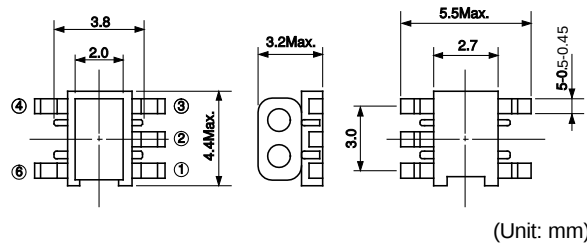

Recommended patterns 推荐焊盘尺寸

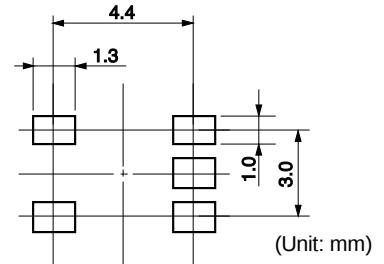


- Operating temperature (−40~+85°C)

- 使用温度范围：−40 ~ +85°C

Transformers for Frequency Mixer 混频器用变压器


Part No.	Winding Turns		Impedance Ratio
	1-2=2-3	4-6	
#617PT-2038=P3	3T	6T	75 : 75
#617PT-2270=P3	2T	6T	75 : 37.5
#617PT-2301=P3	1T	4T	75 : 18.75
#617PT-2304=P3	1T	6T	75 : 8.333

Test Circuit 测试电路

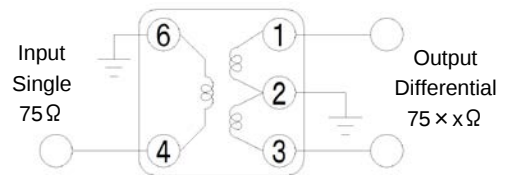


Typical Characteristics 典型特性


1) #617PT-2038 (Impedance Ratio=75Ω:75Ω)

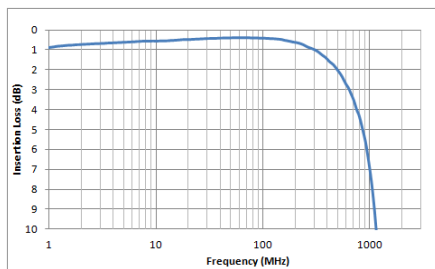

2) #617PT-2270 (Impedance Ratio=75Ω:37.5Ω)

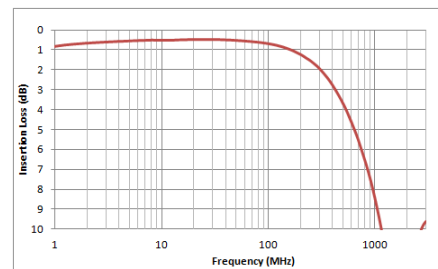

3) #617PT-2301 (Impedance Ratio=75Ω:18.75Ω)

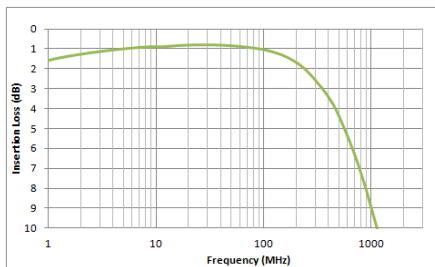

4) #617PT-2304 (Impedance Ratio=75Ω:8.333Ω)

