


Maswell 2X2 5G MIMO Antenna Magnet and Adhesive Mount 700-4900MHz

AN_5G_316-2C



Schematic picture

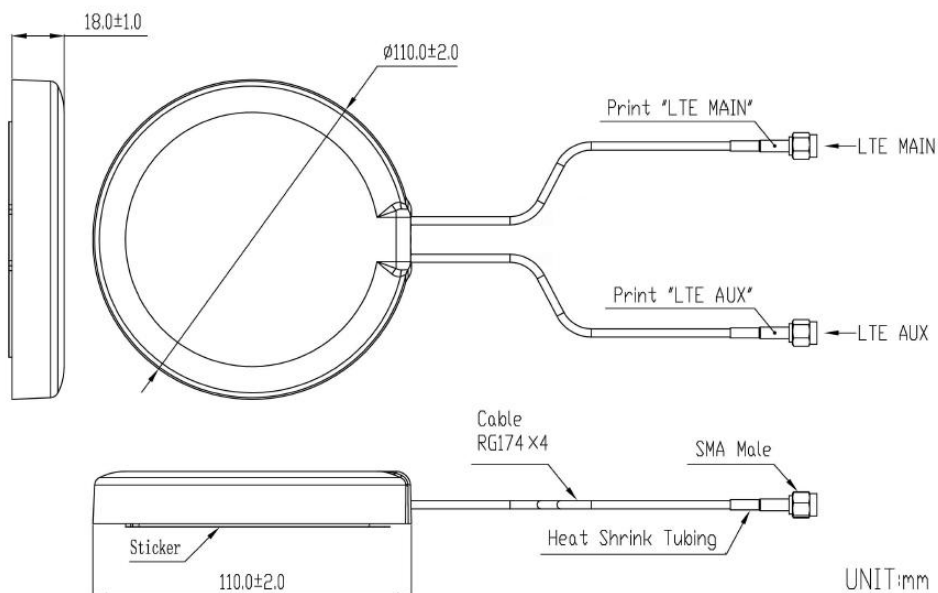

Maswell 2X2 5G MIMO Antenna Magnet and Adhesive Mount 700-4900MHz

AN_5G_316-2C

Specifications

Item	Specifications	
Cellular 5G/4G LTE/3G Antenna 1	Frequency Range	700MHz~4900MHz
	Polarization	Linear
	Gain	2.0 dBi
	V.S.W.R	≤2.0
	Efficiency	>50%
Cellular 5G/4G LTE/3G Antenna 2	Frequency Range	700MHz~4900MHz
	Polarization	Linear
	Gain	2.0dBi
	V.S.W.R	≤2.0
	Efficiency	>50%
Mechanical	Dimension	D110mm *18mm
	Mounting Type	3M Adhesive and Magnet
	Connector Type	Cellular Antenna 1-2: SMA Male
	Cable	LMR100 2meters
Environmental	Operating Temperature	-40°C~+85°C
	Relative Humidity	Up to 95%
	Vibration	10 to 55Hz with 1.5mm amplitude 2hours
	Environmentally Friendly	ROHS Compliant
	Ingress Protection	IP67