



Maswell 6 in 1 Combo Antenna Screw Mount 4G LTE 2x2 MIMO+WIFI 4x4 MIMO

AN_6combo_2C4W

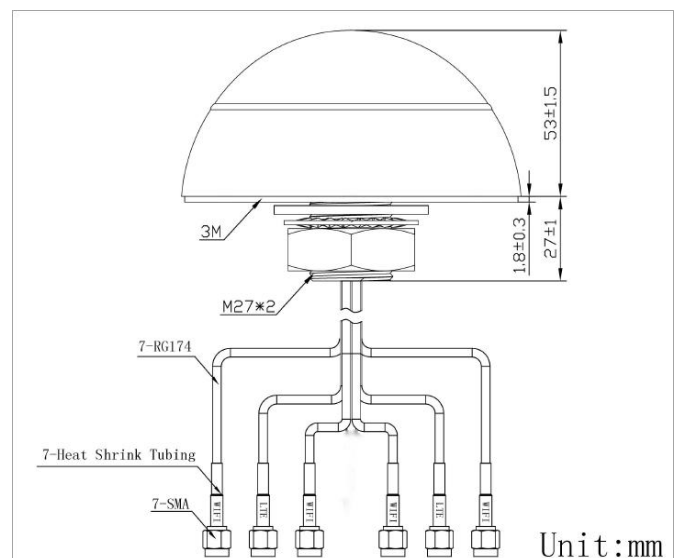

Mechanical dimension

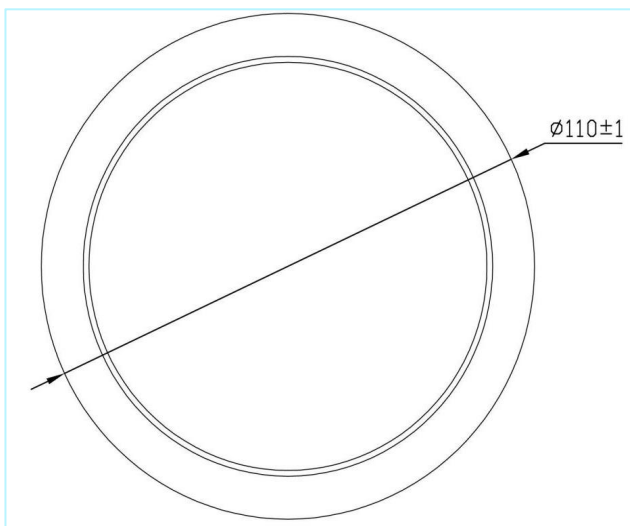

Maswell 6 in 1 Combo Antenna Screw Mount 4G LTE 2x2 MIMO+WIFI 4x4 MIMO

AN_6combo_2C4W

Specifications




Item		Specifications
LTE Antenna 2x2 MIMO	Frequency Range	698~960MHz/1710~2690MHz
	V.S.W.R	<3.0
	Polarization	Linear
	Gain	3dBi
	Impedance	50Ω
WIFI Antenna 4x4 MIMO	Frequency Range	2400~2483.5MHz/4900~5825MHz
	V.S.W.R	<2.5
	Polarization	Linear
	Gain	2dBi
	Impedance	50Ω
Mechanical	Cable	RG 174 3 meters
	Connector	SMA male for 4G,RP-SMA plug for WiFi
	Radome Material	ABS
	Mounting Method	Screw
Environmental	Operating Temperature	-40℃~+85℃
	Relative Humidity	Up to 95%
	Ingress Protection	IP67(exclude cable outlet)
	Vibration	10 to 55Hz with 1.5mm amplitude 2hours
	Environmentally Friendly	ROHS Compliant

Maswell 6 in 1 Combo Antenna Screw Mount 4G LTE 2x2 MIMO+WIFI 4x4 MIMO

AN_6combo_2C4W

Radiation Patterns

LTE Antenna

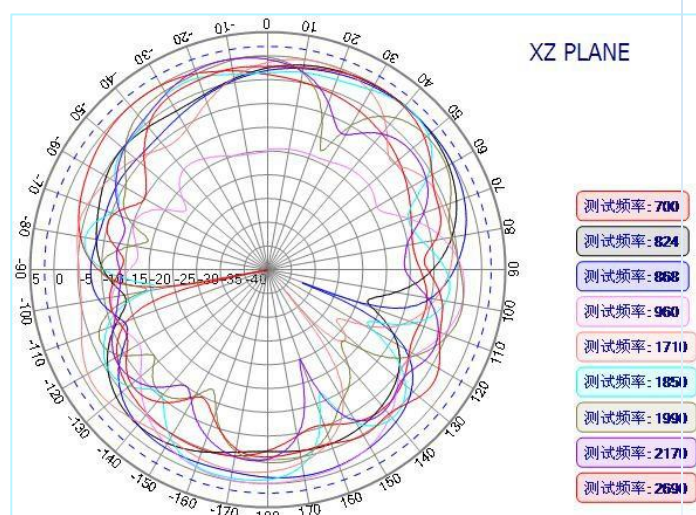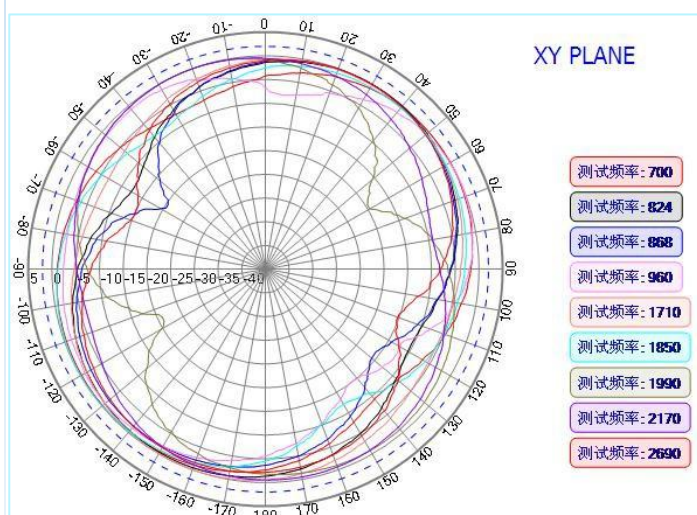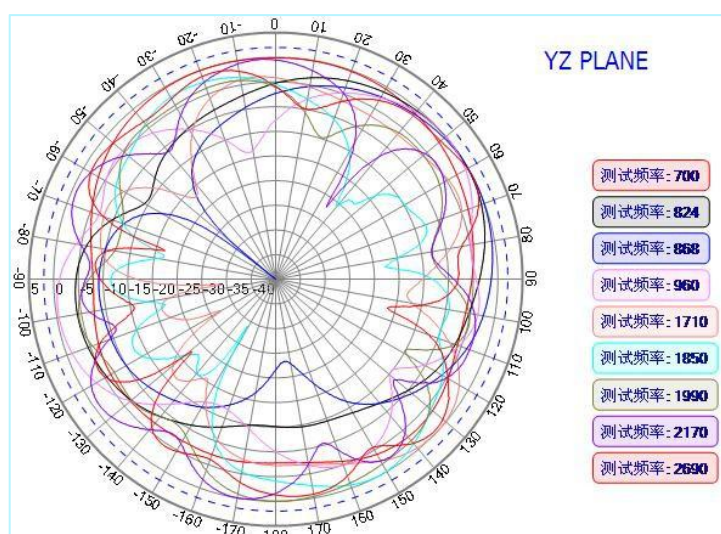

Maswell 6 in 1 Combo Antenna Screw Mount 4G LTE 2x2 MIMO+WIFI 4x4 MIMO

AN_6combo_2C4W

Radiation Patterns

WIFI Antenna

