


Heavy Duty Marine Iridium Antenna Screw Mount

AN_Iridium_005



Mechanical Dimension

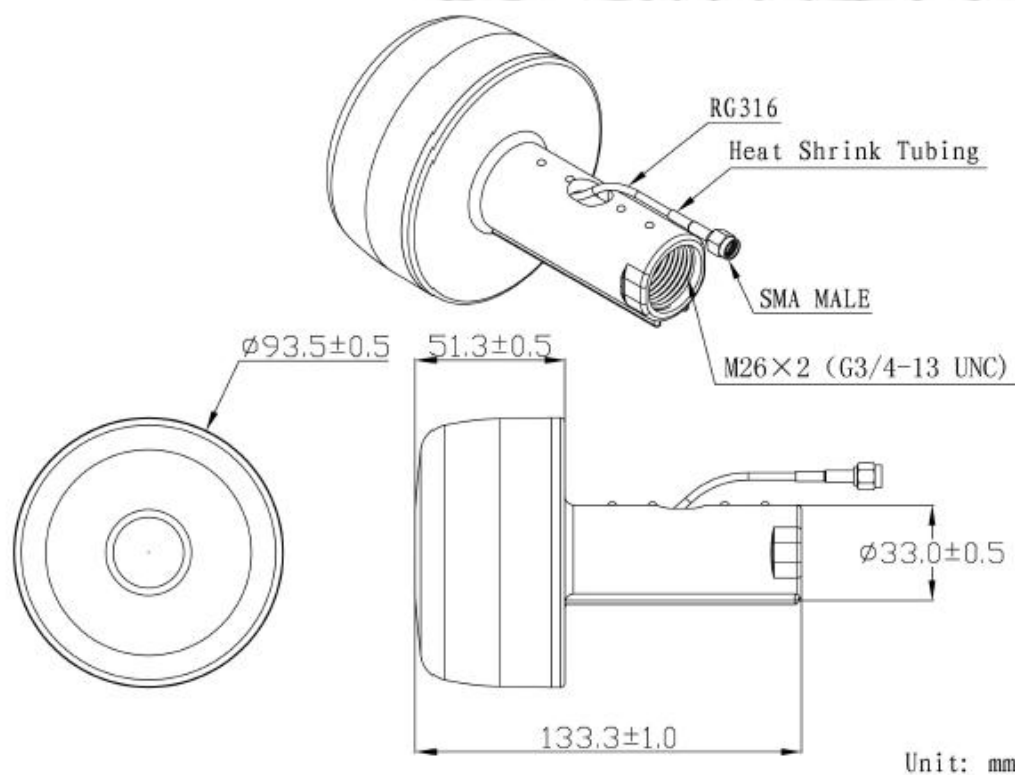

Heavy Duty Marine Iridium Antenna Screw Mount

AN_Iridium_005

Specifications

Item		Specifications
Antenna	Center Frequency	1616-1626.5MHz
	Band Width	10.5MHz
	Polarization	RHCP
	Gain	5dBic (Zenith)
	V.S.W.R	<1.5
	Impedance	50Ω
	Axial Ratio	5dB(max)
Mechanical	Cable	RG316 5m
	Connector	SMA male
	Radome Material	ABS
	Mounting Method	Screw
Environmental	Operating Temperature	-40℃~+85℃
	Relative Humidity	Up to 95%
	Ingress Protection	IP67
	Vibration	10 to 55Hz with 1.5mm amplitude 2hours
	Environmentally Friendly	ROHS Compliant

Heavy Duty Marine Iridium Antenna Screw Mount

AN_Iridium_005

Radiation Patterns

