


# EPIC® HA 10 Standard & High Profile Hoods

## Single Lever Bolts

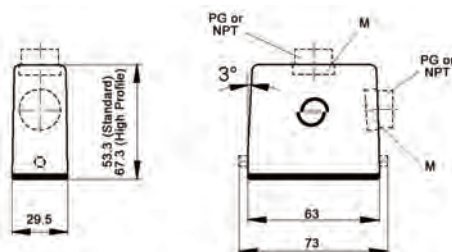

All dimensions are in mm.

### Technical Data

|                           |                               |                          |                              |
|---------------------------|-------------------------------|--------------------------|------------------------------|
| <b>Specifications:</b>    | DIN 43652, DIN 50262 (metric) | <b>Protection Class:</b> | NEMA 4, NEMA 12, IP65        |
| <b>Temperature Range:</b> | -40°C to +125°C               | <b>Material:</b>         | Powder-coated aluminum alloy |

| PG                           | Size of Entry |        | PG     | Part Number |          | Metric*  | Complete the Installation: SKINTOP® Strain Relief, page 368 |          |              |              |
|------------------------------|---------------|--------|--------|-------------|----------|----------|-------------------------------------------------------------|----------|--------------|--------------|
|                              | NPT           | Metric |        | NPT         | Metric   |          | PG Nylon                                                    | PG Metal | Metric Nylon | Metric Metal |
| Standard Profile: Top Entry  |               |        |        |             |          |          |                                                             |          |              |              |
| 13                           | ½"            | 20     | 104460 | 104460NP    | 19446000 | 53015030 | 52015730                                                    | 53111020 | 53112020     |              |
| 16                           | ½"            | 25     | 104461 | 104461NP    | 19446100 | 53015040 | 52015740                                                    | 53111030 | 53112030     |              |
| Standard Profile: Side Entry |               |        |        |             |          |          |                                                             |          |              |              |
| 16                           | ½"            | 20     | 104450 | 104450NP    | 19445000 | 53015040 | 52015740                                                    | 53111020 | 53112020     |              |
| 21                           | ¾"            | 25     | 104455 | 104455NP    | 19445500 | 53015050 | 52015750                                                    | 53111030 | 53112030     |              |
| High Profile: Top Entry      |               |        |        |             |          |          |                                                             |          |              |              |
| 16                           | ½"            | 20     | 704602 | 704602NP    | 79460200 | 53015040 | 52015740                                                    | 53111020 | 53112020     |              |
| 21                           | ¾"            | 25     | 704604 | 704604NP    | 79460400 | 53015040 | 52015740                                                    | 53111020 | 53112020     |              |
| High Profile: Side Entry     |               |        |        |             |          |          |                                                             |          |              |              |
| 16                           | ½"            | 20     | 704622 | 704622NP    | 79462200 | 53015040 | 52015740                                                    | 53111020 | 53112020     |              |
| 21                           | ¾"            | 25     | 704624 | 704624NP    | 79462400 | 53015050 | 52015750                                                    | 53111030 | 53112030     |              |

\* Top entry metric and high profile metric hoods do not come with a neck

### Approvals





### Complete the Installation



HA Dust  
Covers:  
page 415

# EPIC® HA 10 Panel Mount Bases

## Single Lever

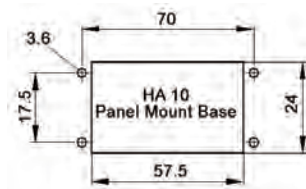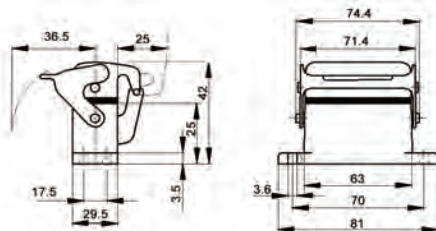

All dimensions are in mm.

### Technical Data

|                           |                               |                          |                              |
|---------------------------|-------------------------------|--------------------------|------------------------------|
| <b>Specifications:</b>    | DIN 43652, DIN 50262 (metric) | <b>Protection Class:</b> | NEMA 4, NEMA 12, IP65        |
| <b>Temperature Range:</b> | -40°C to +125°C               | <b>Material:</b>         | Powder-coated aluminum alloy |

| Description                      | Part Number |
|----------------------------------|-------------|
| Panel Mount Base                 | 104420C0    |
| Panel Mount Base with Dust Cover | 704440C0    |

### Complete the Installation



HA Dust  
Covers:  
page 415

### Approvals




Photographs are not to scale and are not true representations of the products in question.

For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.

# EPIC® HA 10 Surface Mount Bases

## Single Lever

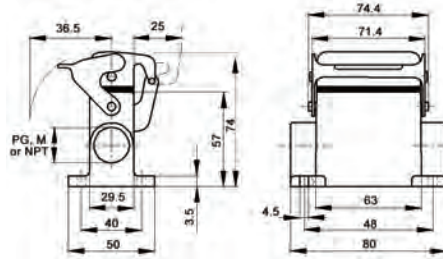

All dimensions are in mm.



### Technical Data

|                           |                               |                          |                              |
|---------------------------|-------------------------------|--------------------------|------------------------------|
| <b>Specifications:</b>    | DIN 43652, DIN 50262 (metric) | <b>Protection Class:</b> | NEMA 4, NEMA 12, IP65        |
| <b>Temperature Range:</b> | -40°C to +125°C               | <b>Material:</b>         | Powder-coated aluminum alloy |

| PG                               | Size of Entry |        | PG     | Part Number |          | Complete the Installation: SKINTOP® Strain Relief, page 368 |          |              |              |
|----------------------------------|---------------|--------|--------|-------------|----------|-------------------------------------------------------------|----------|--------------|--------------|
| PG                               | NPT           | Metric | PG     | NPT         | Metric   | PG Nylon                                                    | PG Metal | Metric Nylon | Metric Metal |
| <b>2 Entries</b>                 |               |        |        |             |          |                                                             |          |              |              |
| 16                               | 1/2"          | 20     | 104501 | 104501NP    | 19450100 | 53015040                                                    | 52015740 | 53111020     | 53112020     |
| 21                               | 3/4"          | 25     | 104500 | 104500NP    | 19450000 | 53015050                                                    | 52015750 | 53111030     | 53112030     |
| <b>1 Entry</b>                   |               |        |        |             |          |                                                             |          |              |              |
| 16                               | 1/2"          | 20     | 104481 | 104481NP    | 19448100 | 53015040                                                    | 52015740 | 53111020     | 53112020     |
| 21                               | 3/4"          | 25     | 104480 | 104480NP    | 19448000 | 53015050                                                    | 52015750 | 53111030     | 53112030     |
| <b>2 Entries with Dust Cover</b> |               |        |        |             |          |                                                             |          |              |              |
| 16                               | 1/2"          | 20     | 704562 | 704562NP    | 79456200 | 53015040                                                    | 52015740 | 53111020     | 53112020     |
| 21                               | 3/4"          | 25     | 704564 | 704564NP    | 79456400 | 53015050                                                    | 52015750 | 53111030     | 53112030     |
| <b>1 Entry with Dust Cover</b>   |               |        |        |             |          |                                                             |          |              |              |
| 16                               | 1/2"          | 20     | 704552 | 704552NP    | 79455200 | 53015040                                                    | 52015740 | 53111020     | 53112030     |
| 21                               | 3/4"          | 25     | 704554 | 704554NP    | 79455400 | 53015050                                                    | 52015750 | 53111030     | 53112030     |

### Approvals




### Complete the Installation



HA Dust  
Covers:  
page 415

# EPIC® HA 10 Cable Coupler Hoods

## Single Lever

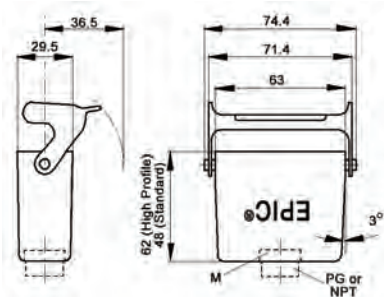

All dimensions are in mm.



### Technical Data

|                           |                               |                          |                              |
|---------------------------|-------------------------------|--------------------------|------------------------------|
| <b>Specifications:</b>    | DIN 43652, DIN 50262 (metric) | <b>Protection Class:</b> | NEMA 4, NEMA 12, IP65        |
| <b>Temperature Range:</b> | -40°C to +125°C               | <b>Material:</b>         | Powder-coated aluminum alloy |

| PG                      | Size of Entry |        | PG     | Part Number |          | Complete the Installation: SKINTOP® Strain Relief, page 368 |          |              |              |
|-------------------------|---------------|--------|--------|-------------|----------|-------------------------------------------------------------|----------|--------------|--------------|
| PG                      | NPT           | Metric | PG     | NPT         | Metric*  | PG Nylon                                                    | PG Metal | Metric Nylon | Metric Metal |
| <b>Standard Profile</b> |               |        |        |             |          |                                                             |          |              |              |
| 13                      | 1/2"          | 20     | 104390 | 104390NP    | 19439000 | 53015030                                                    | 52015700 | 53111020     | 53112020     |
| 16                      | 1/2"          | 25     | 704500 | 704500NP    | 79450000 | 53015040                                                    | 52015740 | 53111030     | 53112030     |
| <b>High Profile</b>     |               |        |        |             |          |                                                             |          |              |              |
| 21                      | 3/4"          | 25     | 704504 | 704504NP    | 79450400 | 53015050                                                    | 52015750 | 53111030     | 53112030     |

\* Metric hoods do not come with a neck

### Approvals



### Complete the Installation



HA Dust  
Covers:  
page 415

Photographs are not to scale and are not true representations of the products in question.  
For current information go to our website. If not otherwise specified, all values relating to the product are nominal values.