


Mechanical Specifications

D	6.0mm Max
T	3.5mm Max
Lead Diameter	0.5 ±0.1mm
S	5.1 ±0.2mm
L	38mm Min
Coating run down	2.5mm Max
B	3.0mm Nom
C	1.0mm Nom

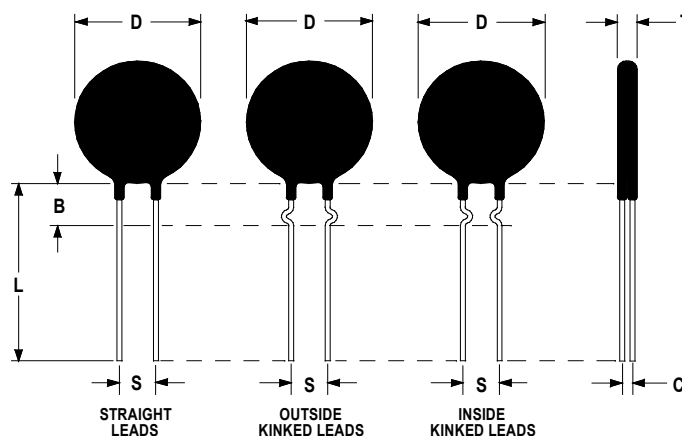

Electrical Specifications

Resistance @ 25°C	10Ω ±20%
Max Steady State Current Up to 65°C	1.0 A
Max recommended energy rating (Joules)	6.0 J
Max Voltage	240 VAC
Max Capacitance @ 120 VAC / 240VAC	120μF / 30μF
Resistance @ 100% of Max Current	0.85 Ω
Resistance @ 50% of Max Current	2.2 Ω
Body Temperature @ 100% Current rating	149°C
Dissipation Constant	6.5 mW/°C
Thermal Time Constant	16 seconds
Material Type	B

Revision:	Date:	Change:
0	11/11/08	Issue
1	8/7/20	Reformat

Ametherm, Inc
961 Fairview Dr.
Carson City, NV 89701
Telephone: **800-808-2434**
Fax: 775 884-0670
www.Ametherm.com