


# CLIFF

## 4mm PANEL SOCKET S16N

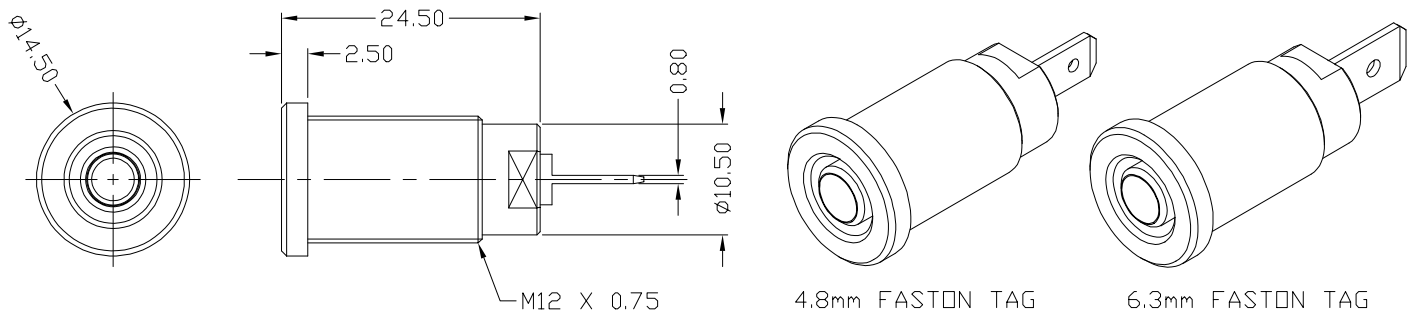

**FCR73575A**  
S16N/4.8 GREY WNW



**FCR73575B**  
S16N/4.8 BLACK WNW

**FCR7356B**  
S16N/6.3 BLACK WNW



**FCR73575G**  
S16N/4.8 GREEN WNW

**FCR7356G**  
S16N/6.3 GREEN WNW



**FCR73575L**  
S16N/4.8 BLUE WNW

**FCR7356**  
S16N/6.3 BLUE WNW



**FCR73575R**  
S16N/4.8 RED WNW

**FCR7356R**  
S16N/6.3 RED WNW



**FCR73575Y**  
S16N/4.8 YELLOW WNW

**FCR7356Y**  
S16N/6.3 YELLOW WNW



**FCR73575W**  
S16N/4.8 WHITE WNW

Shrouded, 4mm, nickel or tin plated socket. Mates with shrouded or unshrouded plugs.  
Rated 1000V, CAT III. 24A for 4.8mm Faston  
32A for 6.3mm Faston  
Supplied with M12 slotted ring nut and washer.