

**Amps**

**Poles**




**Pack unit**

**Net weight**

3pole 4pole 5pole  
4h 4h 4h 6h 9h 9h 9h 6h 6h 7h 7h 7h 10h 10h 10h 2h 2h 2h

A	P	TYP							pcs/package	g/pcs
16	3	R2314		<b>R231</b>	R2319	R2317	R2310	R2312	10	118
	4	R2334		R2339	<b>R233</b>	R2337	R2330	R2332	10	122
	5	R2354		R2359	<b>R235</b>	R2357	R2350	R2352	10	165
32	3	R2814		<b>R281</b>	R281900	R2817	R2810	R2812	10	220
	4	R2834		R2839	<b>R283</b>	R2837	R2830	R2832	10	239
	5	R2854		R2859	<b>R285</b>	R2857	R2850	R2852	10	260

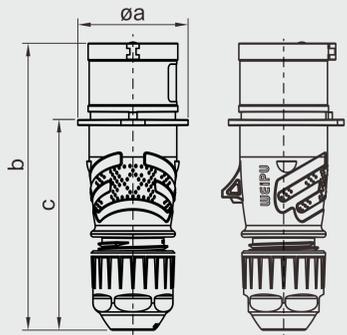

Amp.	16			32		
Poles	3	4	5	3	4	5
a	51	59	68	70	70	77.5
b	139	139	144	169.5	169.5	171.5
c	101	102	107	123.5	123.5	125.5
Min wire size (mm <sup>2</sup> )	1.5	1.5	1.5	2.5	2.5	2.5
Max wire size (mm <sup>2</sup> )	4	4	4	10	10	10
Cable outer diameter range (mm)	10~14	10~14	10~14	13~19	13~19	13~19

- Plug**
- Clamping cable fix
  - IP44 ⚠