


CLIFF

SLIM SMA (F-F) 50Ω FRONT MOUNTING METAL FRAME FEEDTHROUGH

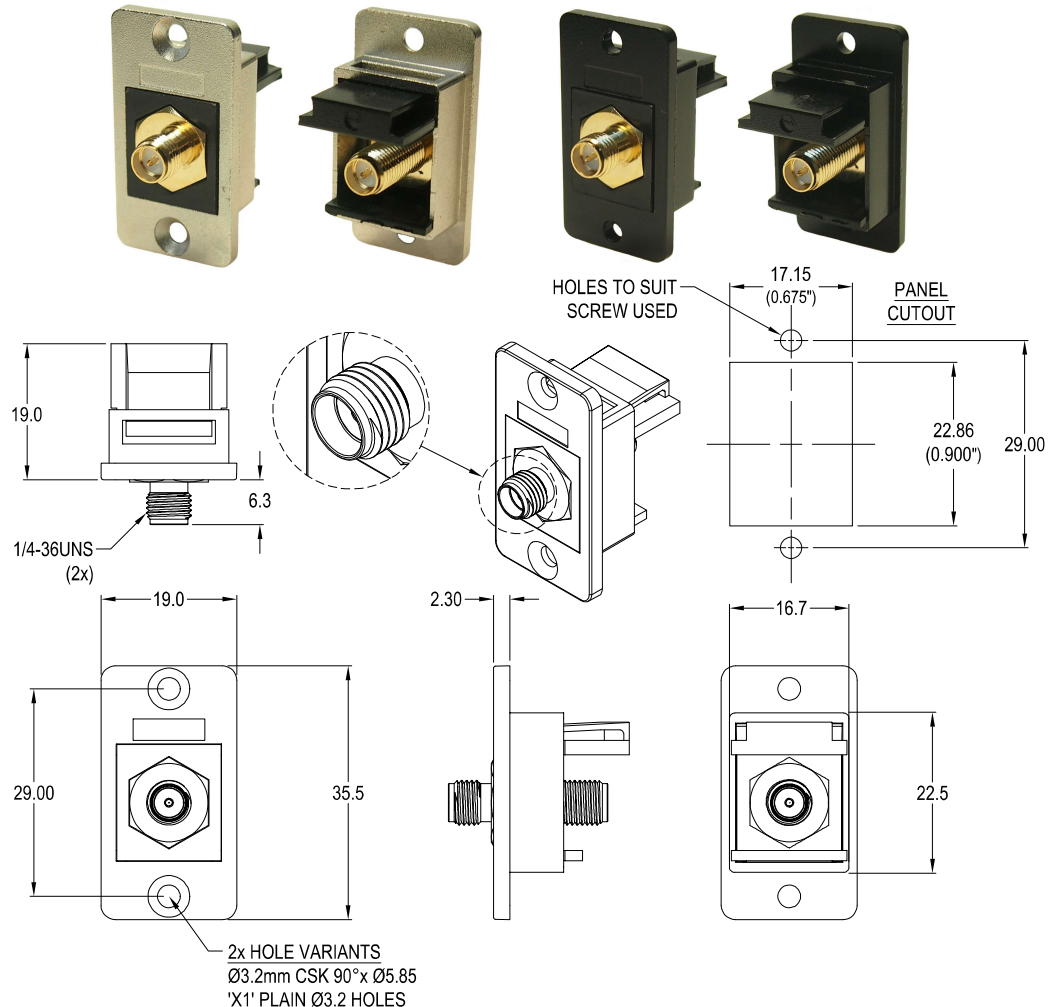

VARIANTS

Part No.

CP30660M	SLIM FM SMA (F-F) 50Ω Nickel frame, CSK holes
CP30660MB	SLIM FM SMA (F-F) 50Ω Black metal frame, CSK holes
CP30660MX1	SLIM FM SMA (F-F) 50Ω Nickel frame, Ø3.2 PLAIN holes
CP30660MBX1	SLIM FM SMA (F-F) 50Ω Black metal frame, Ø3.2 PLAIN holes

Feedthrough Features

- Fits standard rectangular cutout.
- Various hole mounting options.
- No soldering or punch termination. Use standard cable for each connector style.
- Low rear profile.

General:

Please note: Functionality is affected by cable quality, length and cable wiring configuration.

Material:

1. Body: Brass, Gold plated
2. Insulation: Teflon
3. SMA Pin A+B: Brass, Gold plated
4. Nut: Brass, Gold plated
5. Frame: ABS UL94-V2
6. FT Frame: Zinc Diecast, Nickel or Black plated

SPECIFICATION

Impedance:	50 Ohm
Frequency:	10MHz - 18GHz
Operating Temp:	-30°C to 80°C
Plug A:	Female SMA
Plug B:	Female SMA