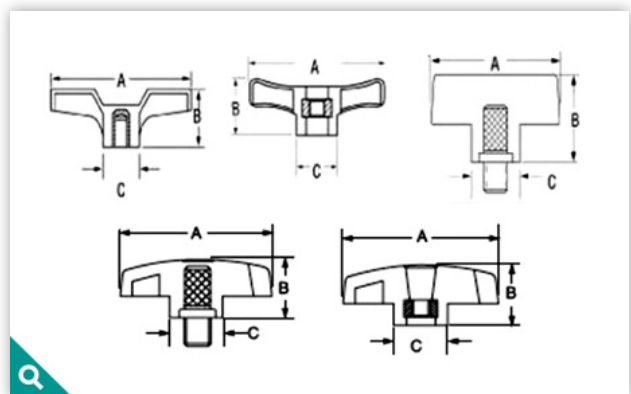


Bar/T Knobs

Series #3084

- Over 20 different shapes of bar knobs and T knobs available in both thermoplastic and phenolic materials.
- Sizes ranging from 1-1/32" to 3-3/8" in diameter.
- Female insert, projecting stud and thru-hole bar knobs options.
- Click on the part number for additional information and search by diameter, mounting, material, etc.
- Knobs can be decorated or customized to your specific need.
- Colors available upon request.
- Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

[CHECK INVENTORY](#)
[REQUEST A QUOTE](#)


Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
3084	1.25	0.83	0.625	Thermoplastic	1/4-20	Female Insert	0.375	BLACK	Download
3084-A	1.25	0.83	0.625	Thermoplastic	5/16-18	Projecting Stud	0.75	BLACK	Download
3084-B	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	1.00	BLACK	Download
3084-C	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.50	BLACK	Download
3084-E	1.25	0.83	0.625	Thermoplastic	1/4-20	Thru-Hole		BLACK	Download
3084-F	1.25	0.83	0.625	Thermoplastic	5/16-18	Female Insert	0.50	BLACK	Download
3084-G	1.25	0.83	0.625	Thermoplastic	5/16-18	Thru-Hole		BLACK	Download
3084-K	1.25	0.83	0.625	Thermoplastic	M6x1-6g	Projecting Stud	0.31	BLACK	Download
3084-L	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.75	BLACK	Download
3084-Q	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud w/ Hex Bolt	0.75	BLACK	Download
3084-U	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	1.25	BLACK	Download
3084-Y	1.25	0.83	0.625	Thermoplastic	1/4-20	Thru-Hole		BLACK	Download
3084-Z	1.25	0.83	0.625	Thermoplastic	5/16-18	Projecting Stud	0.50	BLACK	Download
3084AA	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	1.81	BLACK	Download
3084AC	1.25	0.83	0.625	Thermoplastic	1/4-20	Female Insert	0.50	BLACK	Download
3084AD	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.75	BLACK	Download
3084AF	1.25	0.83	0.625	Thermoplastic	5/16-18	Projecting Stud	1.00	BLACK	Download
3084AG	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.50	BLACK	Download
3084AH	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.625	BLACK	Download

3084AJ	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.625	BLACK	Download
3084AJ	1.25	0.83	0.625	Thermoplastic	1/4-20	Thru-Hole SS		Black	
3084AL	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	2.25	BLACK	Download
3084AN	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	1.75	BLACK	Download
3084AS	1.25	0.83	0.625	Thermoplastic	10-24	Projecting Stud	1.00	BLACK	Download
3084AU	1.25	0.83	0.625	Thermoplastic	1/4-20	Projecting Stud	0.375	BLACK	Download
3084AV	1.25	0.83	0.625	Thermoplastic	1/4-20	Thru-Hole		BLACK	Download
3084AW	1.25	0.83	0.625	Thermoplastic	5/16-18	Projecting Stud	0.625	BLACK	Download
3084BJ	1.25	0.83	0.625	Thermoplastic	M6	Female Insert		BLACK	
3084BK	1.25	0.83	0.625	Thermoplastic	M8	Female Insert		BLACK	
3084BL	1.25	0.83	0.625	Thermoplastic	M6	Projecting Stud		BLACK	
3084BM	1.25	0.83	0.625	Thermoplastic	M6	Projecting Stud		BLACK	
3084BN	1.25	0.83	0.625	Thermoplastic	M8	Projecting Stud		BLACK	
3084BP	1.25	0.83	0.625	Thermoplastic	M8	Projecting Stud		BLACK	

PRODUCTS

[Knobs](#)
[Handles](#)
[Electronic Enclosures](#)
[Hex Hybrid Standoffs](#)
[Two-Shot / Soft Touch](#)
[Frac Balls](#)
[Cable Glands](#)
[Rubber Grommets](#)
[Custom Molding](#)

RESOURCES

[Engineering Specifications](#)
[Distributor Listing](#)
[Sales Representative Listing](#)

COMPANY

[About Us](#)
[Capabilities](#)
[Certifications](#)
[Contact Us](#)
[Blog](#)
[Careers](#)

QUESTIONS ?

1 + 1 = *

SEND