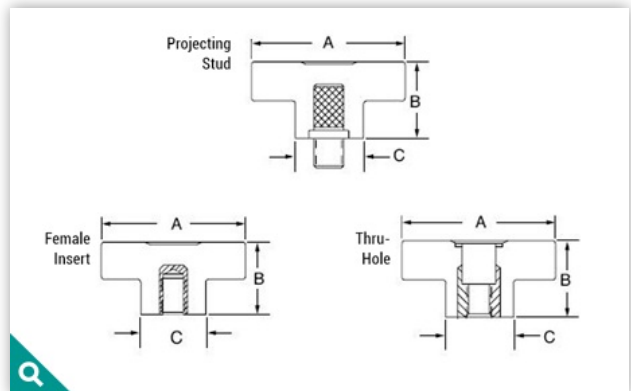


## Four Arm Clamping Knobs

### Series #2820

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

[CHECK INVENTORY](#)
[REQUEST A QUOTE](#)


| Item # | Diameter A | Height B | Hub C | Material Type | Mounting Diameter | Mounting Type   | Thread Length/Depth | Color | Product Drawing          |
|--------|------------|----------|-------|---------------|-------------------|-----------------|---------------------|-------|--------------------------|
| 2820   | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Female Insert   | 0.375               | BLACK | <a href="#">Download</a> |
| 2820-A | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Female Insert   | 0.50                | BLACK | <a href="#">Download</a> |
| 2820-B | 1.5        | 1.00     | 0.625 | Thermoset     | 3/8-16            | Female Insert   | 0.50                | BLACK | <a href="#">Download</a> |
| 2820-C | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 0.56                | BLACK | <a href="#">Download</a> |
| 2820-D | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 0.50                | BLACK | <a href="#">Download</a> |
| 2820-E | 1.5        | 1.00     | 0.625 | Thermoset     | 3/8-16            | Projecting Stud | 1.00                | BLACK | <a href="#">Download</a> |
| 2820-F | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 0.50                | BLACK | <a href="#">Download</a> |
| 2820-G | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 1.00                | BLACK | <a href="#">Download</a> |
| 2820-H | 1.5        | 1.00     | 0.625 | Thermoset     | 3/8-24            | Female Insert   | 0.625               | BLACK | <a href="#">Download</a> |
| 2820-J | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 1.00                | BLACK | <a href="#">Download</a> |
| 2820-N | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 0.75                | BLACK | <a href="#">Download</a> |
| 2820-R | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 1.125               | BLACK | <a href="#">Download</a> |
| 2820-T | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 1.25                | BLACK | <a href="#">Download</a> |
| 2820-X | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 1.25                | BLACK | <a href="#">Download</a> |
| 2820-Y | 1.5        | 1.00     | 0.625 | Thermoset     | 5/16-18           | Projecting Stud | 1.75                | BLACK | <a href="#">Download</a> |
| 2820AC | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 0.875               | BLACK | <a href="#">Download</a> |
| 2820AE | 1.5        | 1.00     | 0.625 | Thermoset     | 3/8-16            | Projecting Stud | 0.50                | BLACK | <a href="#">Download</a> |
| 2820AG | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Female Insert   | 0.375               | RED   | <a href="#">Download</a> |
| 2820AK | 1.5        | 1.00     | 0.625 | Thermoset     | 1/4-20            | Projecting Stud | 0.75                | BLACK | <a href="#">Download</a> |

| 2820AL | 1.5 | 1.00 | 0.625 | Thermoset | 3/8-16  | Projecting Stud    | 1.50  | BLACK | <a href="#">Download</a> |
|--------|-----|------|-------|-----------|---------|--------------------|-------|-------|--------------------------|
| 2820AL | 1.5 | 1.00 | 0.625 | Thermoset | 3/8-16  | Projecting Stud    | 1.50  | BLACK | <a href="#">Download</a> |
| 2820AM | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Projecting Stud    | 0.31  | BLACK | <a href="#">Download</a> |
| 2820AP | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Thru-Hole          |       | TAN   | <a href="#">Download</a> |
| 2820AT | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Thru-Hole          |       | BLACK | <a href="#">Download</a> |
| 2820AU | 1.5 | 1.00 | 0.625 | Thermoset | 5/16-18 | Thru-Hole          |       | BLACK | <a href="#">Download</a> |
| 2820AV | 1.5 | 1.00 | 0.625 | Thermoset | 3/8-16  | Thru-Hole          |       | BLACK | <a href="#">Download</a> |
| 2820AW | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Female Insert      | 0.50  | BLACK | <a href="#">Download</a> |
| 2820BA | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Projecting Stud    | 0.75  | BLACK | <a href="#">Download</a> |
| 2820BE | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Projecting Stud    | 0.375 | BLACK | <a href="#">Download</a> |
| 2820BF | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Female Insert      | 0.375 | WHITE | <a href="#">Download</a> |
| 2820BG | 1.5 | 1.00 | 0.625 | Thermoset | 10-24   | Projecting Stud    | 0.50  | BLACK | <a href="#">Download</a> |
| 2820BH | 1.5 | 1.00 | 0.625 | Thermoset | 5/16-18 | Projecting Stud    | 1.50  | BLACK | <a href="#">Download</a> |
| 2820BJ | 1.5 | 1.00 | 0.625 | Thermoset | 5/16-18 | Projecting Stud    | 2.25  | BLACK | <a href="#">Download</a> |
| 2820BL | 1.5 | 1.00 | 0.625 | Thermoset | 1/4-20  | Projecting Stud    | 0.75  | BLUE  | <a href="#">Download</a> |
| 2820BM | 1.5 | 1.00 | 0.625 | Thermoset | M6      | Female Insert      |       | BLACK |                          |
| 2820BP | 1.5 | 1.00 | 0.625 | Thermoset | 8-32    | Projecting Stud SS | 0.56  | Black |                          |
| 2820BQ | 1.5 | 1.00 | 0.625 | Thermoset | 8-32    | Projecting Stud SS | 1.00  | Black |                          |
| 2820BS | 1.5 | 1.00 | 0.625 | Thermoset | 10-32   | Projecting Stud SS | 1.00  | Black |                          |
| 2820CQ | 1.5 | 1.00 | 0.625 | Thermoset | M8      | Female Insert      |       | BLACK |                          |
| 2820CR | 1.5 | 1.00 | 0.625 | Thermoset | M6      | Projecting Stud    | 20    | BLACK |                          |
| 2820CS | 1.5 | 1.00 | 0.625 | Thermoset | M6      | Projecting Stud    | 30    | BLACK |                          |
| 2820CT | 1.5 | 1.00 | 0.625 | Thermoset | M8      | Projecting Stud    | 20    | BLACK |                          |
| 2820CU | 1.5 | 1.00 | 0.625 | Thermoset | M8      | Projecting Stud    | 30    | BLACK |                          |

#### PRODUCTS

[Knobs](#)  
[Handles](#)  
[Electronic Enclosures](#)  
[Hex Hybrid Standoffs](#)  
[Two-Shot / Soft Touch](#)  
[Frac Balls](#)  
[Cable Glands](#)  
[Rubber Grommets](#)  
[Custom Molding](#)

#### RESOURCES

[Engineering Specifications](#)  
[Distributor Listing](#)  
[Sales Representative Listing](#)

#### COMPANY

[About Us](#)  
[Capabilities](#)  
[Certifications](#)  
[Contact Us](#)  
[Blog](#)  
[Careers](#)

#### QUESTIONS ?






1 + 1 =  \*

SEND