
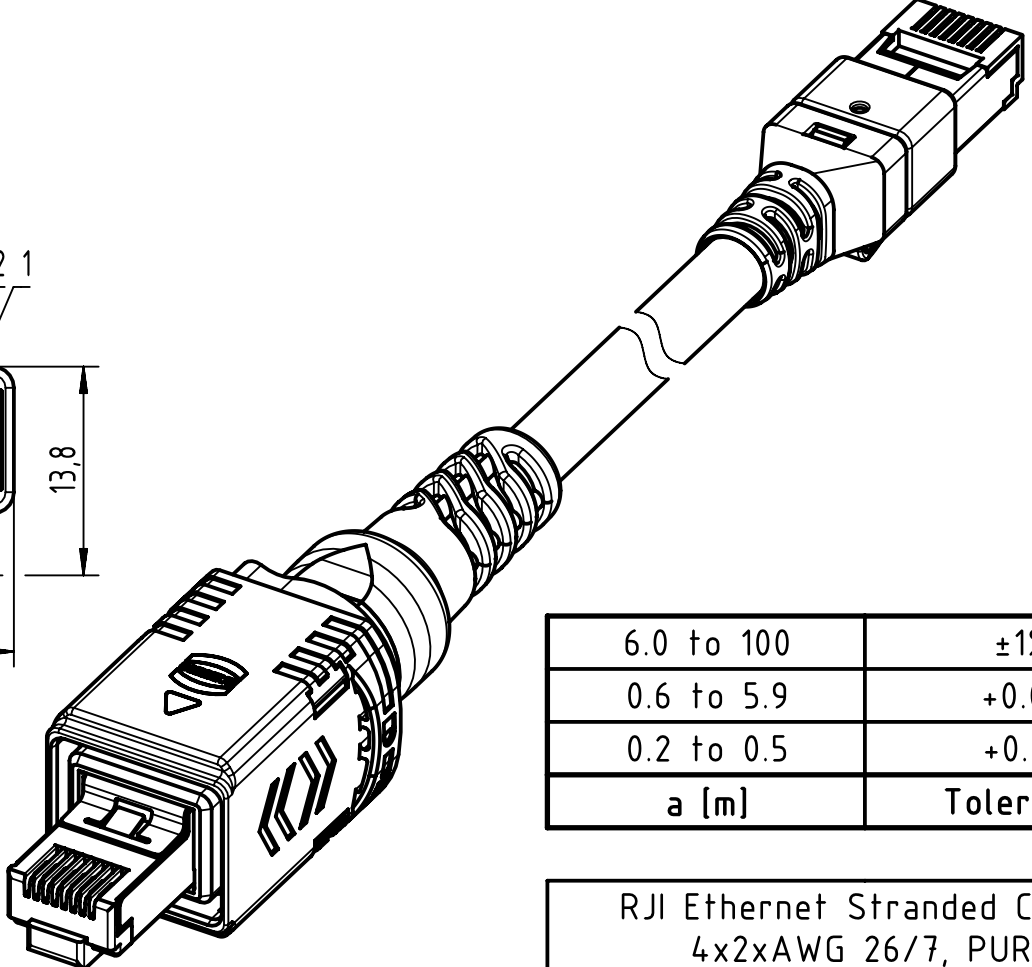
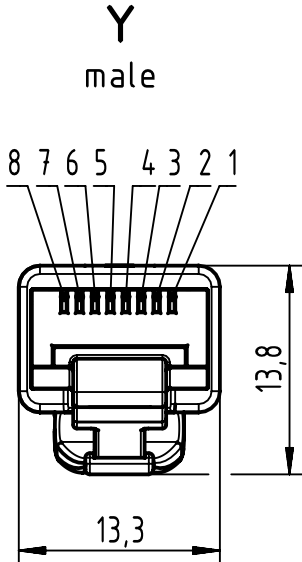
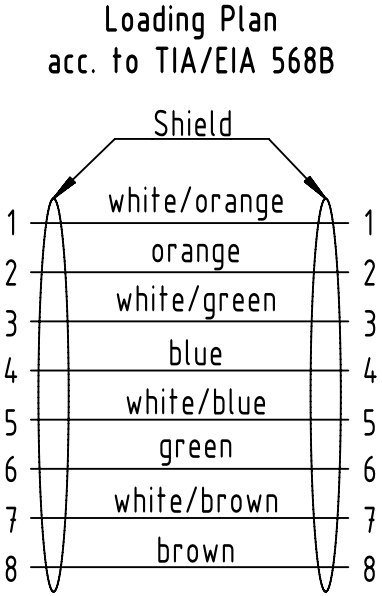
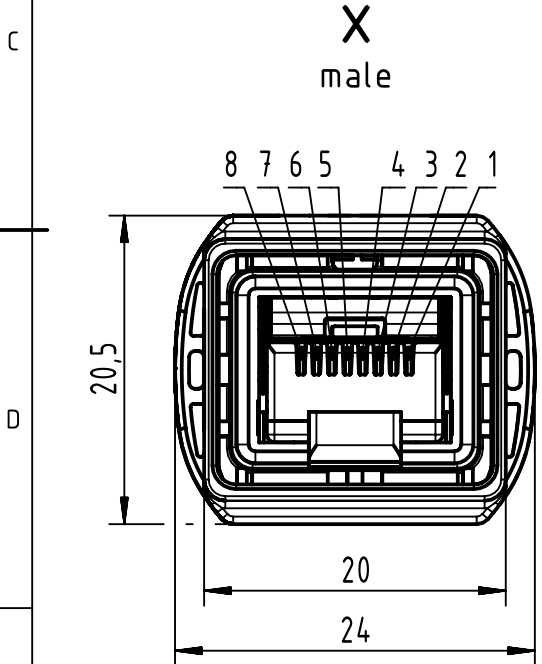


Connector Location A

Connector Location B

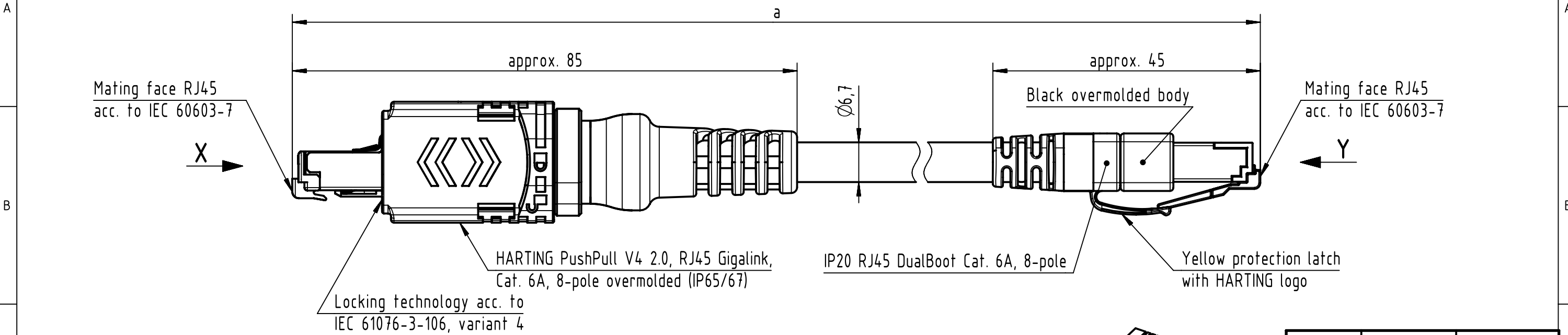

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

RJI Ethernet Stranded Cable, 4x2xAWG 26/7, PUR, Cat. 6A, yellow	09482847756XXX
Type of cable	Part no.

Temperature range:
- Fixed installation: -40°C ... +80°C
- Dynamic installation: -40°C ... +80°C

NOTE:
* For lengths < 1.0m:
- relative positioning of the connectors to each other will be as presented in the drawing, however with an admissible angular deviation around cable axis of ± 30°
* For lengths ≥ 1.0m:
- relative positioning of the connectors to each other not obligatory
* Ethernet transmission possible for lengths up to 45m

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by COSTEA Costea	Inspected by 402676 Gross	Standardisation MUNTEANV Muntean	Date 2020-11-02	State Final Release	
	Department HCS - RO	Title PPV4 2.0 RJ45 - RJ45 IP20 Cat6A PUR				Doc-Key / ECM-Nr. 100696529/UGD/001/F 500000182295	
	HARTING Customised Solutions D-32339 Espelkamp	Type TB	Number 09482847756XXX			Rev. F	Page 1/1