


## EPIC® M-D 1.0 D-Sub stamped contacts-on-reel

For inserts and modules of the EPIC® rectangular connectors

### Info

Gold plated contacts in 2 quality levels  
for automated production with crimping machine  
Two crimp areas with wire and insulation crimp

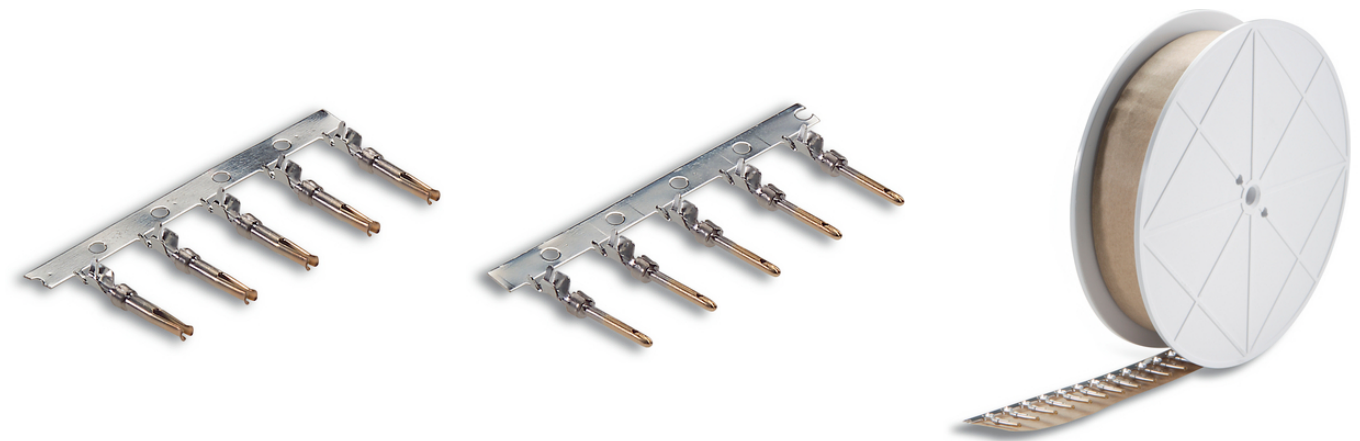

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000796

ETIM 5.0 Class-Description: Contact for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000796

ETIM 6.0 Class-Description: Contact for industrial connectors

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® M-D 1.0 D-Sub stamped contacts-on-reel**

| Article number | Article description                          | Contact type | Conductor cross-section (mm²) | Surface     | Stripping length (mm) | Note                             | Packaging unit |
|----------------|----------------------------------------------|--------------|-------------------------------|-------------|-----------------------|----------------------------------|----------------|
| Contacts       |                                              |              |                               |             |                       |                                  |                |
| 44429011       | EPIC® D-SUB SCBG<br>AU G2 0,08-0,22<br>(500) | male         | 0.08 - 0.22                   | Au (0.8 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429007       | EPIC® D-SUB BCBG<br>AU G2 0,08-0,22<br>(500) | female       | 0.08 - 0.22                   | Au (0.8 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429013       | EPIC® D-SUB SCBG<br>AU G3 0,08-0,22<br>(500) | male         | 0.08 - 0.22                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429009       | EPIC® D-SUB BCBG<br>AU G3 0,08-0,22<br>(500) | female       | 0.08 - 0.22                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429012       | EPIC® D-SUB SCBG<br>AU G2 0,22-0,56<br>(500) | male         | 0.22 - 0.56                   | Au (0.8 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429008       | EPIC® D-SUB BCBG<br>AU G2 0,22-0,56<br>(500) | female       | 0.22 - 0.56                   | Au (0.8 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429014       | EPIC® D-SUB SCBG<br>AU G3 0,22-0,56<br>(500) | male         | 0.22 - 0.56                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429010       | EPIC® D-SUB BCBG<br>AU G3 0,22-0,56<br>(500) | female       | 0.22 - 0.56                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 500<br>contacts    | 1              |
| 44429030       | EPIC® D-SUB SCBG<br>AU G3 0,22-0,56<br>(10k) | male         | 0.22 - 0.56                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 10.000<br>contacts | 1              |
| 44429031       | EPIC® D-SUB BCBG<br>AU G3 0,22-0,56<br>(10k) | female       | 0.22 - 0.56                   | Au (0.1 µm) | 2.5 + 0.5             | 1 reel (PU) = 10.000<br>contacts | 1              |

**EPIC® M-D 1.0 D-Sub stamped contacts-on-reel**