


GM520 Pressure Manometer

XE-4011-001

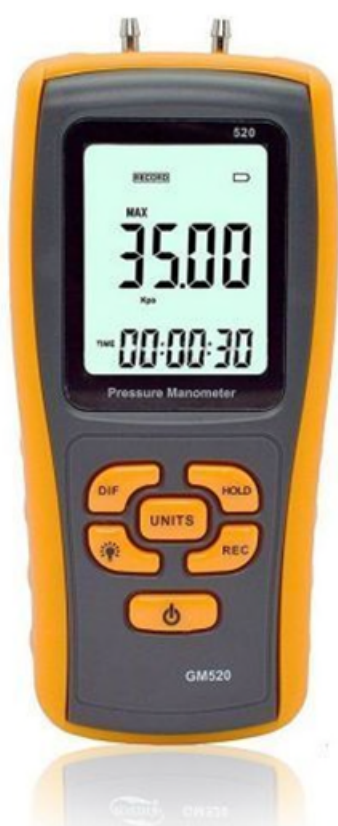

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Model	GM520 Pressure Manometer
Series	Pressure Manometer
Communications Protocol	USB communication
Accuracy	+/- 0.3% FSO (25°C)
Repeatability	+/- 0.2% (Maximum +/- 0.5% FSO)
Response	Typical 0.5 s
Linearity/hysteresis	+/- 0.29% FSO
Maximum Pressure	+/- 150kPa
Storage Temperature Range	-10 to 60°C
Ambient Operating Temperature	0 to 50°C
Measuring range	+/- 35kPa

