



Image shown is a representation only. Exact specifications should be obtained from the product dimension

PRODUCT NAME:	Male Contact 16A Crimp Pin 16AWG
REVISION:	A3
NEXTGEN ORDER PART CODE*:	CESM1M5000L001
CROSS REF. PART NO.:	09330006104
ORIGINAL MFG PART CODE:	CESM - 1.5
ORIGINAL MFG PART NO.:	1010191100901
ORIGINAL MANUFACTURER:	Wain Electrical/Wain Connectors

*: Please Indicate this Part Code For RFQ/Order Support

WAIN
CONNECTORS



AUTHORIZED DISTRIBUTOR


NextGen Components, Inc.

 
US Warehouse Location: 9 Orchard Road, Suit 106, Lake Forest, CA 92630, USA

RFQ/Order Support: sales@NextGenComponent.com

Note: This coversheet was created by NextGen Components, Inc. ("NextGen"). The attached last document was created by the part manufacturer, not NextGen, and is provided strictly 'as is.' NextGen, its subsidiaries, affiliates, employees, and agents make no representations or warranties regarding the attached last document and disclaim any liability for the consequences of relying on the information therein. All referenced brands, product names, service names, and trademarks are the property of their respective owners.

DIMENSION – Unit: mm

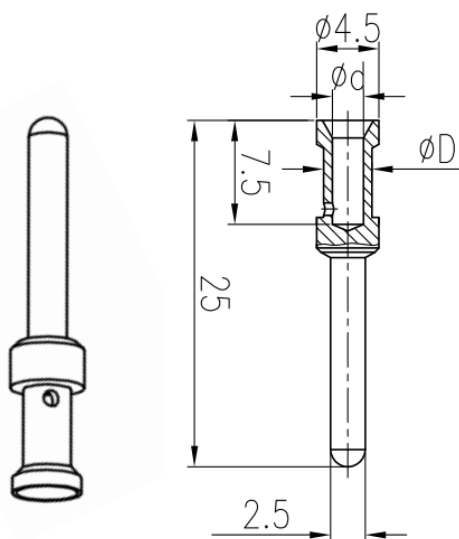

No.	No.1	No.2	No.3	No.4	No.5	No.6
Marked Graph						

NEXTGEN ORDER PART CODE	ORIGINAL MFG PART CODE	ORIGINAL MFG PART NUMBER	d	D	h	Identification	Identification No.
CESM0M3700L001	CESM- 0.37	1010191100301	0.9	1.8	7.5	No Groove	No.1
CESM0M5000L001	CESM- 0.50	1010191100401	1.15	2.6	7.5	No Groove	No.1
CESM0M7500L001	CESM- 0.75	1010191100601	1.30	2.6	7.5	1 Groove	No.2
CESM1M0000L001	CESM- 1.0	1010191100801	1.45	2.6	7.5	1 Groove	No.3
CESM1M5000L001	CESM- 1.5	1010191100901	1.75	3.0	7.5	2 Groove	No.4
CESM2M5000L001	CESM- 2.5	1010191101001	2.25	3.5	7.5	3 Groove	No.5
CESM3M0000L001	CESM- 3.0	1010191101101	2.55	3.7	7.5	With Groove	No.6
CESM4M0000L001	CESM- 4.0	1010191101201	2.85	3.9	7.5	No Groove	No.1

GENERAL PRODUCT ATTRIBUTES

ATTRIBUTE	DESCRIPTION
Product Category	Connectors, Interconnects/Heavy Duty Connectors/Contacts
Product Name	Male Crimp Contact
Part Category No.	101019
Series Category No.	CESM
Pin or Socket	Pin
Contact Termination	Crimp
Material	Copper Alloy
Surface Treatment	Silver-plated
Packaging	Bulk
Need Crimp Contacts Separately	No
Application	Applicable to HD, HDD, HM, HK, HQ inserts

ENVIRONMENTAL & EXPORT CLASSIFICATIONS

ATTRIBUTE	DESCRIPTION
RoHS Status	ROHS3 Compliant With Exemption
Moisture Sensitivity Level (MSL)	1 (Unlimited)
REACH Status	REACH Unaffected
ECCN	EAR99
HTSUS	8536.90.4000

GENERAL TECHNICAL CHARACTERISTICS

ATTRIBUTE	DESCRIPTIONS
Rated Current	16A
Contact Resistance	≤1mΩ
Mating Cycles	≥500

TECHNICAL CHARACTERISTICS – For Different Part Code

NEXTGEN ORDER PART CODE *	ORIGINAL MFG PART CODE	ORIGINAL MFG PART NUMBER	WEIGHT	WIRE GAUGE		STRIPPING LENGTH
			g	mm ²	AWG	mm
CESM0M3700L001	CESM- 0.37	1010191100301	1.25	0.14-0.37	26-22	7.5
CESM0M5000L001	CESM- 0.50	1010191100401	1.33	0.5	20	7.5
CESM0M7500L001	CESM- 0.75	1010191100601	1.30	0.75	18	7.5
CESM1M0000L001	CESM- 1.0	1010191100801	1.29	1.0	18	7.5
CESM1M5000L001	CESM- 1.5	1010191100901	1.33	1.5	16	7.5
CESM2M5000L001	CESM- 2.5	1010191101001	1.36	2.5	14	7.5
CESM3M0000L001	CESM- 3.0	1010191101101	1.27	3.0	12	7.5
CESM4M0000L001	CESM- 4.0	1010191101201	1.32	4.0	12	7.5

Note: * Please Indicate this Part Code For RFQ/Order Support By e-mail: sales@NextGenComponent.com

2D ORIGINAL MANUFACTURER SINGAL DATASHEET

日期/Date	档案号 Ring Clerk	产品代号 Part code	产品料号 Part NO.	重量/Weight g	线径/Wire Gauge mm ²	AWG	d	D	剥线长度 Stripping length	标识 Identification	标识图 Identification No.	No.	No.1	No.2	No.3	No.4	No.5	No.6
CESM-0.37	1010191100301	1.25	0.14~0.37	26~22	0.90	1.8	7.5mm	no groove	No.1	标识图 Marked Graph								
CESM-0.5	1010191100401	1.33	0.5	20	1.15	2.6	7.5mm	no groove	No.1									
CESM-0.75	1010191100601	1.30	0.75	18	1.30	2.6	7.5mm	1 groove	No.2									
CESM-1.0	1010191100801	1.29	1.0	18	1.45	2.6	7.5mm	1 groove	No.3									
CESM-1.5	1010191100901	1.33	1.5	16	1.75	3.0	7.5mm	2 groove	No.4									
CESM-2.5	1010191101001	1.36	2.5	14	2.25	3.5	7.5mm	3 groove	No.5									
CESM-3.0	1010191101101	1.27	3.0	12	2.55	3.7	7.5mm	wide groove	No.6									
CESM-4.0	1010191101201	1.32	4.0	12	2.85	3.9	7.5mm	no groove	No.1									

技术参数:

- 材料: 铜合金
- 表面处理: 镀银
- 额定电流: 16A
- 接触电阻: ≤1mΩ
- 线径范围: 1.5mm²(16 AWG)
- 可插拔次数: >500

Technical specification:

- Material: copper alloy
- Surface: hard-silver plated
- Rated current: 16A
- Contact resistance: ≤1mΩ
- Wire gauge: 1.5mm²(16 AWG)
- Mating cycles: >500

NextGen
Components, Inc.

变更描述/Description	姓名/Name	日期/Date	标准/Standard	签名/Signature	日期/Date	表面处理/Finish	材料/Material	版本/Version	重量/Weight	数量/Qty.	图号/Drawing No.	产品代号/Part Code	产品料号/Port No.
BQ LU0	18.10.2010	标准/Standard	-	-	-	-	-	2:1	V1.1	1.33g	-	CESM-1.5	1010191100901
P RAO	18.10.2010	批准/Approved	YY LIN	18.10.2010	All Dimensions in mm Original Size IN A 4	厦门唯恩电气有限公司 XIAMEN WAIN ELECTRONIC CO.LTD							