



FAN MOUNTS

FM Series
Fan Mounts

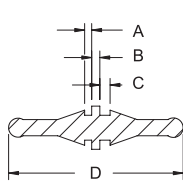
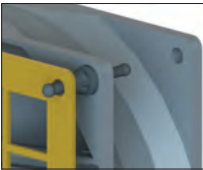


Fig. 1

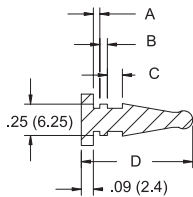


Fig. 2

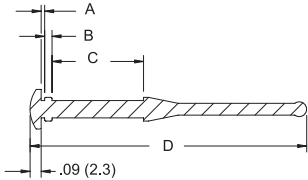


Fig. 3

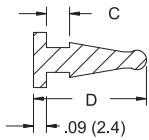


Fig. 4

Specifications:

- Material: See table
- Color: Black



Features:

- Fast mounting of fans eliminating the need for screws
- May reduce noise caused by the vibration of the fan

Item No.	Fig.	Ø Hole		Fan Thickness		Max. Panel Thickness		Material	A		B		C		D		Bulk Pack Qty
		in	mm	in	mm	in	mm		in	mm	in	mm	in	mm	in	mm	
FM-1	1	0.197	5.0	0.079	2.0	0.055	1.4	EPDM Rubber, 30 Shore A	0.05	1.3	0.06	1.5	0.07	1.9	1.27	32.3	1000
FM-2	1	0.197	5.0	0.079	2.0	0.055	1.4	EPDM Rubber, 40 Shore A	0.05	1.3	0.06	1.5	0.07	1.9	1.27	32.3	1000
FM-3	2	0.197	5.0	0.122	3.1	0.055	1.4	EPDM Rubber, 30 Shore A	0.05	1.3	0.06	1.5	0.12	3.0	0.88	22.2	1000
FM-4	2	0.197	5.0	0.122	3.1	0.055	1.4	EPDM Rubber, 40 Shore A	0.05	1.3	0.06	1.5	0.12	3.0	0.88	22.2	1000
FM-5	3	0.138	3.5	0.787	20.0	0.031	0.8	Silicone Rubber, 40 Shore A	0.03	0.7	0.06	1.5	0.73	18.5	2.20	56.0	1000
FM-6	3	0.161	4.3	0.591	15.0	0.118	3.0	Silicone Rubber, 40 Shore A	0.10	2.5	0.08	2.0	0.55	14.0	2.12	53.8	1000
FM-7	3	0.138	3.5	0.98 - 1.10	25.0 - 28.0	0.031	0.8	Silicone Rubber, 40 Shore A	0.03	0.7	0.06	1.5	0.94	24.0	2.87	73.0	1000
FM-8	4	0.197	5.0	0.213	5.4*	0.031	0.8	EPDM Rubber, 30 Shore A	—	—	—	—	0.17	4.3	0.83	21.0	1000
FM-9	4	0.197	5.0	0.213	5.4*	0.031	0.8	EPDM Rubber, 40 Shore A	—	—	—	—	0.17	4.3	0.83	21.0	1000

* Total thickness of panel and fan combined

FMB Series
Break Away Fan Mount

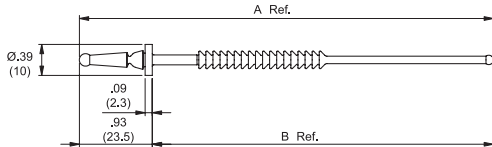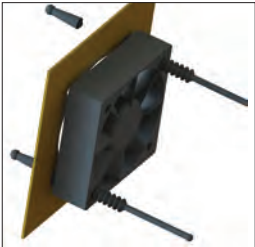

Specifications:



- Material: UL94 HB Silicone Rubber 40 Shore A
- Color: Black

Features:

- Evenly spaced flexible ribs allow mounting fans of many different heights
- Pull-through, break away installation tabs ease installation, especially in blind corners
- Pull-tab breaks away cleanly after installation for low profile panels
- Easy assembly when mounting in restricted spaces
- To save space, end can be cut off after mounting

Item No.	A Ref.		B Ref.		Ø Fan Hole		Fan Thickness		Ø Panel Hole		Panel Thickness		Bulk Pack Qty
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	
FMB-1	5.26	133.5	4.33	110.0	0.18 - 0.20	4.0 - 4.5	0.98 - 2.01	25.0 - 51.0	0.18 - 0.20	4.5 - 5.0	0.03 - 0.06	0.8 - 1.6	1000
FMB-2	3.29	83.5	2.36	60.0	0.13 - 0.14	3.2 - 3.5	Up to 0.40	Up to 10.0	0.18 - 0.20	4.5 - 5.0	0.03 - 0.06	0.8 - 1.6	1000

 FMM Series
Multi Fan Mount

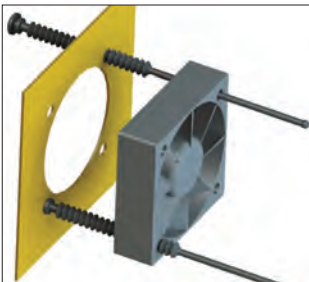

Specifications:

- Material: UL94 HB Silicone Rubber 40 Shore A
- Color: Black

Features:

- One piece design fits all industry standard DC fans from 0.39 - 2.00 (10.0 - 51.0) thick
- Easy assembly when mounting in restricted spaces
- To save space, end can be cut off after mounting

Item No.	Fan Thickness		Ø Fan Hole		Panel Thickness		Ø Panel Hole		Bulk Pack Qty
	in	mm	in	mm	in	mm	in	mm	
FMM-1	0.39 - 2.00	10.0 - 51.0	0.126 - 0.177	3.2 - 4.5	0.039 - 0.059	1.0 - 1.5	0.177 - 0.189	4.5 - 4.8	500