
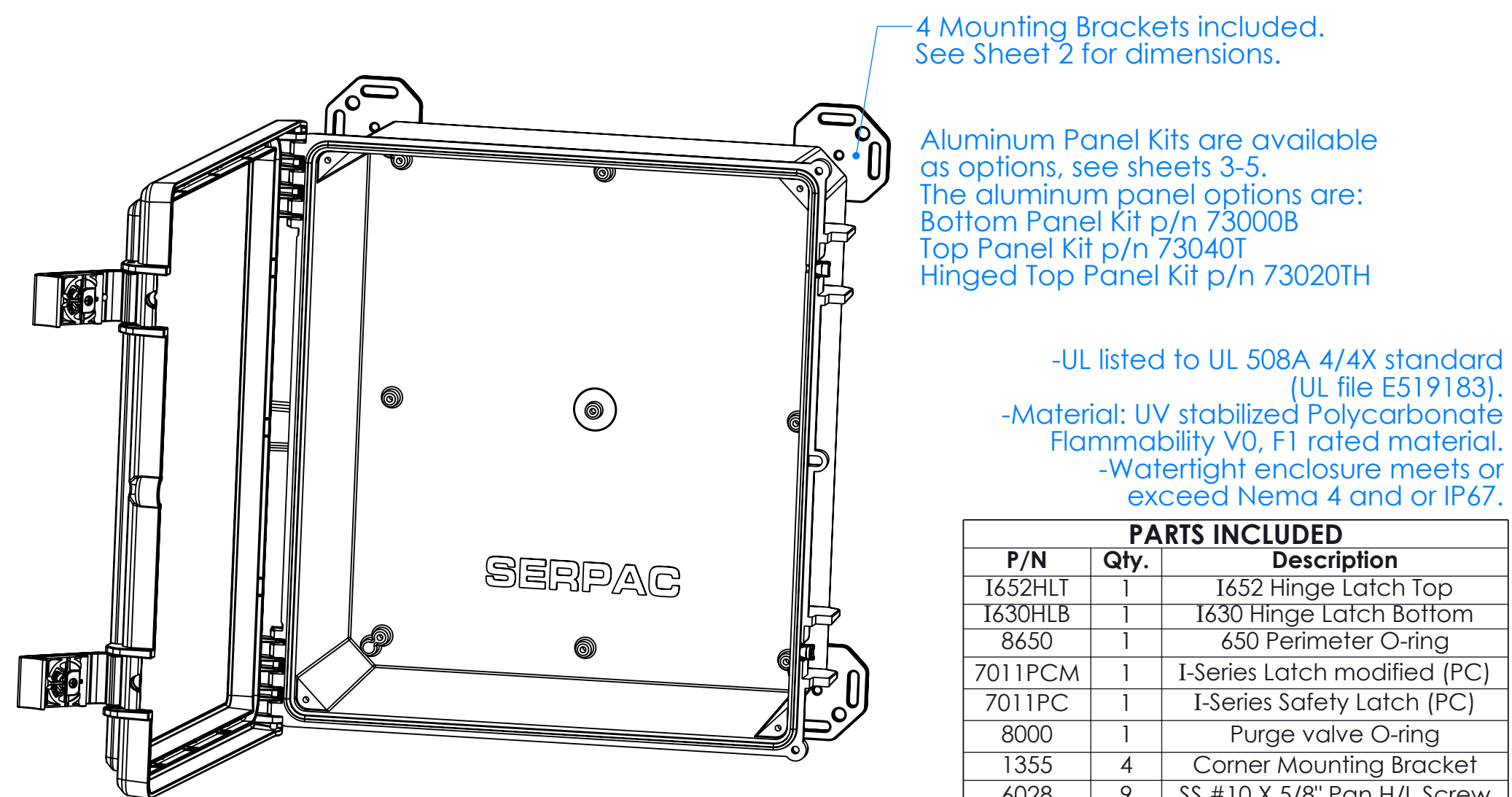
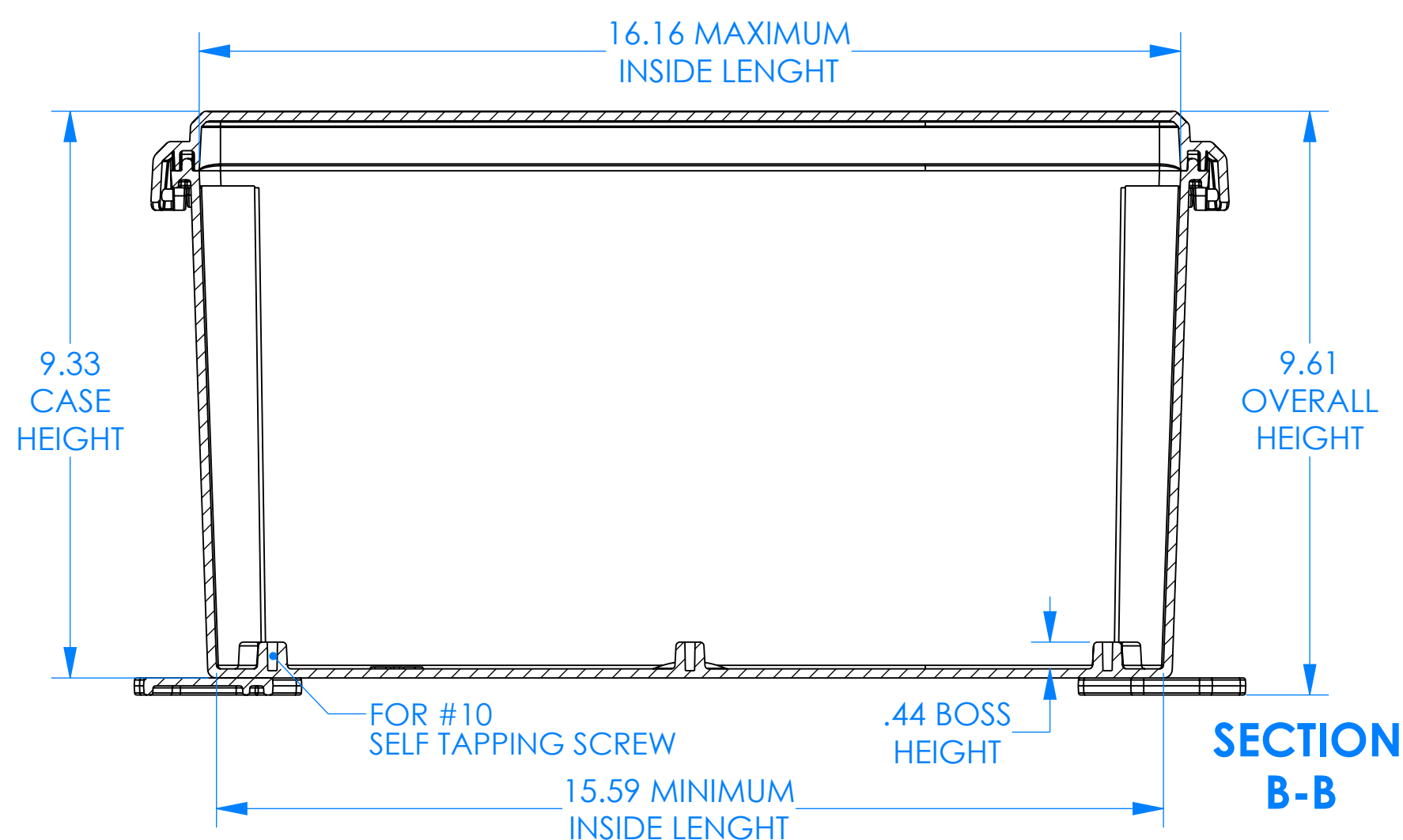
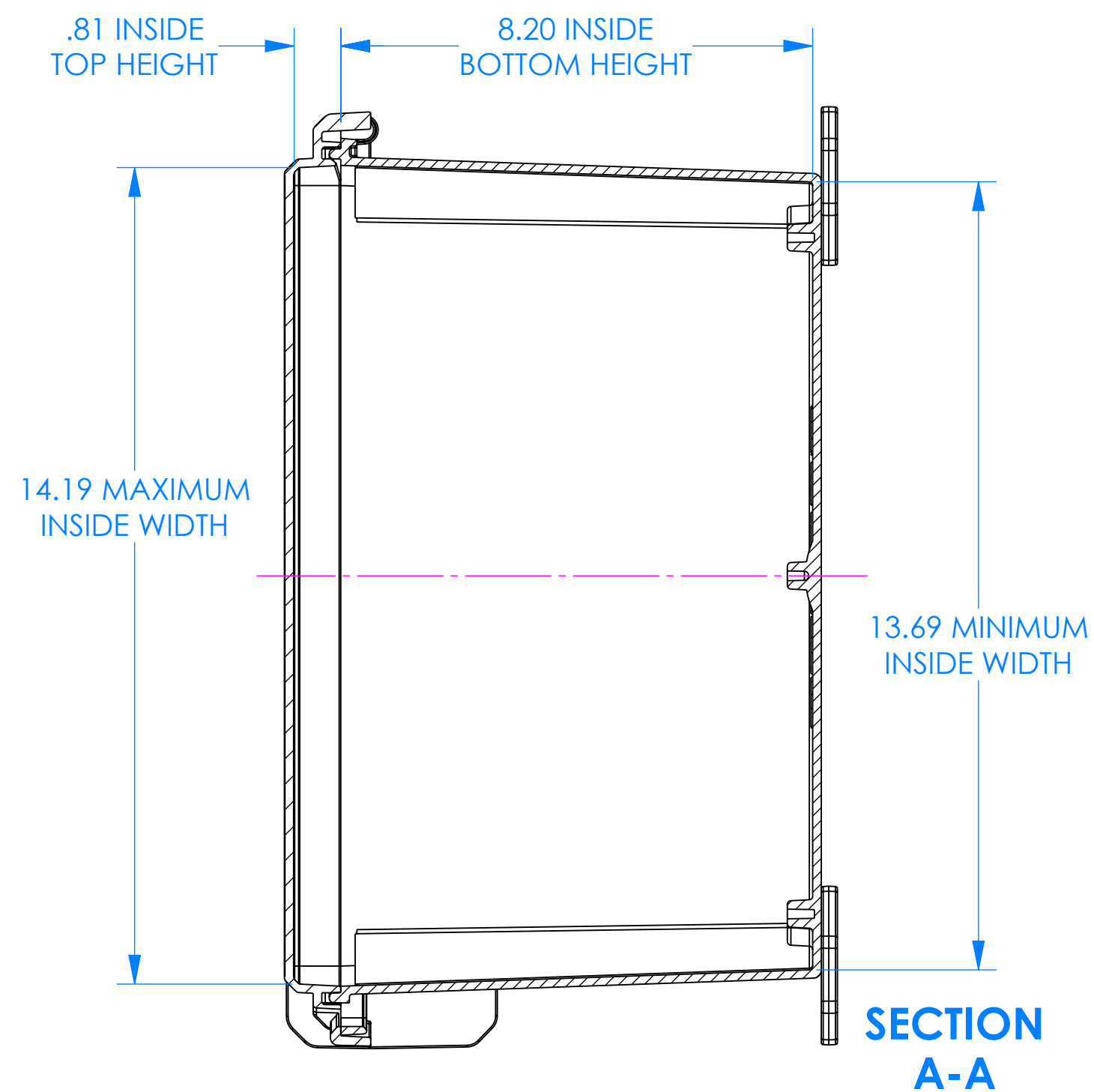


SERPAC I632HL

Electronic Enclosures

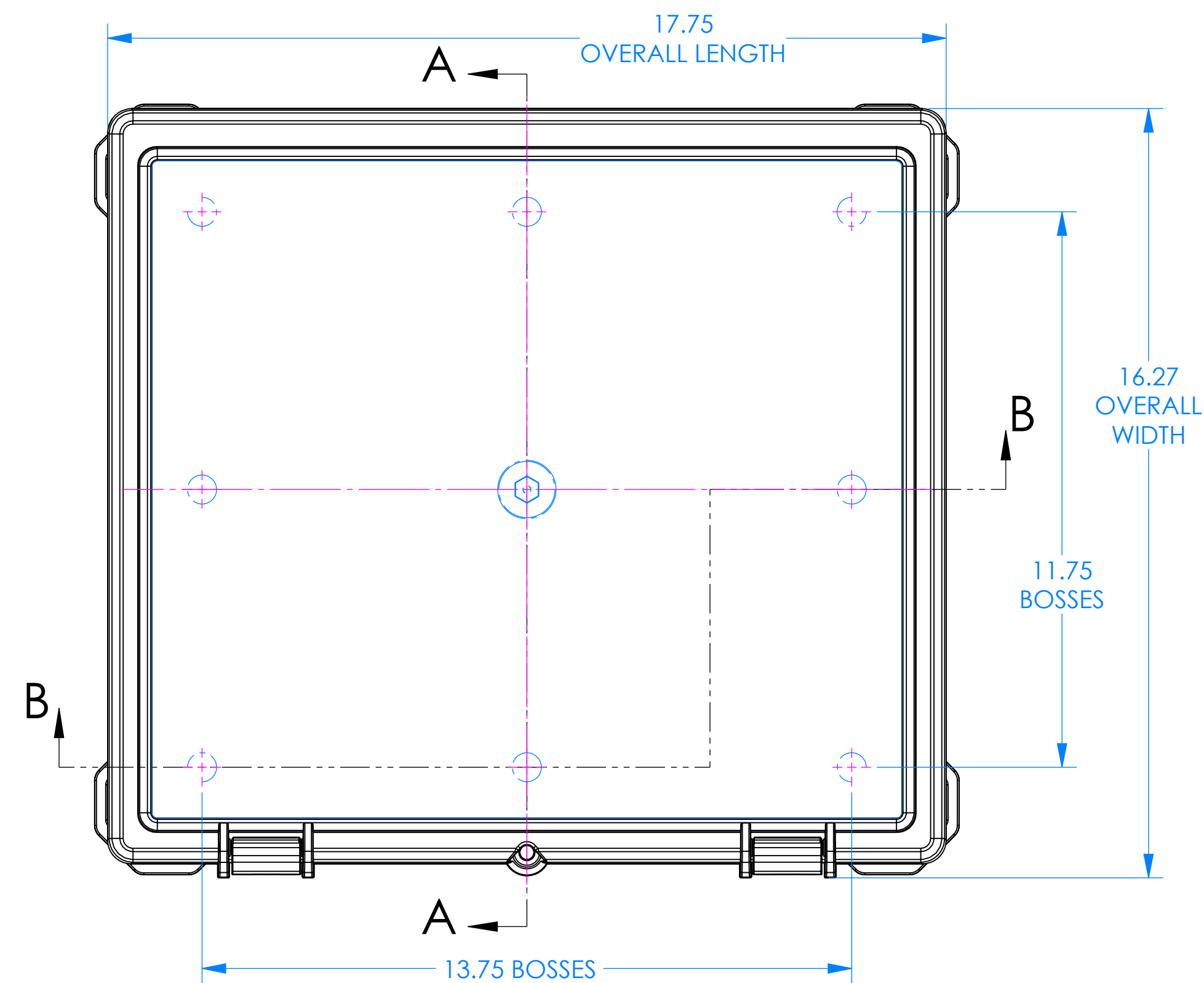


PARTS INCLUDED		
P/N	Qty.	Description
I652HLT	1	I652 Hinge Latch Top
I630HLB	1	I630 Hinge Latch Bottom
8650	1	650 Perimeter O-ring
7011PCM	1	I-Series Latch modified (PC)
7011PC	1	I-Series Safety Latch (PC)
8000	1	Purge valve O-ring
1355	4	Corner Mounting Bracket
6028	9	SS #10 X 5/8" Pan H/L Screw

SERPAC

Electronic Enclosures

I632HL Mounting Bracket Dimensions

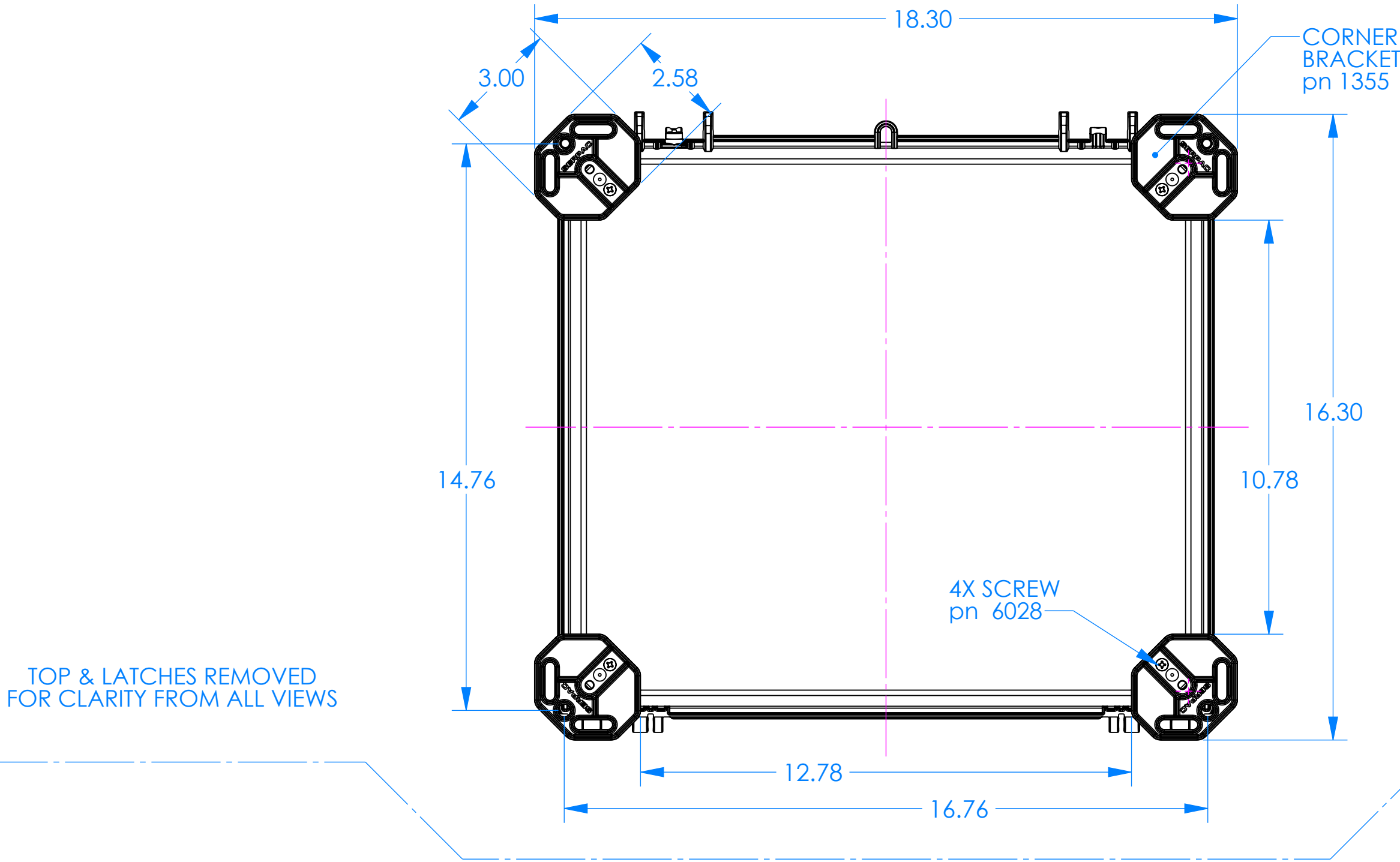


INCLUDED STANDARD
1355 FLANGE KIT

Parts Included in kit number 1355		
P/N	Qty.	Description
1355	4	Mounting Corner Bracket
6028	4	SS #10 X 5/8" Pan Combo H/L Screw



OPTIONAL 1306 CORNER FEET KIT

Parts Included in kit number 1306		
P/N	Qty.	Description
1306	4	Mounting Corner Feet
6028	4	SS #10 X 5/8" Pan Combo H/L Screw

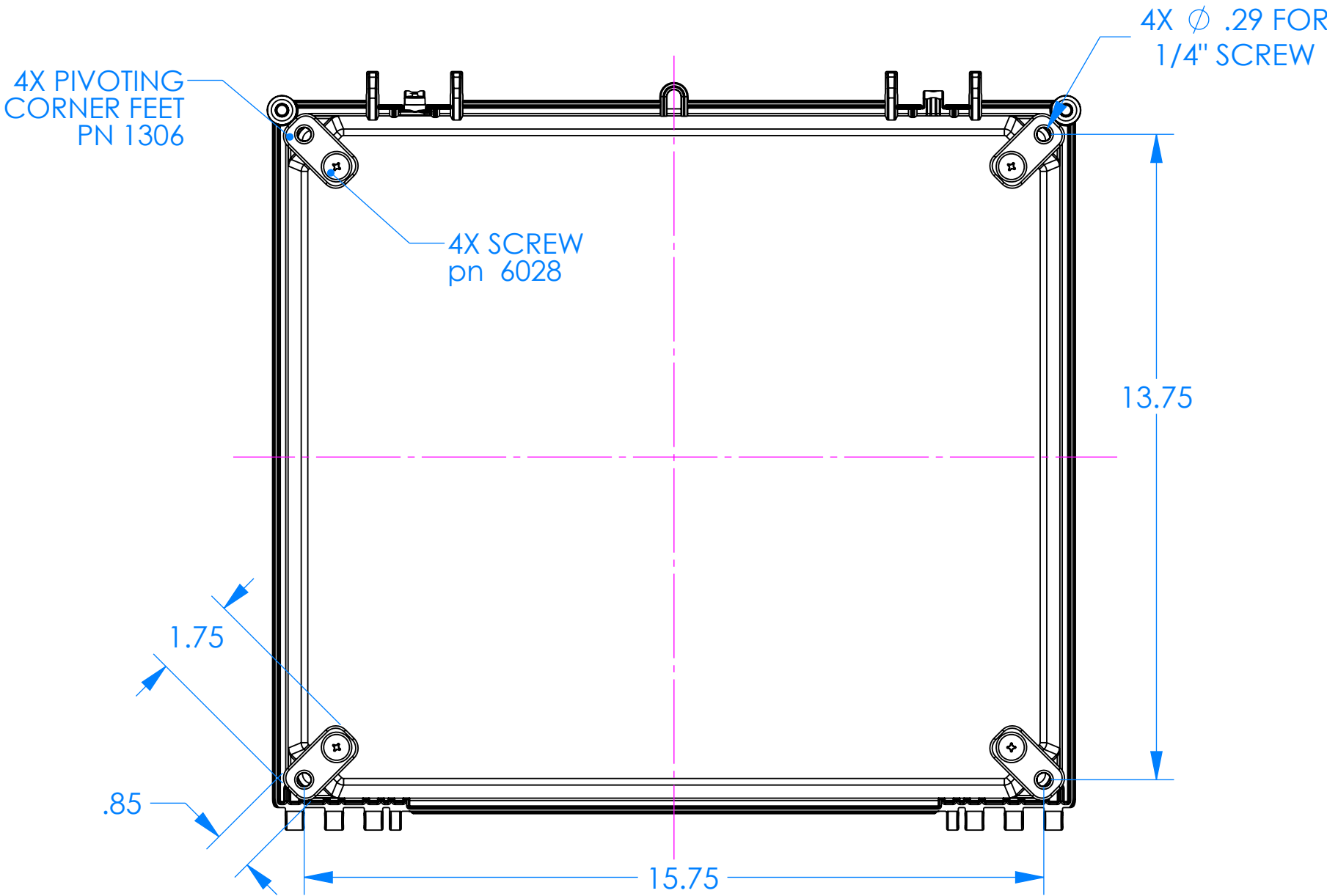


SERPAC
Electronic Enclosures

7300T Aluminum Top Panel Kit for
I602HL, I622HL, I632 and I652

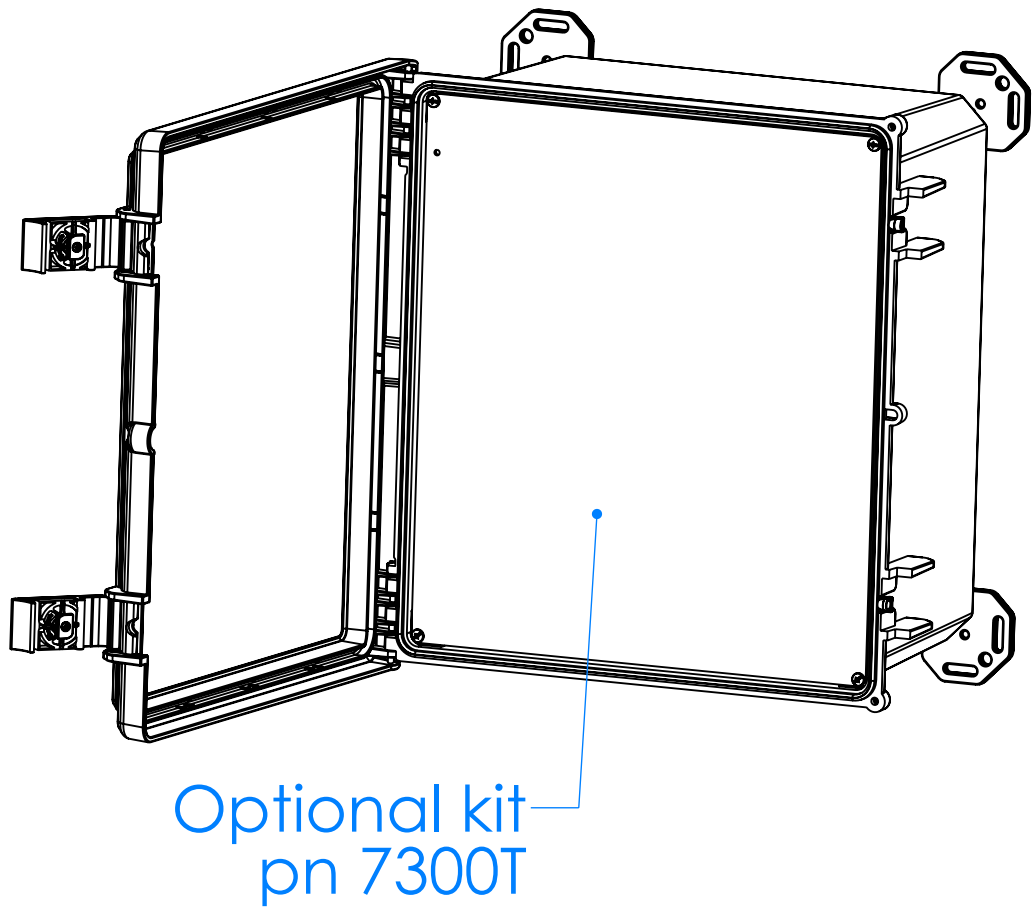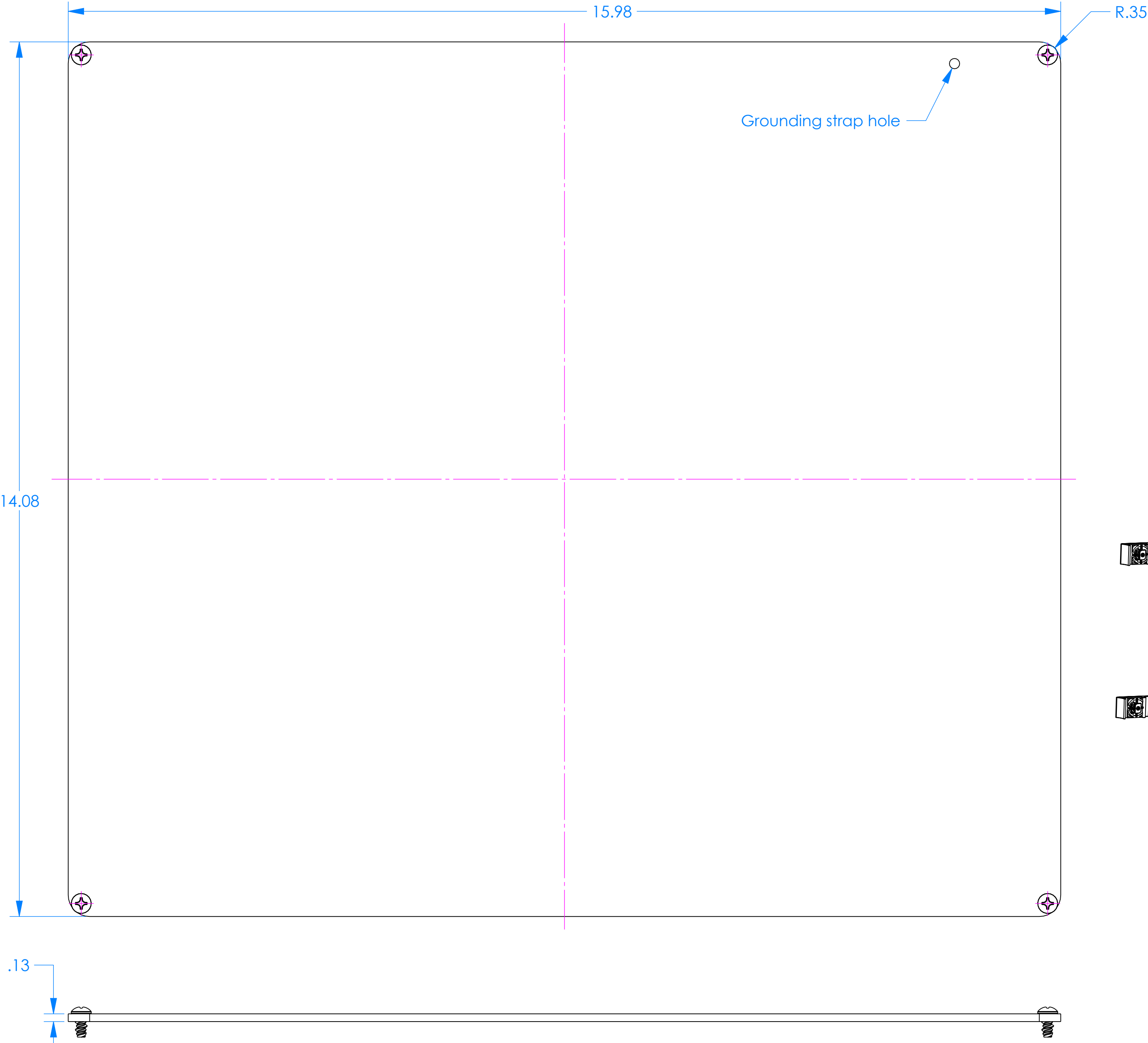



Parts Included in kit number 7300T		
P/N	Qty.	Description
73040	1	Aluminum Top Panel
6029	4	SS #10 X 3/8" Pan HL Screw

73040 Aluminum Top Panel for I602HL, I622HL, I632 and I652

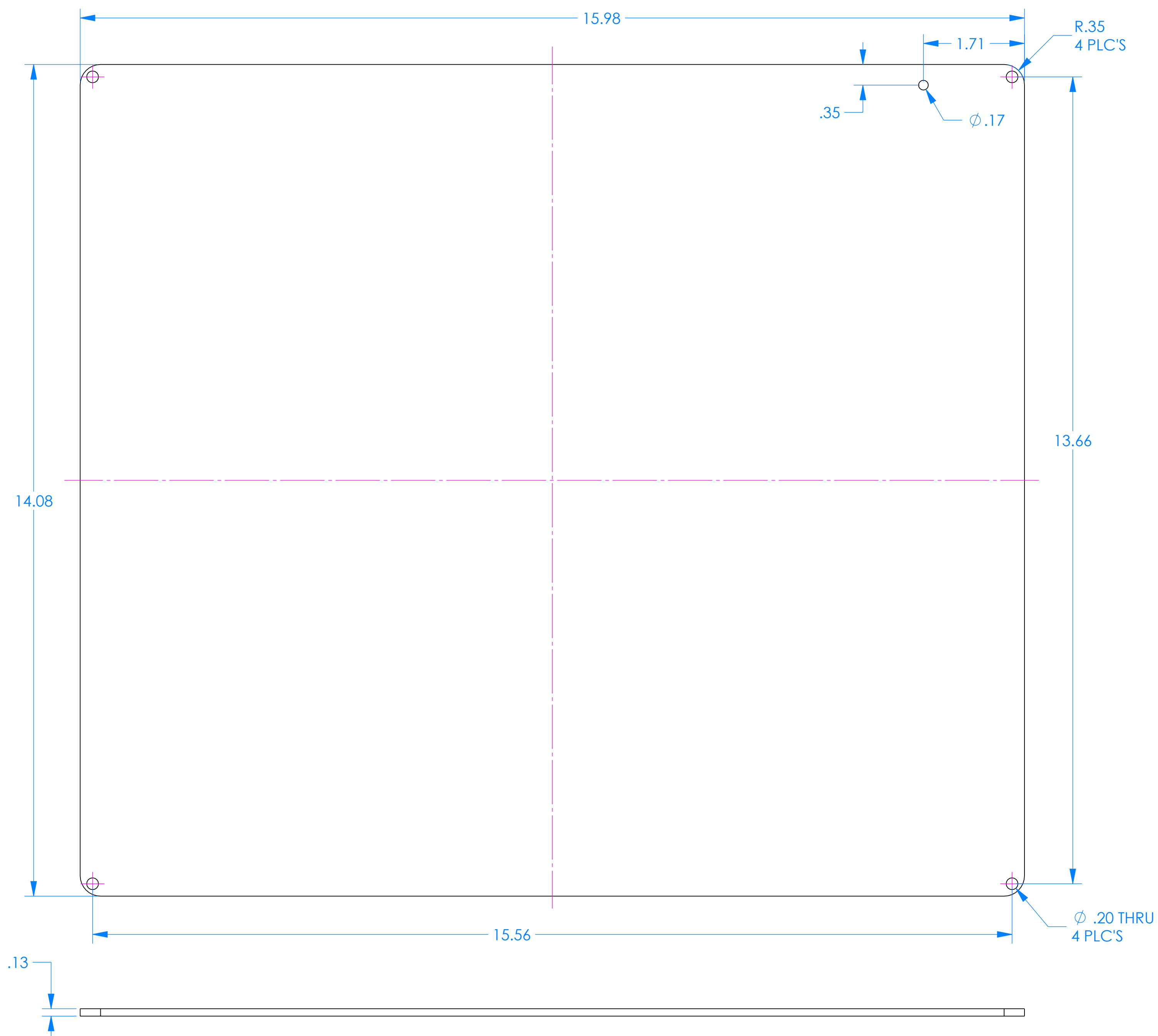


SERPAC
Electronic Enclosures

7300B Aluminum Bottom Panel Kit for
I602HL, I622HL, I632 and I652

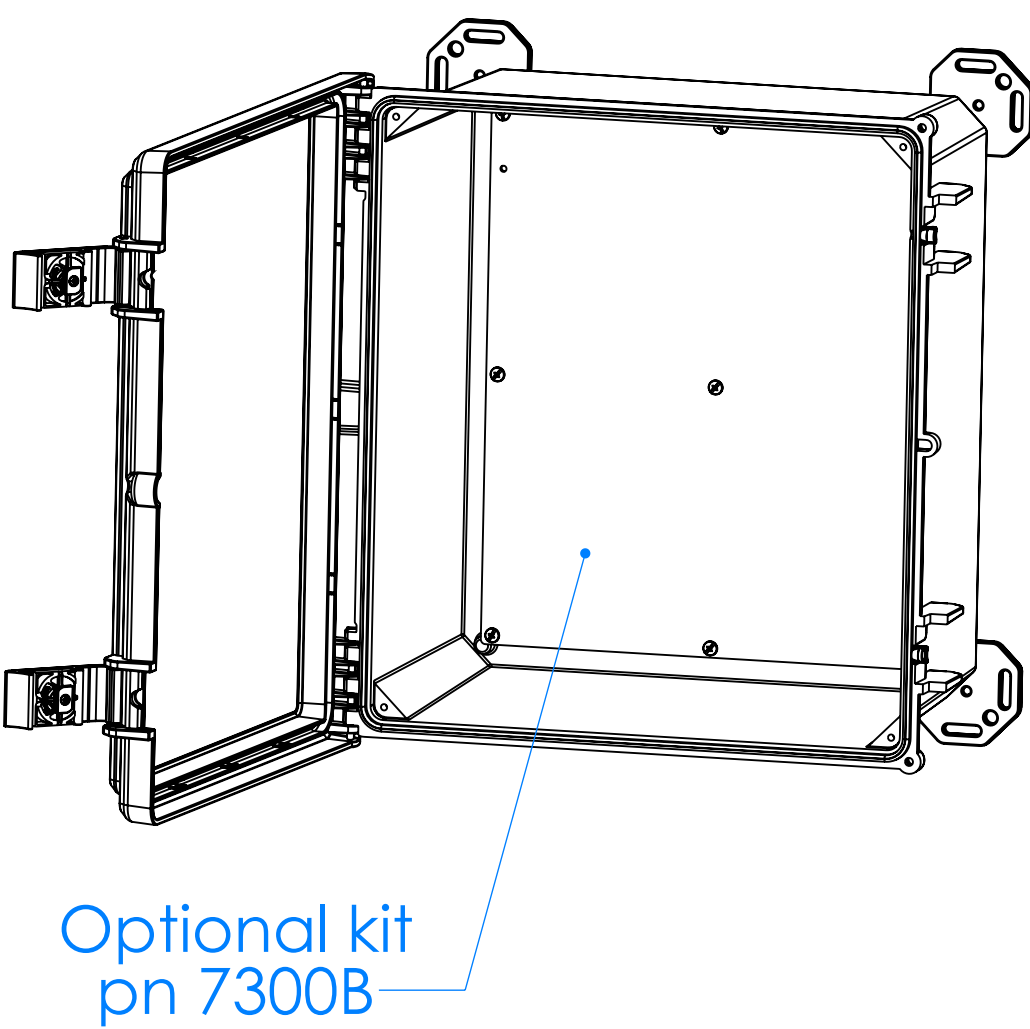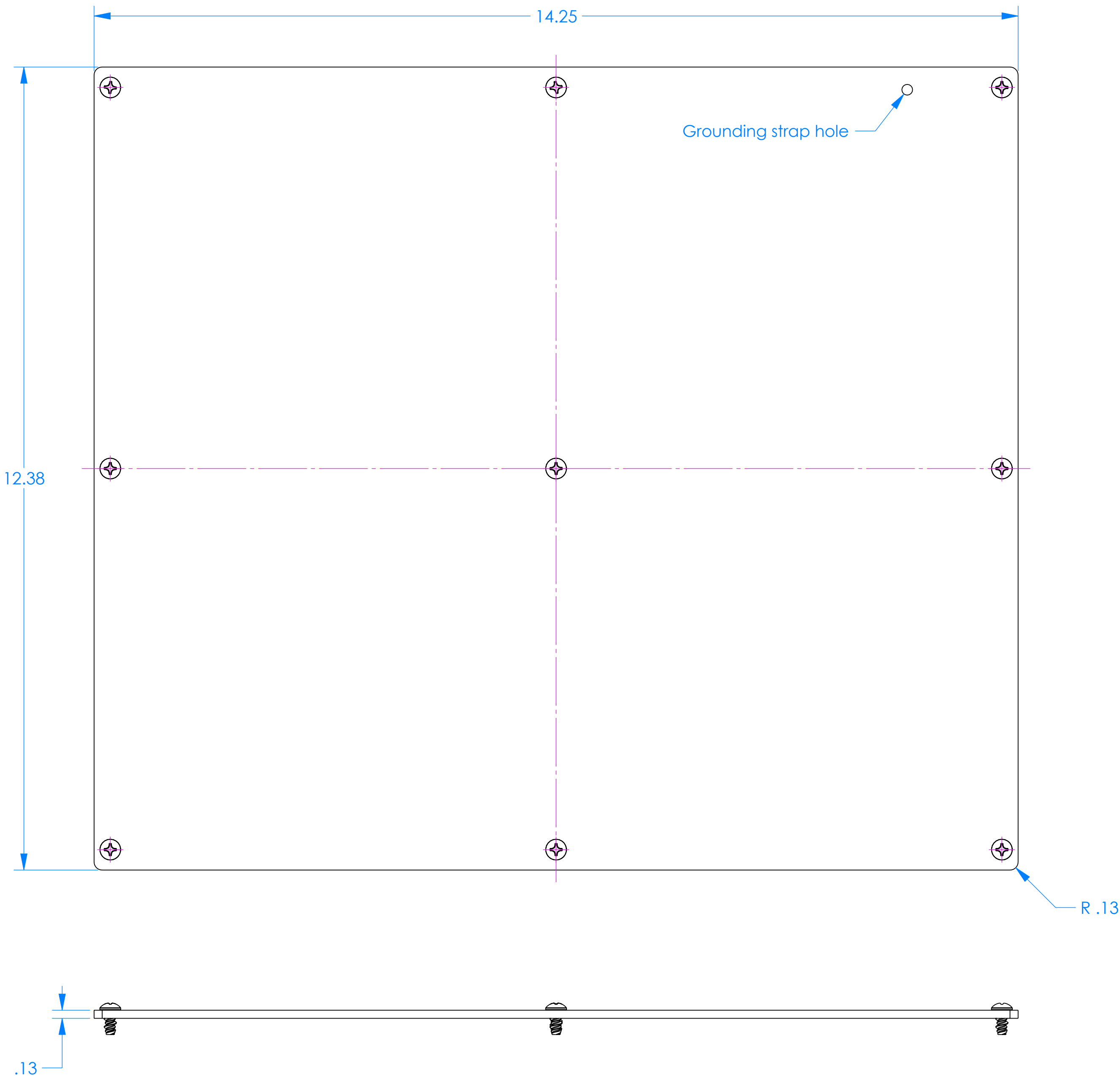

Parts Included in kit number 7300B		
P/N	Qty.	Description
73000	1	Aluminum Bottom Panel
6029	9	SS #10 X 3/8" Pan HL Screw



73000 Aluminum Bottom Panel for I602HL, I622HL, I632 and I652

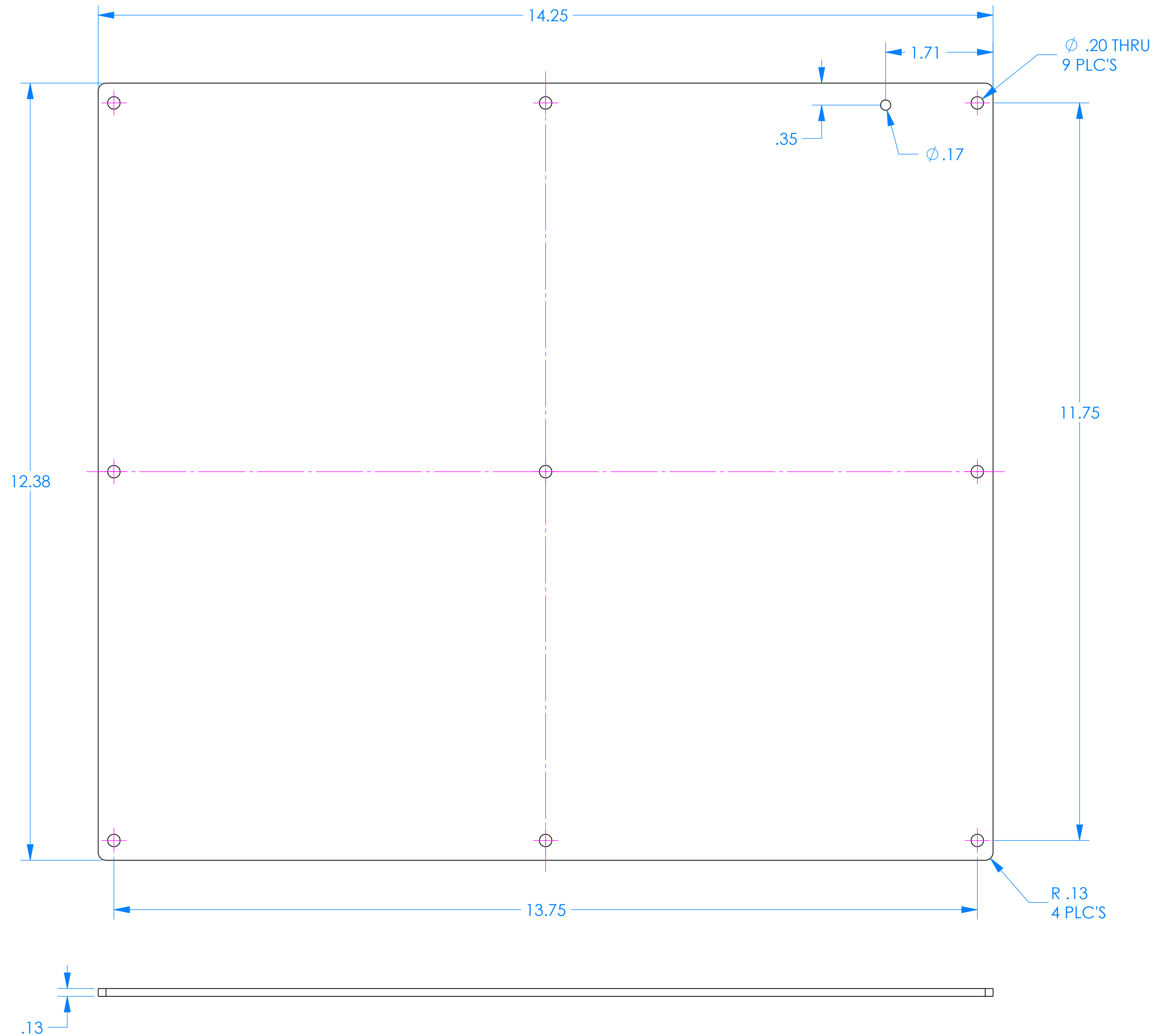

SERPAC

Electronic Enclosures

7300TH Aluminum Hinged Top Panel Kit for I602HL, I622HL, I632 and I652

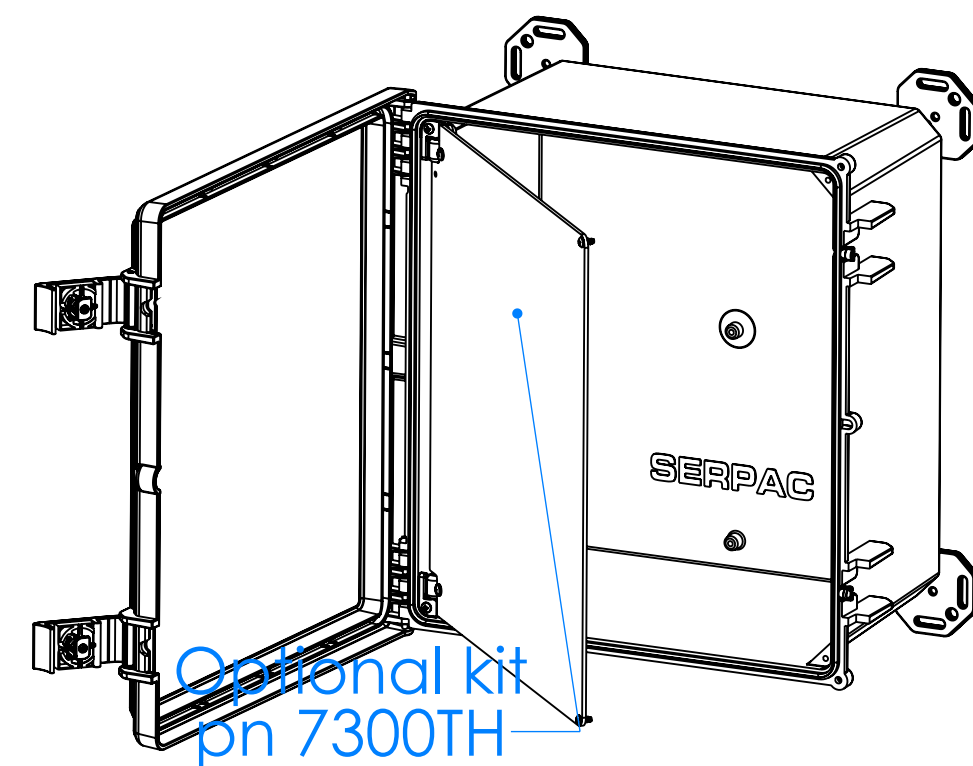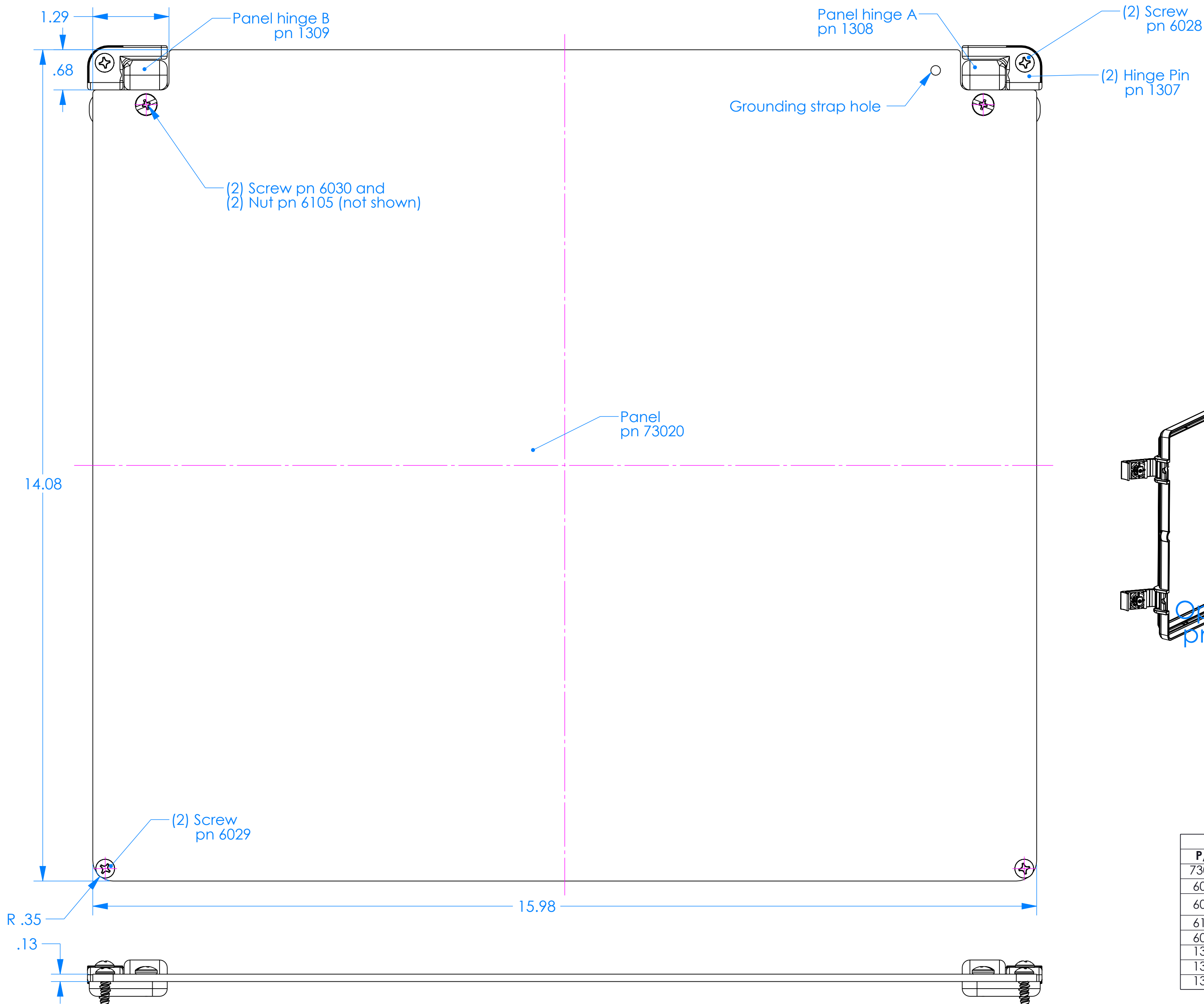

Parts Included in kit number 7300TH		
P/N	Qty.	Description
73020	1	Aluminum Hinged Top Panel
6029	2	SS #10 X 3/8" Pan HL Screw
6030	2	SS #10 X 3/8" Pan Combo H/L Screw
6105	2	SS #10-32 X1/8" Nut
6028	2	SS #10 X 5/8" PH HD H/L Screw
1307	2	Hinge Pin for Hinge Panel
1308	1	Hinge A for Hinge Panel
1309	1	Hinge B for Hinge Panel

73020 Aluminum Hinged Panel for I602HL, I622HL, I632 and I652

