

CLIFF

DC LEADS



VARIANTS

FC582105 - 2.1mm DC Plug to Socket 0.5m


FC582110 - 2.1mm DC Plug to Socket 1m

FC582120 - 2.1mm DC Plug to Socket 2m


FC582505 - 2.5mm DC Plug to Socket 0.5m

FC582510 - 2.5mm DC Plug to Socket 1m

FC582520 - 2.5mm DC Plug to Socket 2m

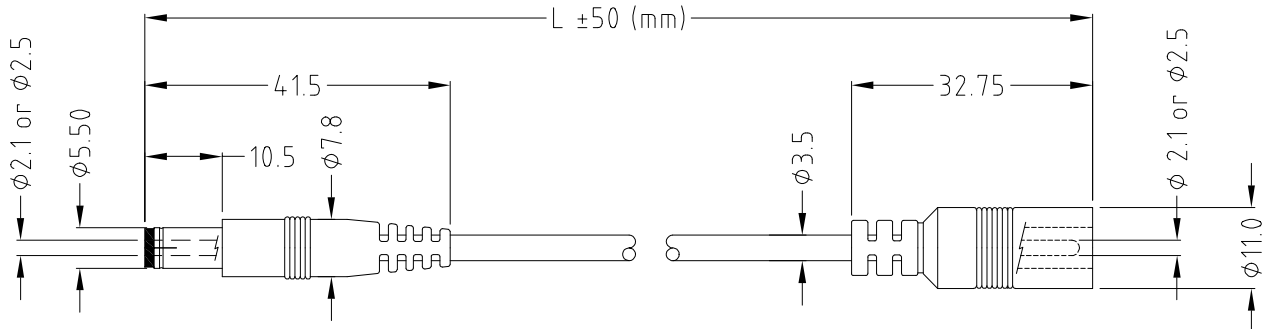

DC PLUG TO FREE END

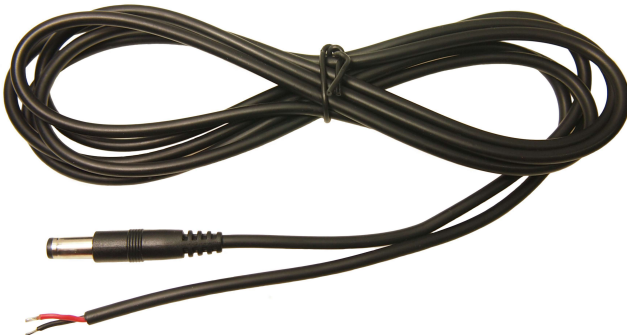

VARIANTS

FC592105 - 2.1mm DC Plug to Free End 0.5m


FC592110 - 2.1mm DC Plug to Free End 1m

FC592120 - 2.1mm DC Plug to Free End 2m

FC592505 - 2.5mm DC Plug to Free End 0.5m

FC592510 - 2.5mm DC Plug to Free End 1m

FC592520 - 2.5mm DC Plug to Free End 2m

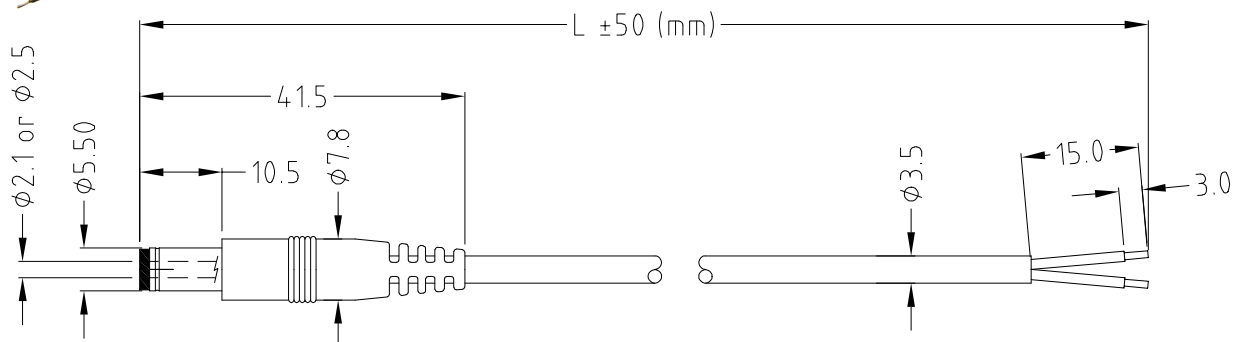

MATERIAL

Plug Overmould: 40P PVC Black

Cable: Black PVC 17x0.16 (2x)

Plug Contact: Brass Ni Plated

Socket Contact: Brass Ni Plated

SPECIFICATION

Max Voltage: 12V

Max Current: 2A

Dielectric Withstand: 300V DC

Conductor Resistance: 2Ω

Insulation Resistance: 50MΩ