

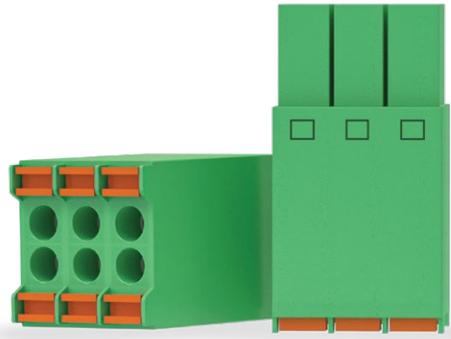
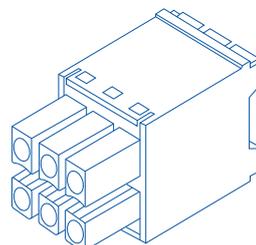
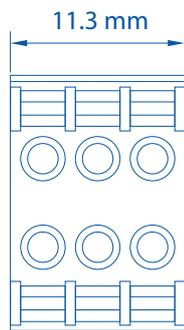


# 2X3PIN CONNECTOR

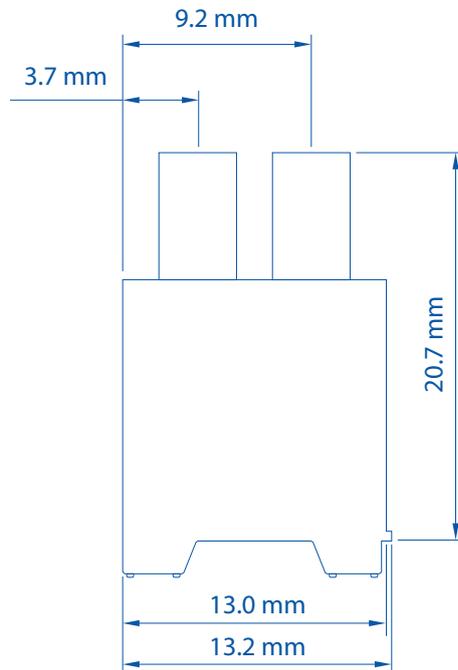

## TECHNICAL DATA

GENERAL		ADDITIONAL	
Insulation material	PA66	Rated voltage	300 V
Contact material	Copper alloy	Rated current	8 A
Contact finishing	Tin-plated	Dielectric voltage-withstand	1600V/1min
Wire cross section	0.2-1.5mm <sup>2</sup> (24-16AWG)	Strip Length	9 - 10mm
Pitch	3.5 mm	Certification	• RoHS
Temperature range	-40 +105		• REACH
			• UL94V-0

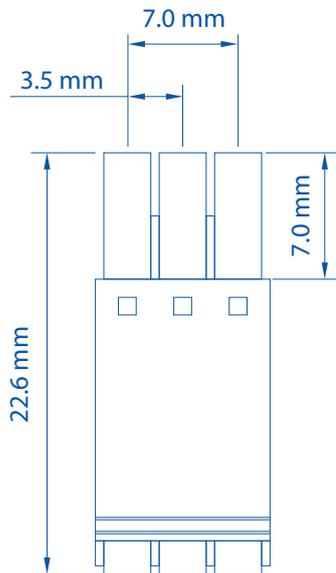

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR4RS06K](#)