


Part Number: RBF-40T
Flashing Safety Light - Tilt Activated, Fully Sealed
Product Datasheet



PICTURE



DIMENSIONS

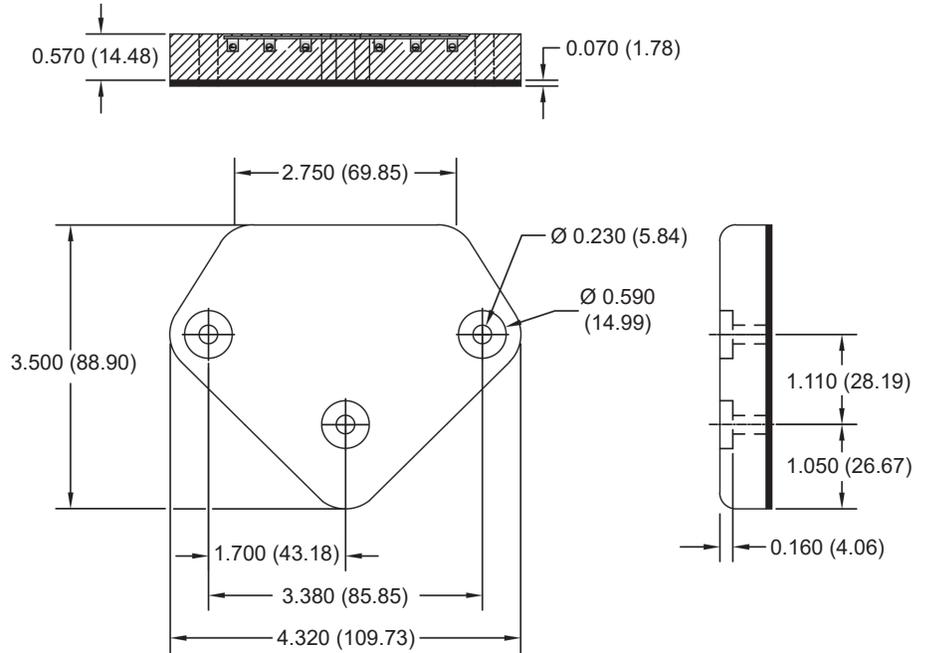


Drawings not to scale.
 All dimensions in mm nominal.


FEATURES

- Robust New Slim Design
- Vibration Resistant
- No Mechanical Parts
- Plug and Play Device
- 3 Bright Pulses Every Flash

OPERATION

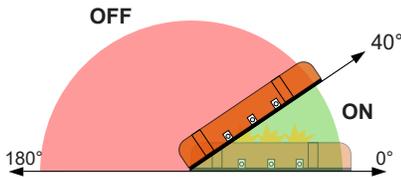

ACTIVATION

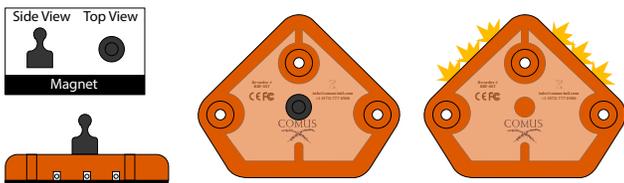

Place Magnet on Center Circle of the Flasher to Turn ON

DEACTIVATION Only if removing from gate.



Step 1: Rotate Flasher 90° Step 2: Place Magnet on Flasher for 5 seconds. It should flash consecutively 5 times before ultimately turning OFF.

SPECIFICATION

Operation Angle	Degree	40° Tilt (see above for activating flasher)
Battery Life		Aprox 3 years (1 hour a day, under normal conditions)
Number of LED's		6
Operating Temperature	Celsius	-20° to 85°
Flash Rate	P/min	35 / min (3 bright pulse every flash, duration 1/2 second)
Battery Voltage (non replaceable)	Volts	3.6
Fixing Holes		3 x 5.8 mm
IP Rating		68
Material		Resin filled Polycarbonate Shell

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone: (1) 973 777 6900 **www.comus-intl.com** **Fax: (1) 973 777 8405**

Belgium: + 32 (0)12 390400 - Comus Europe Ltd (Assemblech) UK: +44 (0) 1255 862236 - Germany: +49 (0)911 923 15 943 - Netherlands: +31(0)45 54 39 345 - India: +(91) (44) 43219090

©2020 Copyright Comus International, 454 Allwood Road, Clifton NJ 07012, USA