

RJ45 PROFINET Kabel PVC 4p; Cat. 5; 0,8m

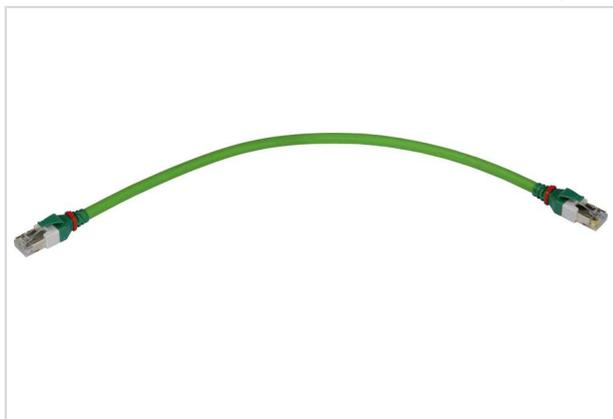


Image is for illustration purposes only. Please refer to product description.

Part number	09 48 686 8001 008
Specification	RJ45 PROFINET Kabel PVC 4p; Cat. 5; 0,8m
HARTING eCatalogue	https://harting.com/09486868001008

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING DualBoot RJ45
Connector 2	HARTING DualBoot RJ45
Type of cable	Copper cable (round)
Description of the cable	Straight

Version

Cable length	0.8 m
Number of cores	4
Core structure	4x AWG 22/7

Technical characteristics

Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s
Limiting temperature	-25 ... +60 °C

Material properties

Material (cable)	PVC
------------------	-----



Pushing Performance
Since 1945

Material properties

Colour (cable) Green

Specifications and approvals

Specifications UN/ECE-R 118 fire protection for rolling stock

UL / CSA UL 1863 DUXR.E470046
Raw cable UL rating 600 V

PROFINET Yes

Commercial data

Packaging size 1

Net weight 72 g

Country of origin Latvia

European customs tariff number 85444290

GTIN 5713140883437

eCl@ss 27060308 Patch cord copper (data cable)
