

Sales Outline Drawing

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Specifications:

Panel Hole (mm)	19 mm
Switch Rated Voltage VDC	12
Switch Rated Current mADC	50
Switch Function	OFF-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP67
Shock Resistance	IK08
Material, Light Ring	PC
Material, Button	Stainless Steel
Material, Body	Stainless Steel
Material, Base	PA66+GF20% Nylon
Material, Gasket	SIL Silica Gel
Material, Nut	H59 Brass
Termination Type	WIRES
Wire Specification	20cm AWG 22

Example Part Number:


RoHS Compliant

FPM19-FW3-S0M4R2

* NOTES LED COLOR & VDC

LED Color	VDC						
	2	3	5	6	12	24	36
R - RED	1.8-2.2V	2.7-3.3V	4.5-5.5V	5.4-6.6V	10.8-13.2V	21.6-26.4V	32.4-39.6V
G - GREEN	N/A	3-3.2V	4.5-5.5V	5.4-6.6V	10.8-13.2V	21.6-26.4V	32.4-39.6V
B - BLUE	N/A	3-3.2V	4.5-5.5V	5.4-6.6V	10.8-13.2V	21.6-26.4V	32.4-39.6V
Y - YELLOW	2-2.2V	2.7-3.3V	4.5-5.5V	5.4-6.6V	10.8-13.2V	21.6-26.4V	32.4-39.6V
W - WHITE	N/A	3-3.2V	4.5-5.5V	5.4-6.6V	10.8-13.2V	21.6-26.4V	32.4-39.6V

Dimensions (mm):

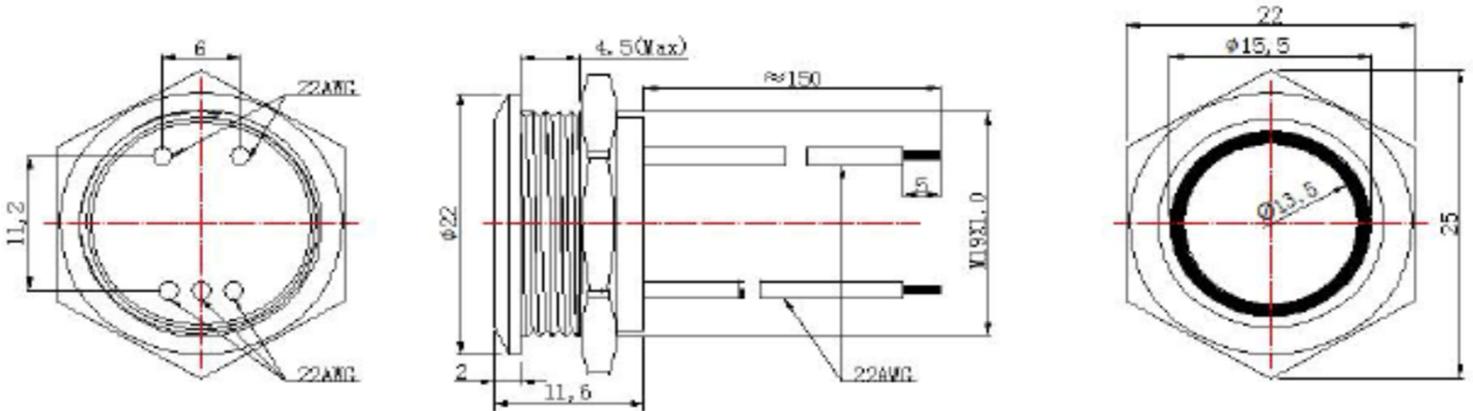

CONNECTION DIAGRAM:

PANEL HOLE:

