

Home / Products / Hand Tools / PA2034 DIE RG58/59/62AU  
COAX


# PA2034 DIE RG58/59/62AU COAX

**Cat No:** PA2034

**UPC No:** 769328101041

[Contact Sales](#)

CrimpALL® Interchangeable DieSets for Coaxial Connectors

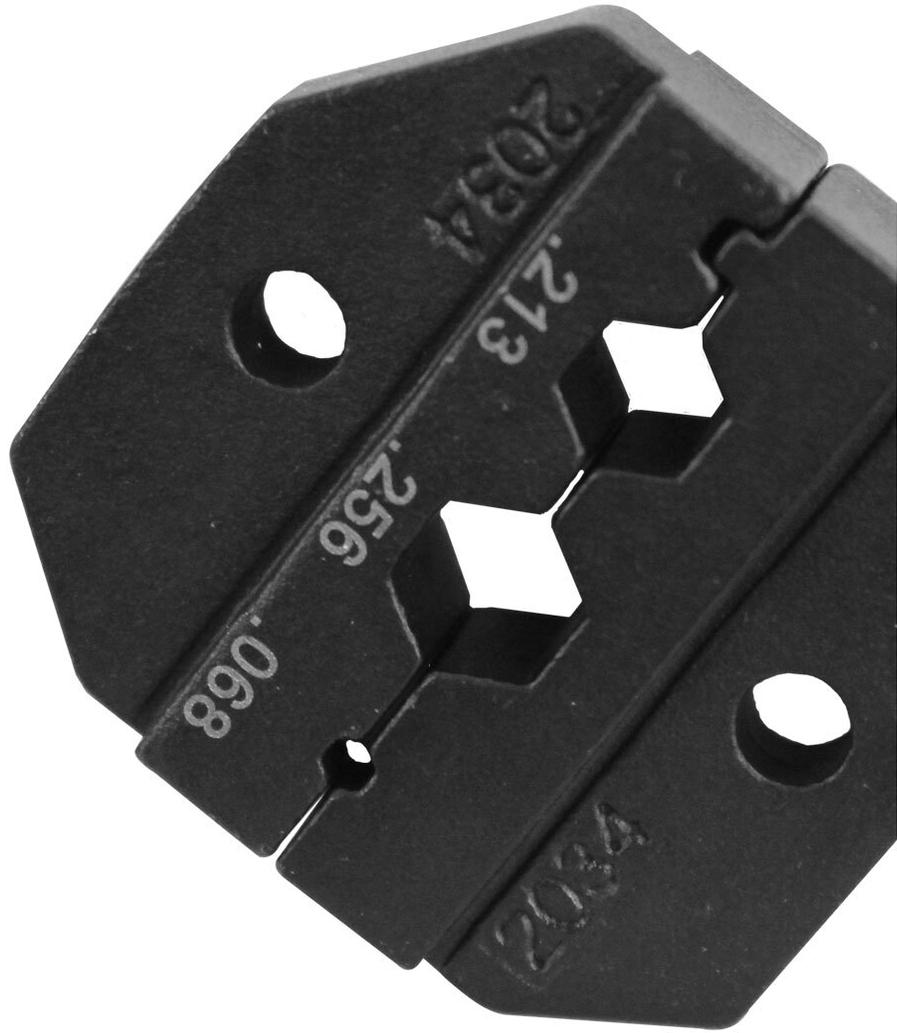

## Specifications

Attribute Name	Attribute Value
Application	For Coaxial Connectors
Cable Type	RG58, RG59, RG62AU
Connection	BNC/TNC And 3 Piece
Crimp Size	0.256 IN (6.500 MM), 0.213 IN(5.400 MM), 0.068 IN (1.700 MM) HEX
Sub Brand	CrimpALL
Type	Interchangeable
Item Status Date	04302010
Country of Origin	TW
UNSPSC	43223334
International Harmonize Code	8207306092
RoHS Indicator	U
MSDS Update Flag	N

## Products

- Cable TV
- Copper-DSL
- Ethernet
- Fiber Optic Instruments
- Hand Tools
- Location and Irrigation
- VDV Instruments

## Our Company

- About Us
- Jobs
- Paladin

- [Adapters](#)

## Quick Links

- [Request a Demo](#)
- [Contact Us](#)
- [Join Mailing List](#)
- [News](#)
- [Where to Buy](#)



©2020 Tempo Communications, Inc.

[Cookies](#) [License Agreement](#) [Privacy Policy](#)

[Terms & Conditions](#) [Vendor Information](#)