

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Home](#) / [Products](#) / [NEMA / IP Rated Boxes](#) / [PTQ Series Fiberglass Box](#) / Fiberglass Box with Stainless Steel Latch and Clear Cover PTQ-11036-C

Fiberglass Box with Stainless Steel Latch and Clear Cover PTQ-11036-C



2 Videos

Model # PTQ-11036-C


[PTQ Series Fiberglass Box](#)

- Body made of gray polycarbonate plastic 10% glass fiber filled
- Hinged cover made of clear polycarbonate plastic
- High impact resistance IK08
- Stainless steel latch
- IP67 TUV rating to keep out dust and water in extreme conditions (meets NEMA Type 6)
- UL508 / UL tested for type 4X, listed #E194432.
- RoHs compliant
- Non-chlorinated & non-brominated flame retardant With UL-94 V0 and UL-94 5VA rating @ 3 mm
- Suitable for outdoor use with respect to exposure to ultraviolet light, water exposure and immersion in accordance with UL 746C
- -40 C to +95 C extended exposure condition
- Good chemical resistance
- Continuous gasket
- [View NEMA/IP Accessories](#)

[Check Stock / Pricing](#)[Estimate Modifications](#)[Compare Sizes and Models](#)[See Accessories](#)**External Size L x W x D:** 7.61" x 5.31" x 3.94"**Internal Size L x W x D:** 6.66" x 4.36" x 3.68"**Weight:** 0.99 lbs**Color:** Light Gray**RoHS Certified:** Always Compliant**Use Gallery Photo:** true**NEMA Rating:** NEMA 1, NEMA 2, NEMA 4, NEMA 4X, NEMA 6**IP Rating:** IP67**Features:** 10% Fiberglass Reinforced Plastic**Cover Style:** Clear, Hinged Cover**Latch Style:** Stainless Steel**Knockouts:** No Knockouts**Indoor / Outdoor:** Outdoor (UV Stabilized)**Flammability Rating:** UL94-5VA**Door Flammability Rating:** UL94-5VA**Type of Plastic:** Gray Polycarbonate**Door Type of Plastic:** Clear Polycarbonate**Service Temperature Min:** -40°C**Service Temperature Max:** 95°C

If you're looking for a Clear Polycarbonate NEMA rated or IP rated enclosure for a printed circuit board (PCB) that measures up to 6.66" x 4.36" x 3.68" or smaller, then this enclosure is an excellent choice.

[DRAWING](#)

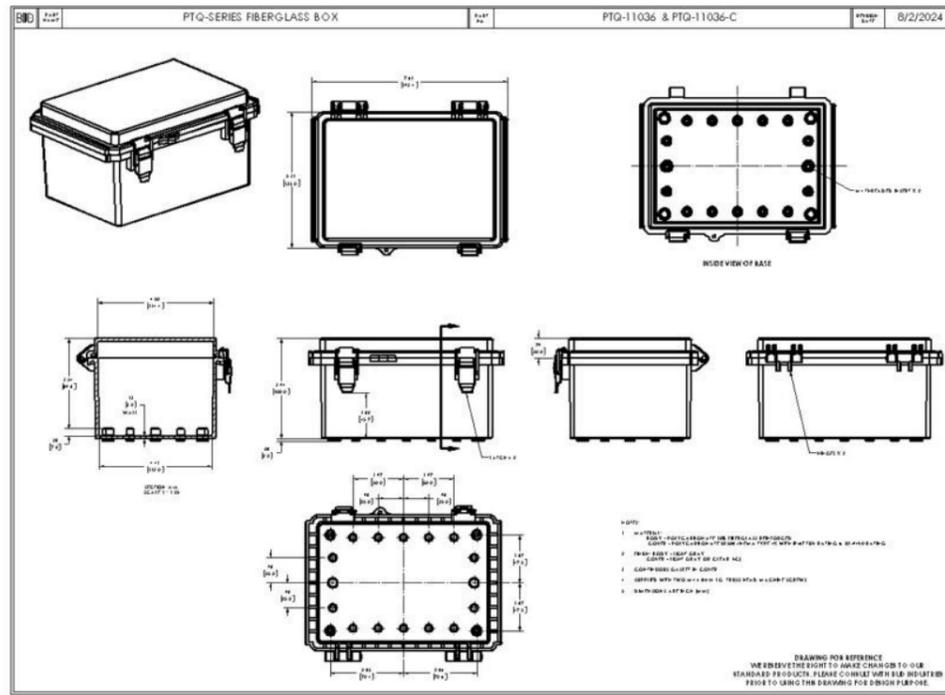

[EMAIL ME THE STEP FILE](#)

OTHER MODELS IN THIS SERIES

-- External Dimensions -- -- Internal Dimensions -- -- Cover Style -- -- Indoor / Outdoor --

-- Type of Plastic --

Model #	External Dimensions	Internal Dimensions	Cover Style	Indoor / Outdoor	Type of P
PTQ-11035-C	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11035	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11135	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11038	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11038-C	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11138	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11046-C	5.91" x 5.91" x 3.55"	4.59" x 4.59" x 3.11"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11046	5.91" x 5.91" x 3.55"	4.59" x 4.59" x 3.11"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11047-C	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11047	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11147	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11044-C	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11044	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11144	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11136	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11036	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11036-C	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11048-C	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11148	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	Gray Polyca
PTQ-11048	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11055	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11055-C	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11155	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11140	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11040-C	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11040	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11143	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11043-C	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11043	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11142	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11042-C	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11042	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11051	10.21" x 6.28" x 5.10"	9.90" x 5.96" x 4.78"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11051-C	10.21" x 6.28" x 5.10"	9.90" x 5.96" x 4.78"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11050	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11050-C	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11150	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11041	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca

Model #	External Dimensions	Internal Dimensions	Cover Style	Indoor / Outdoor	Type of P
PTQ-11041-C	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11141	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11145	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11045	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11045-C	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11057-C	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11057	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11157	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11054	11.35" x 11.02" x 5.12"	10.40" x 10.07" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11054-C	11.35" x 11.02" x 5.12"	10.40" x 10.07" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11049	11.35" x 7.48" x 3.95"	10.40" x 6.53" x 3.69"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11049-C	11.35" x 7.48" x 3.95"	10.40" x 6.53" x 3.69"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11158	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11058-C	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11058	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11166	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11066	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11066-C	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11059-C	11.81" x 7.87" x 5.91"	10.51" x 6.70" x 5.21"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11059	11.81" x 7.87" x 5.91"	10.51" x 6.70" x 5.21"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11070	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11070-C	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11170	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11162	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11062	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11062-C	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11053	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11053-C	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11153	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11064	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11164	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11064-C	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11168	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11068	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11068-C	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11072-C	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11072	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11172	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11073-C	17.72" x 13.78" x 6.30"	17.87" x 13.50" x 5.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11073	17.72" x 13.78" x 6.30"	17.87" x 13.50" x 5.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11076-C	19.69" x 15.75" x 7.87"	19.45" x 15.50" x 7.18"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11076	19.69" x 15.75" x 7.87"	19.45" x 15.50" x 7.18"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11077	23.62" x 15.75" x 7.09"	23.50" x 15.63" x 6.97"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11077-C	23.62" x 15.75" x 7.09"	23.50" x 15.63" x 6.97"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11080	24.80" x 20.87" x 10.04"	24.28" x 20.50" x 9.30"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11180	24.80" x 20.87" x 10.04"	24.28" x 20.50" x 9.30"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11181	28.74" x 20.87" x 7.28"	28.60" x 20.75" x 7.16"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
PTQ-11081	28.74" x 20.87" x 7.28"	28.60" x 20.75" x 7.16"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11083	32.68" x 24.80" x 7.28"	32.50" x 24.68" x 7.16"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
PTQ-11183	32.68" x 24.80" x 7.28"	32.50" x 24.68" x 7.16"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS

ACCESSORIES



PTX-25311-P, Internal ABS plastic Panel 6.34 x 4.45 Inches for PTQ-11044

PTX-25311-P

[View Details](#)

Check Stock / Pricing

PTX-25311, Internal Steel Panel 6.34 x 4.45 Inches for PTQ-11044 And PTQ-11036

PTX-25311

[View Details](#)

Check Stock / Pricing

Plastic Mounting Bracket

PIX-4117

[View Details](#)

Check Stock /

RELATED PRODUCT SERIES



PTH Series Fiberglass Box

[VIEW SERIES DETAILS](#)



PTS Series Fiberglass Box

[VIEW SERIES DETAILS](#)



NBF Series NEI

[VIEW SERIES D](#)

440-946-3200 [Find Distributor/ Rep](#) [Contact Us](#)



[Warranty](#) [Privacy Policy](#) [Unsubscribe](#)

©2021 - 2026 BUD Industries, all rights reserved

Contact Us

Name *

First

Last

Company

Email *

Phone *

State

Country

Comments *

I agree to receive email announcements from Bud Industries. See Privacy Policy.

 I'm not a robot reCAPTCHA
Privacy - Terms