

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Home](#) / [Products](#) / [NEMA / IP Rated Boxes](#) / [PTQ Series Fiberglass Box](#) / Fiberglass Box with Stainless Steel Latch PTQ-11041

## Fiberglass Box with Stainless Steel Latch PTQ-11041

[2 Videos](#)

### Model # PTQ-11041


[PTQ Series Fiberglass Box](#)

- Body made of gray polycarbonate plastic 10% glass fiber filled
- Hinged cover made of gray polycarbonate plastic
- High impact resistance IK08
- Stainless steel latch
- IP67 TUV rating to keep out dust and water in extreme conditions (meets NEMA Type 6)
- UL508 / UL tested for type 4X, listed #E194432.
- RoHs compliant
- Non-chlorinated & non-brominated flame retardant With UL-94 V0 and UL-94 5VA rating @ 3 mm
- Suitable for outdoor use with respect to exposure to ultraviolet light, water exposure and immersion in accordance with UL 746C
- -40 C to +95 C extended exposure condition
- Good chemical resistance
- Continuous gasket
- [View NEMA/IP Accessories](#)

[Check Stock / Pricing](#)[Estimate Modifications](#)[Compare Sizes and Models](#)[See Accessories](#)**External Size L x W x D:** 10.57" x 6.30" x 5.12"**Internal Size L x W x D:** 9.62" x 5.35" x 4.86"**Weight:** 1.77 lbs**Color:** Light Gray**RoHS Certified:** Always Compliant**Use Gallery Photo:** true**NEMA Rating:** NEMA 1, NEMA 2, NEMA 4, NEMA 4X, NEMA 6**IP Rating:** IP67**Features:** 10% Fiberglass Reinforced Plastic**Cover Style:** Opaque, Hinged Cover**Latch Style:** Stainless Steel**Knockouts:** No Knockouts**Indoor / Outdoor:** Outdoor (UV Stabilized)**Flammability Rating:** UL94-5VA**Door Flammability Rating:** UL94-5VA**Type of Plastic:** Gray Polycarbonate**Door Type of Plastic:** Gray Polycarbonate**UL Rating:** UL508**Service Temperature Min:** -40°C**Service Temperature Max:** 95°C

If you're looking for a Gray Polycarbonate NEMA rated or IP rated enclosure for a printed circuit board (PCB) that measures up to 9.62" x 5.35" x 4.86" or smaller, then this enclosure is an excellent choice.

### DRAWING

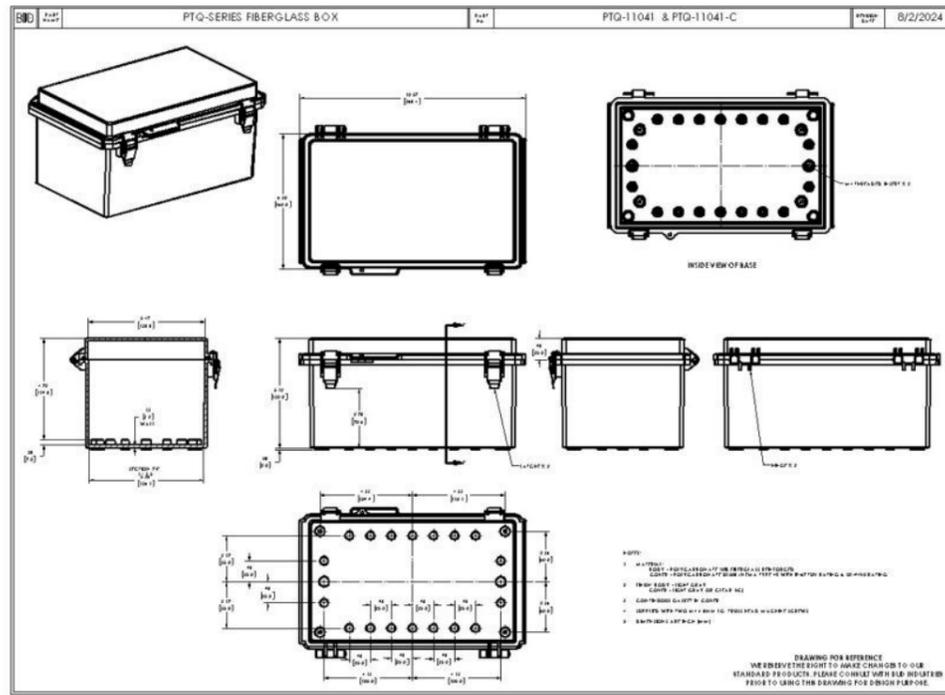

[EMAIL ME THE STEP FILE](#)

### OTHER MODELS IN THIS SERIES

Model #	External Dimensions	Internal Dimensions	Cover Style	Indoor / Outdoor	Type of P
<a href="#">PTQ-11035-C</a>	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11035</a>	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11135</a>	4.72" x 3.54" x 2.76"	4.60" x 3.42" x 2.64"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11038</a>	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11038-C</a>	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11138</a>	5.91" x 3.94" x 3.35"	5.79" x 3.82" x 3.23"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11046-C</a>	5.91" x 5.91" x 3.55"	4.59" x 4.59" x 3.11"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11046</a>	5.91" x 5.91" x 3.55"	4.59" x 4.59" x 3.11"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11047-C</a>	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11047</a>	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11147</a>	5.91" x 5.91" x 4.73"	5.79" x 5.79" x 4.60"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11044-C</a>	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11044</a>	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11144</a>	7.28" x 5.31" x 3.36"	7.16" x 5.19" x 3.23"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11136</a>	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11036</a>	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11036-C</a>	7.61" x 5.31" x 3.94"	6.66" x 4.36" x 3.68"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11048-C</a>	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11148</a>	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	Gray Polyca
<a href="#">PTQ-11048</a>	8.27" x 6.30" x 3.94"	7.27" x 5.40" x 3.36"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11055</a>	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11055-C</a>	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11155</a>	8.27" x 8.27" x 5.13"	8.15" x 8.15" x 5.00"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11140</a>	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11040-C</a>	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11040</a>	8.60" x 6.30" x 5.12"	7.65" x 5.35" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11143</a>	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11043-C</a>	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11043</a>	8.60" x 8.27" x 3.94"	7.65" x 7.32" x 3.68"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11142</a>	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11042-C</a>	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11042</a>	10.20" x 4.33" x 3.94"	10.10" x 4.21" x 3.82"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11051</a>	10.21" x 6.28" x 5.10"	9.90" x 5.96" x 4.78"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11051-C</a>	10.21" x 6.28" x 5.10"	9.90" x 5.96" x 4.78"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11050</a>	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11050-C</a>	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca
<a href="#">PTQ-11150</a>	10.24" x 6.30" x 3.94"	9.15" x 5.28" x 3.41"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11041</a>	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polyca

Model #	External Dimensions	Internal Dimensions	Cover Style	Indoor / Outdoor	Type of P
<a href="#">PTQ-11041-C</a>	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11141</a>	10.57" x 6.30" x 5.12"	9.62" x 5.35" x 4.86"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11145</a>	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11045</a>	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11045-C</a>	10.96" x 6.69" x 4.33"	10.01" x 5.74" x 4.07"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11057-C</a>	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11057</a>	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11157</a>	11.02" x 7.48" x 5.51"	9.87" x 6.34" x 4.82"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11054</a>	11.35" x 11.02" x 5.12"	10.40" x 10.07" x 4.86"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11054-C</a>	11.35" x 11.02" x 5.12"	10.40" x 10.07" x 4.86"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11049</a>	11.35" x 7.48" x 3.95"	10.40" x 6.53" x 3.69"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11049-C</a>	11.35" x 7.48" x 3.95"	10.40" x 6.53" x 3.69"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11158</a>	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11058-C</a>	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11058</a>	11.80" x 7.87" x 5.12"	11.60" x 7.75" x 5.00"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11166</a>	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11066</a>	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11066-C</a>	11.81" x 11.81" x 7.09"	11.69" x 11.60" x 6.97"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11059-C</a>	11.81" x 7.87" x 5.91"	10.51" x 6.70" x 5.21"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11059</a>	11.81" x 7.87" x 5.91"	10.51" x 6.70" x 5.21"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11070</a>	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11070-C</a>	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11170</a>	13.78" x 13.78" x 5.91"	13.66" x 13.60" x 5.79"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11162</a>	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11062</a>	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11062-C</a>	13.78" x 9.84" x 7.09"	12.70" x 8.76" x 6.84"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11053</a>	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11053-C</a>	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11153</a>	14.11" x 9.84" x 5.90"	13.16" x 8.89" x 5.64"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11064</a>	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11164</a>	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11064-C</a>	14.96" x 11.02" x 5.12"	13.84" x 9.89" x 4.42"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11168</a>	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11068</a>	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11068-C</a>	15.75" x 11.81" x 5.91"	15.51" x 11.50" x 5.21"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11072-C</a>	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11072</a>	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11172</a>	17.72" x 13.78" x 4.72"	17.60" x 13.60" x 4.60"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11073-C</a>	17.72" x 13.78" x 6.30"	17.87" x 13.50" x 5.60"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11073</a>	17.72" x 13.78" x 6.30"	17.87" x 13.50" x 5.60"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11076-C</a>	19.69" x 15.75" x 7.87"	19.45" x 15.50" x 7.18"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11076</a>	19.69" x 15.75" x 7.87"	19.45" x 15.50" x 7.18"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11077</a>	23.62" x 15.75" x 7.09"	23.50" x 15.63" x 6.97"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11077-C</a>	23.62" x 15.75" x 7.09"	23.50" x 15.63" x 6.97"	Clear, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11080</a>	24.80" x 20.87" x 10.04"	24.28" x 20.50" x 9.30"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11180</a>	24.80" x 20.87" x 10.04"	24.28" x 20.50" x 9.30"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11181</a>	28.74" x 20.87" x 7.28"	28.60" x 20.75" x 7.16"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS
<a href="#">PTQ-11081</a>	28.74" x 20.87" x 7.28"	28.60" x 20.75" x 7.16"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11083</a>	32.68" x 24.80" x 7.28"	32.50" x 24.68" x 7.16"	Opaque, Hinged Cover	Outdoor (UV Stabilized)	Gray Polycarbonate
<a href="#">PTQ-11183</a>	32.68" x 24.80" x 7.28"	32.50" x 24.68" x 7.16"	Opaque, Hinged Cover	Indoor (Not UV Stabilized)	ABS

## ACCESSORIES



**PTX-11050-P, Internal ABS plastic Panel  
8.82 x 5.08 Inches for PTQ-11050**

PTX-11050-P

[View Details](#)

**Check Stock / Pricing**

**PTX-11050,Internal Steel Panel 9.15 x  
5.38 Inches for PTQ-11050**

PTX-11050

[View Details](#)

**Check Stock / Pricing**

**Plastic Mounting Bracket**

PIX-4117

[View Details](#)

**Check Stock /**

## RELATED PRODUCT SERIES



**PTH Series Fiberglass Box**

[VIEW SERIES DETAILS](#)



**PTS Series Fiberglass Box**

[VIEW SERIES DETAILS](#)



**NBF Series NEI**

[VIEW SERIES D](#)

440-946-3200 [Find Distributor/ Rep](#) [Contact Us](#)



[Warranty](#) [Privacy Policy](#) [Unsubscribe](#)

©2021 - 2026 BUD Industries, all rights reserved

## Contact Us

Name \*

First

Last

Company

Email \*

Phone \*

State

Country

Comments \*

I agree to receive email announcements from Bud Industries. See Privacy Policy.

 I'm not a robot reCAPTCHA  
Privacy - Terms